

### Basic features

Approval/Conformity	CE Ecolab WEEE
---------------------	----------------------

### Electrical connection

Bending radius min., fixed cable	5 x D
Bending radius min., flexible cable	10 x D
Cable	TPE-V gray, 2 m
Cable diameter D	9.20 mm ±0.3 mm
Conductor cross-section	1.5 mm <sup>2</sup>
Connection	7/8"-Female, straight, 5-pin
Connector configuration	Straight
Number of conductors	5
Number of pins	5
System	Molded

### Electrical data

Cable rated voltage AC max.	600 V
Cable rated voltage DC max.	600 V
Operating voltage Ub	300 VDC / 300 VAC
Operating voltage Ub 3-phase network	277/480V AC +/- 15%
Rated current (40 °C)	9.0 A

### Remarks

Halogen-free per DIN VDE 0472 Part 815  
 Halogen-free acc. to IEC 60754-1  
 LABS-free  
 Enclosure rating per IEC 60529 or 20653, only in screwed state with the associated mating piece.

### Environmental conditions

Cable temperature, fixed routing	-50...105 °C
Cable temperature, flexible routing	-25...105 °C
IP rating	IP69K


### Material

Cable jacket, material	TPE-V
Material contact carrier	PP
Material contacts	Brass
Material cover nut	1.4404 stainless steel
Material grip	PP

### Mechanical data

Cable jacket, color	gray
Cable length L	2.00 m
Tightening torque pigtail	1.5 Nm

## Connector Drawings

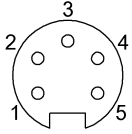

- PIN 1: black
- PIN 2: blue
- PIN 3: green/yellow
- PIN 4: brown
- PIN 5: white

## Wiring Diagrams

