


Remarks

See short guide

For more information about MTTF and B10d see MTTF / B10d Certificate

Indication of the MTTF- / B10d value does not represent a binding composition and/or life expectancy assurance; these are simply experiential values with no warranty implications. These declared values also do not extend the expiration period for defect claims or affect it in any way.

Connector Drawings

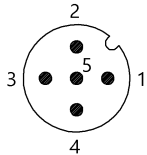

- PIN 1: +24V, US
- PIN 2: +24V, UA
- PIN 3: GND
- PIN 4: C/Q, IO-Link
- PIN 5: n.c.

Wiring Diagrams

| Requirements | Wire color |
|----------------------|----------------|
| 0 V, GND | Black |
| Input 1 / Output 1 | Purple |
| Input 2 / Output 2 | White |
| Input 3 / Output 3 | Brown |
| Input 4 / Output 4 | Green |
| Input 5 / Output 5 | Yellow |
| Input 6 / Output 6 | Gray |
| Input 7 / Output 7 | Rose |
| Input 8 / Output 8 | Blue |
| Input 9 / Output 9 | Red / Blue |
| Input 10 / Output 10 | Gray / Rose |
| Input 11 / Output 11 | White / Gray |
| Input 12 / Output 12 | Gray / Brown |
| Input 13 / Output 13 | White / Green |
| Input 14 / Output 14 | Brown / Green |
| Input 15 / Output 15 | Yellow / Brown |
| Input 16 / Output 16 | White / Yellow |
| US Supply +24 V | Red |