


### Dimensions (mm / inch)

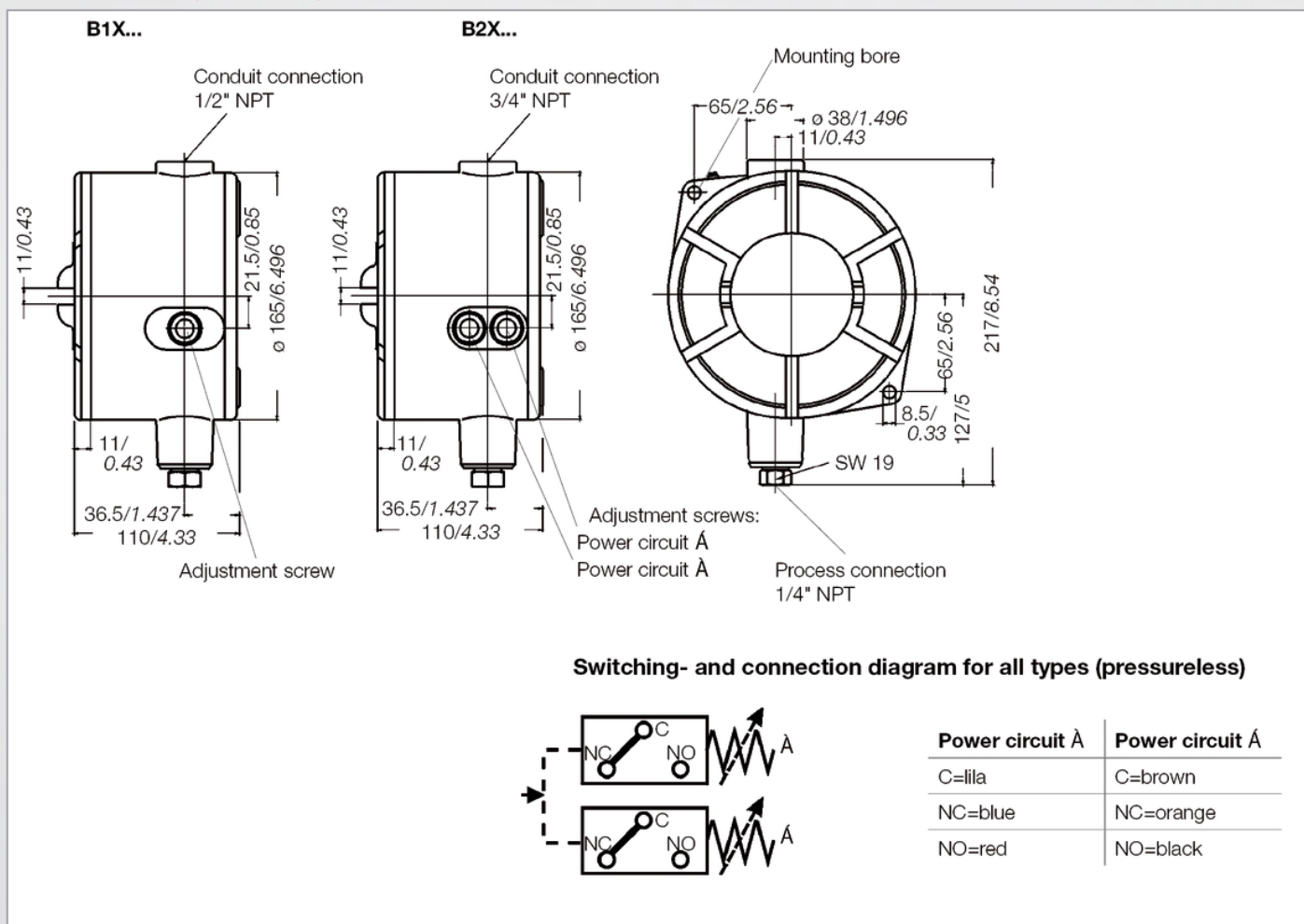

### Electrical Ratings

Micro switch	Special features	Volt AC 50/60 Hz	Ind. load A	Res. load A	Volt DC	Ind. load A	Res. load A	Comments
H	Micro switch with silver contacts	125 250 480*	10 10 3	10 10 3	6 to 24	0.50	0.5	Small hysteresis; High AC-/ low DC-load
M	Micro switch with silver contacts	125 250 480*	10 10 3	10 10 3	12 24 250*	5.00 1.00 0.25	15.0 2.0 0.4	Medium hysteresis; High AC- and DC-loads
GH	Micro switch with gold-plated contacts for low voltage and/ or low current	125	1	1	24	1.00	1.00	Small hysteresis
GM		30	0.1	0.1	30	0.10	0.1	Medium hysteresis

\* on request

### Approvals

EX	Ex d approval
UL	cULus approval
EXI	Ex i approval

### Order Code

Example for order number

Type	Micro switch	Pressure range code	Options	Approval
B1X or B2X	H	72SS	P2	UL

Your order number

Type	Micro switch	Pressure range code	Options	Approval

### Options

P2 = 1/2" NPT F SS Process connection