


Dimensions (mm / inch)

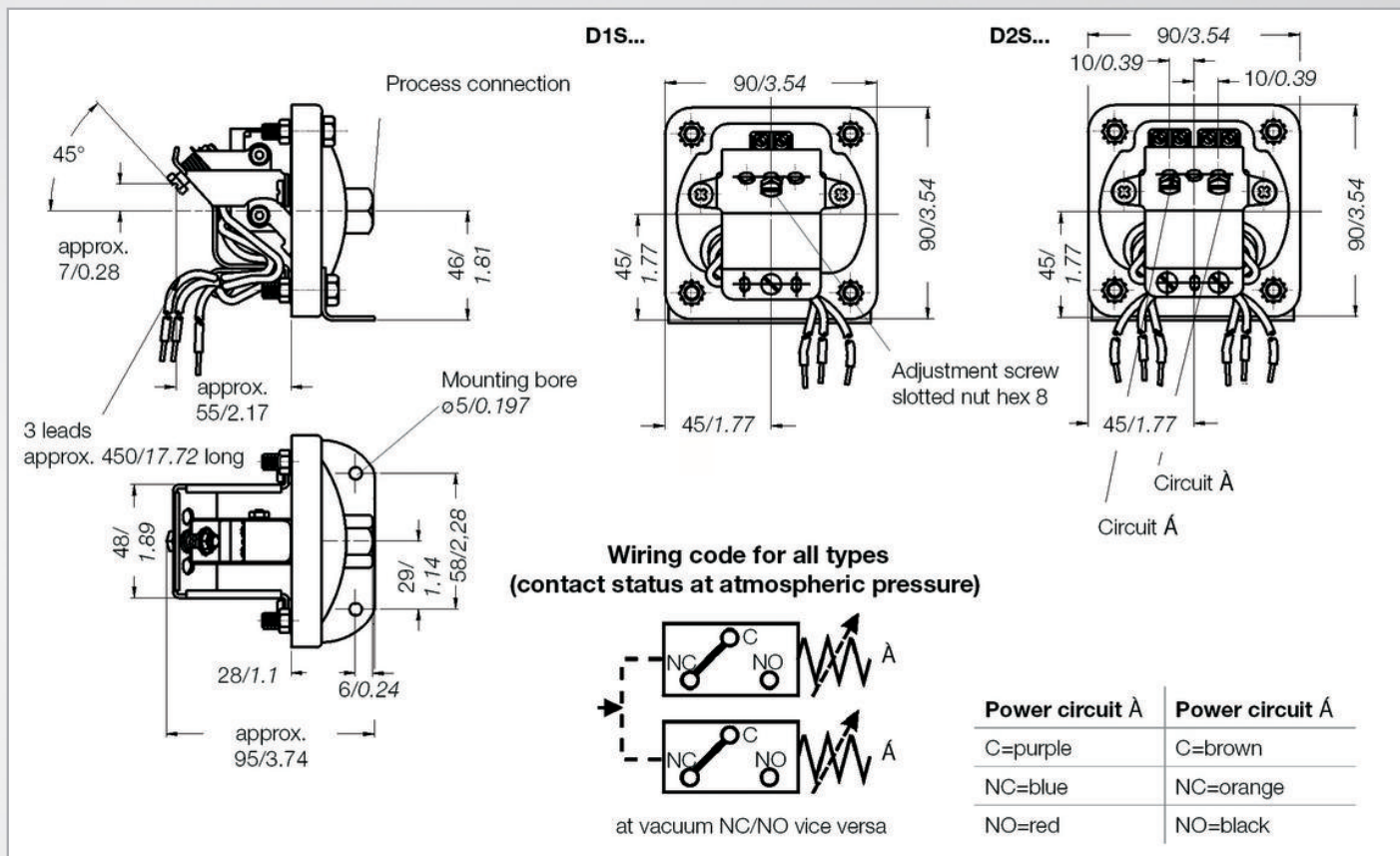

Electrical Ratings

Micro switch	Special features	Volt AC 50/60 Hz	Ind. load A	Res. load A	Volt DC	Ind. load A	Res. load A	Comments
H	Micro switch with silver contacts	125	10	10	6	0.50	0.5	Small hysteresis; High AC-/low DC-load
		250	10	10	to 24			
		480*	3	3				
M	Micro switch with silver contacts	125	10	10	12	5.00	15.0	Medium hysteresis; High AC- and DC-loads
		250	10	10	24	1.00	2.0	
		480*	3	3	250	0.25	0.4	
GH	Micro switch with gold contacts for low voltage and low current	125	1	1	24	1.00	1.00	Small hysteresis
GM		30	0.1	0.1	30	0.10	0.1	Medium hysteresis

Options

P2 = 1/2" NPT F SS Process connection

Order Code

Example for order number

Type	Micro switch	Pressure range code	Options
D1S or D2S	H	3SS	P2

Your order number

Type	Micro switch	Pressure range code	Options