


1" Pressure Regulator

Series 20415

Technical Drawings

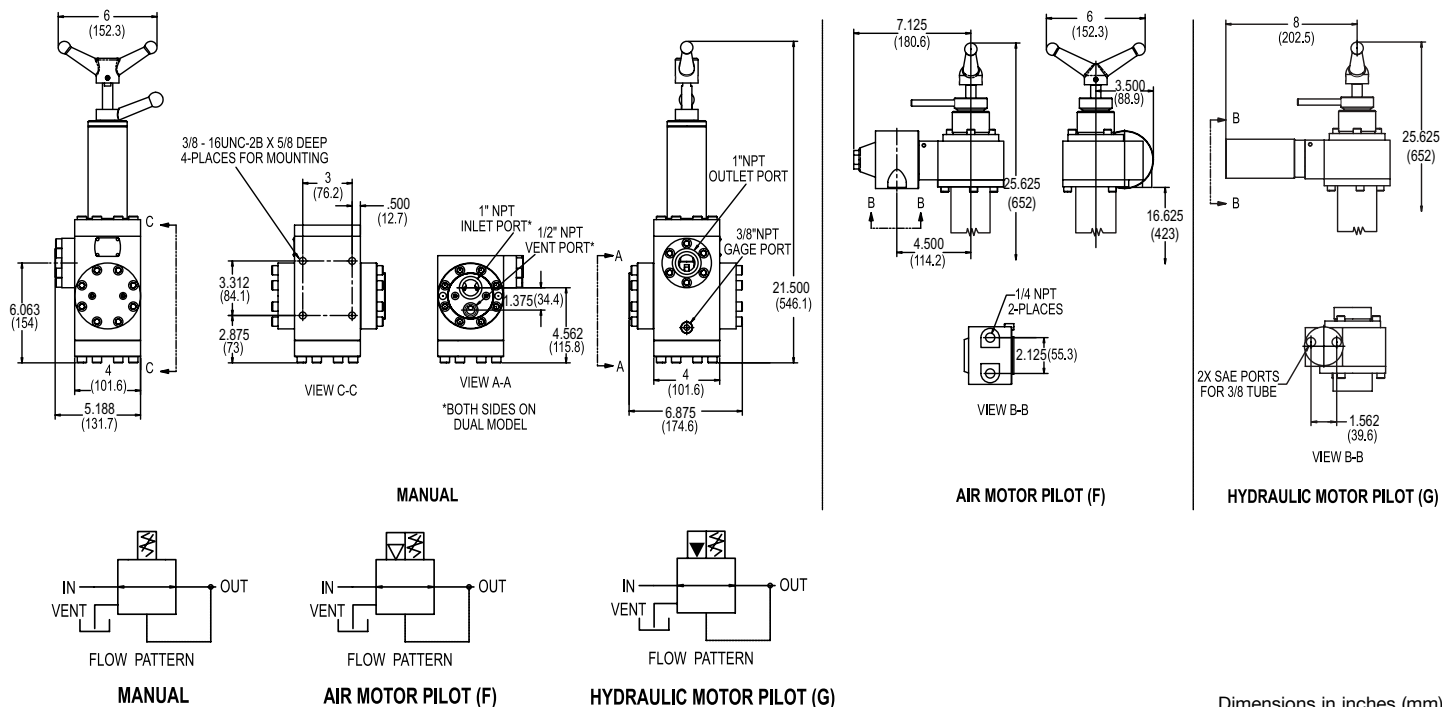

Product Configurator

Example:

20415S3WQ2

Adjustment Method

Blank	Manual
F	Pneumatic failsafe motor
G	Hydraulic failsafe motor

Series

20415S3WQ2	1" Pressure regulator (3/4" full flow regulator)
------------	---

Option

Blank	NPT porting
-MS	SAE porting
-SS	Stainless steel flanges & trim

Regulated Pressure Range (Manual)

Blank	High sensitivity	500 - 1600 psi (34 - 110 bar)
-1	Full range	500 - 2800 psi (34 - 193 bar)

Regulated Pressure Range (Failsafe) F & G Models

Blank	High sensitivity	500 - 1600 psi (34 - 110 bar)
-1	Full range	500 - 2800 psi (34 - 193 bar)

