


Safety Switches for Hinged Protective Equipment

SHS Cable Type A

Article number	Designation	Cable length	Connector type	Number of pins	Special feature
3251103234	AN-KAB.SH5 5M AC STRAIGHT	5 m	Straight	3	AC/DC BG version
3251103236	AN-KAB.SH5 5M AC ELBOW	5 m	Elbow	3	AC/DC BG version

Contact assignments, AC/DC versions

- 1 = Green/yellow
- 2 = Black
- 3 = Blue

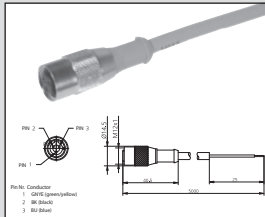


Core insulation / sheathing material:	PVC (UL)/PVC (UL)
Moulding / contact carrier material:	PUR (UL)/PUR (UL)
Max. rated voltage:	300 V AC
Max. current carrying capacity:	3 A
Min. / max. temperature range:	-25 °C / +70 °C
	-13 °F / +158 °F
Cable configuration mm ² :	3 x 0.5
Protection class when assembled:	IP67

SHS Cable Type B

Article number	Designation	Cable length	Connector type	Number of pins	Special feature
3251003221	AN-KAB.SH5 2M DC STRAIGHT	2 m	Straight	3	DC approval
3251003222	AN-KAB.SH5 5M DC STRAIGHT	5 m	Straight	3	DC approval
3251003223	AN-KAB.SH5 10M DC STRAIGHT	10 m	Straight	3	DC approval
3251003224	AN-KAB.SH5 2M DC ELBOW	2 m	Elbow	3	DC approval
3251003225	AN-KAB.SH5 5M DC ELBOW	5 m	Elbow	3	DC approval
3251003226	AN-KAB.SH5 10M DC ELBOW	10 m	Elbow	3	DC approval

Contact assignments, DC versions

- 1 = Brown
- 2 = -
- 3 = Blue
- 4 = Black

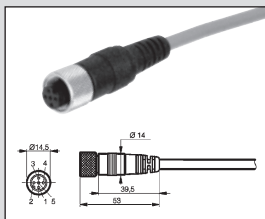


Core insulation / sheathing material:	PVC/PVC
Moulding / contact carrier material:	PUR/PUR
Max. rated voltage:	60 V AC/75 V DC
Max. current carrying capacity:	1.5 A
Min. / max. temperature range:	-25 °C / +70 °C
	-13 °F / +158 °F
Cable configuration mm ² :	3 x 0.34
Protection class when assembled:	IP67

SHS Cable Type C

Article number	Designation	Cable length	Connector type	Number of pins	Special feature
3251004219	AN-KAB.SH5 5M AC STRAIGHT	5 m	Straight	4	AC/DC-approval
3251004220	AN-KAB.SH5 5M AC ELBOW	5 m	Elbow	4	AC/DC-approval

Contact assignments, AC/DC versions

- 1 = Brown
- 2 = Black
- 3 = Blue
- 4 = Green/yellow

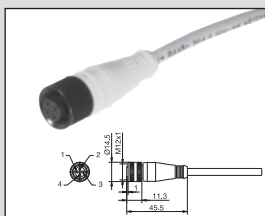

Core insulation / sheathing material:	PVC/PVC
Moulding / contact carrier material:	PUR/Nylon 6.6
Max. rated voltage:	300 V AC
Max. current carrying capacity:	4.0 A
Min. / max. temperature range:	-5 °C / +70 °C
	-13 °F / +158 °F
Cable configuration mm ² :	4 x 0.34
Protection class when assembled:	IP68