


PowerSTAR® 720 Series PMDC 12V right-angle gearmotor offers up to 442 in-lbs of torque running continuously for energy efficient operation in a sleek, compact profile. Uses a 32 Frame TENV PMDC motor with 36" cordset.



#### 720 Series PMDC 12V Gearmotor - TENV

Part Number	Speed (RPM)	Torque (in-lbs)	Input HP	Gear Ratio	OHL (lbs)	Amps
021-720A0010	180	35	1/8	10	270	11.6
021-720A0015	120	52	1/8	15	305	11.6
021-720A0020	90	70	1/8	20	330	11.6
021-720A0030	60	104	1/8	30	370	11.6
021-720A0040	45	139	1/8	40	400	11.6
021-720A0050	36	173	1/8	50	430	11.6
021-720A0060	30	208	1/8	60	455	11.6
021-720A0080	23	277	1/8	80	490	11.6
021-720A0100	18	346	1/8	100	525	11.6
021-720A0120	15	415	1/8	120	550	11.6
021-720A0150	12	277	1/15	150	635	6.5
021-720A0180	10	332	1/15	180	670	6.5
021-720A0240	7.5	442	1/15	240	725	6.5

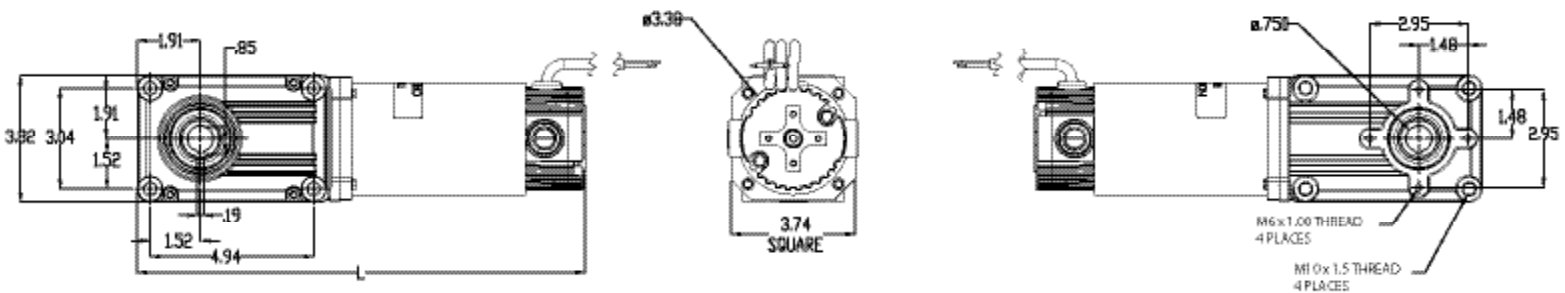

L  
L = Gearmotor length:  
1/8 HP: 13.57  
1/15 HP: 11.91

DC GEARMOTOR  
WHITE +LINE  
BLACK -LINE  
GREEN GROUND  
To reverse rotation interchange white and black leads