


## Raised Floor Systems

Compresses #8 AWG through 4/0 AWG cable.

### Signal Reference Grid Connector

- Clamps onto pedestal posts up to 1" diameter square and 1/4" round
- Can be used as an "X" or "T" configuration cable to post
- High-conductivity wrought-copper construction

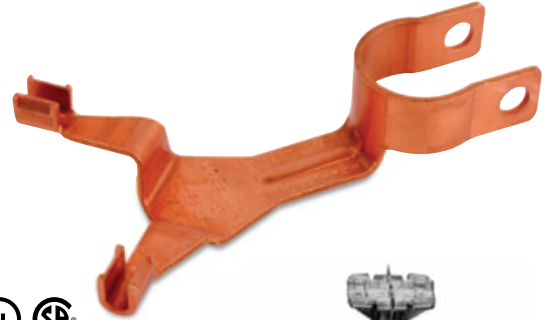

INSTALLING TOOLS AND DIE CODES  
TBM14M AND TBM15I

CAT. NO.	CONDUCTOR	DIE CAT. NO.	DIE CODE	COLOR CODE
SRG8-4	#8	15527	29	GRAY
	#6 to #4	15528	33	BROWN
SRG2-1	#2 & #1	15508	42	PINK
SRG10-20	1/0 & 2/0	15530	50	ORANGE
SRG30-40	3/0 & 4/0	15511	54	PURPLE



Secures signal reference grid wire to raised-floor support posts.

### Signal Reference Grid Clamp

- Range-taking design accepts #8 to #4 AWG grid wire and fits 1" round and 3/4" square trade size support posts
- Lay-in feature means no kinks or bends
- Quick, easy installation
- Only one screw to tighten
- Enables grid wire to make direct, low-resistance contact with support posts
- Stamped-steel construction, zinc plated



CAT. NO.	DESCRIPTION	WIRE RANGE
3900	3/4" square to 1" round	#8-#4
3900BP (BULK PACK)	3/4" square to 1" round	#8-#4

UL File No. E-3060.

Approved for grounding and bonding per UL 467.

## Ground Electrode Boxes

CAT. NO.	DESCRIPTION	WT./100 STANDARD		PACKAGE
		LB.	KG	
51628	Pregalvanized steel	1180	536.3	5
51629	Hot-dip galvanized	1200	545.4	5

14-gauge steel. 10" diameter, 12" depth.



## Ground Rod Accessories

Streamlined design reduces driving friction.

### Type C — Sectional Ground Rod Couplings

- Threaded couplings of high-strength, corrosion-resistant alloy
- Tapped for use on all standard threaded sectional rods



CAT. NO.	SIZE (NOMINAL DIAMETER)	THREAD SIZE
50C	½"	½"-13 UNS
50LC**	½" L	½"-12 UNS
60C**	⅝"	⅝"-11 UNS
70C*	¾"	¾"-10 UNS
80C*	1"	1"-8 UNS

\* UL Listed 467 (425H).

† CSA lists rods ½" and larger, 10' and longer.

‡ RUS Listed.



Use with all standard threaded couplings.

### Type DS — Driving Studs

- Made of high-strength steel
- Compatible with all standard threaded couplings



CAT. NO.	SIZE (NOMINAL DIAMETER)	THREAD SIZE
50DS	½"	½"-13 UNS
50LDS**	½" L	½"-12 UNS
60DS**	⅝"	⅝"-11 UNS
70DS*	¾"	¾"-10 UNS
80DS*	1"	1"-8 UNS

\* UL Listed 467 (425H).

† CSA lists rods ½" and larger, 10' and longer.

‡ REA Listed.



For joining non-threaded, copper-bonded steel ground rods.

### Threadless Couplings and Driving Cap

- Couplings manufactured of high-strength corrosion-resistant copper alloy
- High-strength hardened steel driving cap prevents "mushrooming" of ground rod while driving to ensure proper fit of coupling

CAT. NO.	DESCRIPTION	DIMENSIONS (IN.)	
		LENGTH	DIAMETER
50LCNT*	½" L threadless coupling	3.0	.78
60CNT2*	⅝" threadless coupling	2.5	.69
70CNT*	¾" threadless coupling	3.0	.97
60DSNT	⅝" threadless driving cap	4.0	.88

\* UL Listed.

