

Copper Mechanical Connectors

All the same features as the standard LOCKTITE® lug — with two or three barrels.

LOCKTITE® Double- and Triple-Barrel NEMA-Drilled Lugs for 600V Applications

- Screw tightening
- Serrated saddle
- Built-in lockwasher
- For use with code copper conductor (600V)

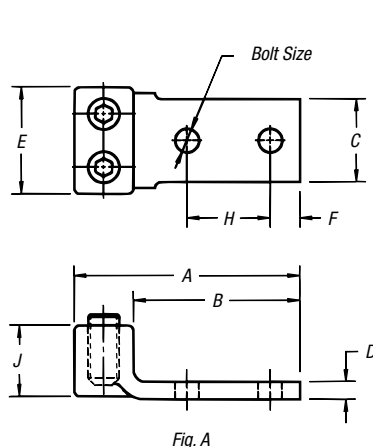


Fig. A

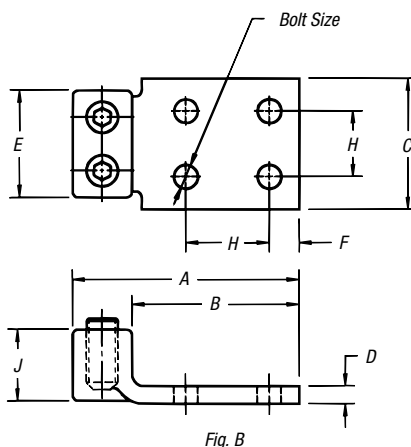


Fig. B

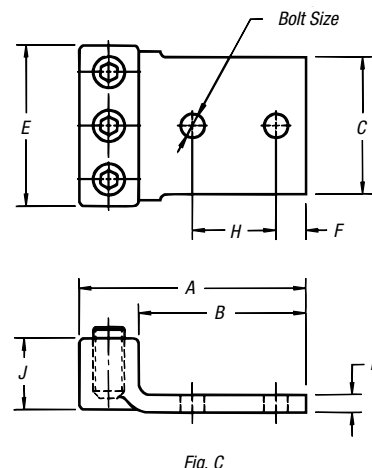


Fig. C

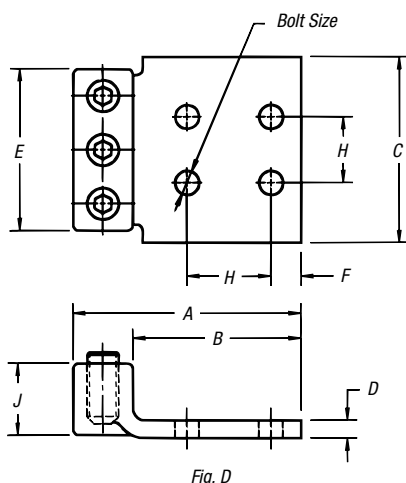


Fig. D



CAT. NO.	CABLE SIZE	FIG.	BOLT SIZE	DIMENSIONS (IN.)							
				A	B	C	D	E	F	H	J
32003BD ¹	14 to 8	A	¼	2 ¹ / ₁₆	1 ³ / ₄	¾	1/8	1 ¹ / ₁₆	9/32	¾	1 ⁵ / ₃₂
32005BD ¹	8 to 4	A	¼	2 ¹ / ₂	2	1	1/8	1	9/32	¾	1 ⁷ / ₃₂
32007BD	4 to 1	A	¾	2 ¹³ / ₁₆	2	1 ¹ / ₄	7/32	1 ¹ / ₄	7/16	1	29/32
32009BD	1 to 2/0	A	½	4 ⁷ / ₁₆	3 ¹ / ₂	1 ¹ / ₂	¼	1 ¹ / ₁₆	¾	1 ³ / ₄	1 ¹³ / ₃₂
32011BD	2/0 to 4/0	A	½	4 ⁵ / ₈	3 ¹ / ₂	1 ³ / ₄	9/32	1 ³ / ₄	¾	1 ³ / ₄	1 ⁵ / ₁₆
32013BD	4/0 to 300	A	½	4 ³ / ₄	3 ¹ / ₂	2	5/16	2 ¹ / ₈	¾	1 ³ / ₄	1 ¹ / ₁₆
32015BD	300 to 500	A	½	5 ⁵ / ₈	3 ¹⁵ / ₁₆	2 ¹ / ₂	1 ¹ / ₃₂	2 ¹ / ₂	¾	1 ³ / ₄	1 ¹³ / ₁₆
32017BD	500 to 700	B	½	5 ¹⁹ / ₃₂	4	4	1 ¹ / ₃₂	2 ¹⁵ / ₁₆	¾	1 ³ / ₄	2 ¹ / ₈
32019BD	750 to 1000	B	½	5 ²⁷ / ₃₂	4	4	1 ⁵ / ₃₂	3 ³ / ₄	¾	1 ³ / ₄	2 ¹¹ / ₃₂
32011TB	2/0 to 4/0	C	½	4 ⁵ / ₈	3 ³ / ₈	2 ¹ / ₂	9/32	2 ³ / ₄	¾	1 ³ / ₄	1 ⁵ / ₁₆
32013TB	4/0 to 300	C	½	4 ³ / ₄	3 ¹ / ₂	3	5/16	3 ³ / ₄	¾	1 ³ / ₄	1 ¹⁷ / ₃₂
32015TB	300 to 500	D	½	5 ⁵ / ₈	4	4	1 ¹ / ₃₂	3 ³ / ₄	¾	1 ³ / ₄	1 ¹³ / ₁₆
32017TB	500 to 750	D	½	5 ¹⁹ / ₃₂	4	4	1 ¹ / ₃₂	4 ⁵ / ₈	¾	1 ³ / ₄	2 ¹ / ₈
32019TB	750 to 1,000	D	½	5 ²⁷ / ₃₂	4	4	1 ⁵ / ₃₂	4 ¹¹ / ₁₆	¾	1 ³ / ₄	2 ¹¹ / ₃₂

¹With Fillister Head Screw.

For torque requirements, see page F-188.