
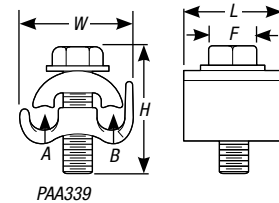


Parallel-Groove Connectors

High-strength, heat-treated cast aluminum alloy provides secure connections.

PAA One- and Two-Bolt Aluminum Parallel-Groove Clamps

- Galvanized steel carriage bolt, nut and lockwasher included
- Dual-rated for use on aluminum, ACSR and copper conductors
- Available prefilled with oxide inhibitor to prevent oxidation on copper-to-aluminum connections

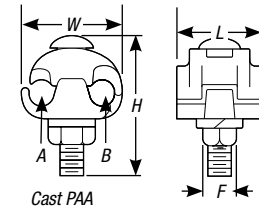

STANDARD CAT. NO.	PREFILLED CAT. NO.	CONDUCTOR RANGE				CONDUCTOR DIAMETER				DIMENSIONS (IN.)				BOLT SIZE
		MAIN		TAP		MAIN		TAP		F	H	L	W	
		ACSR	AL/CU	ACSR	AL/CU	MAX.	MIN.	MAX.	MIN.					
—	PAA29	#2-#6	#2 str.-#6 sol.	#2-#6	#2 str.-#6 sol.	.316	.162	.316	.162	9/16	1 13/32	1 13/32	1 3/8	3/8
—	PAA339	1/0-#6	1/0 str.-#6 sol.	1/0-#6	1/0 str.-#6 sol.	.398	.162	.398	.162	9/16	1 9/16	1 1/4	1 1/2	3/8
PAA4	PAA49	1/0-#6	1/0 str.-#6 sol.	1/0-#6	1/0 str.-#6 sol.	.398	.162	.398	.162	9/16	2 1/32	1 13/32	1 1/2	3/8
PAA5	PAA59	1/0-#8	1/0 str.-#8 sol.	1/0-#8	1/0 str.-#8 sol.	.398	.128	.398	.128	9/16	2 1/32	1 11/32	1 1/2	3/8
PAA6	PAA69	1/0-#8	2/0 str.-#8 sol.	1/0-#8	2/0 str.-#8 sol.	.414	.128	.414	.128	9/16	2 1/32	1 3/8	1 3/8	3/8
PAA10*	PAA109	336.4-1/0, 1/0-#6 AR	400-1/0 str., 1/0-#6 AR	1/0-#8	1/0 str.-#8 sol.	.741	.368	.398	.128	9/16	2 13/32	2	1 3/4	3/8
PAA12	PAA129	4/0-#2	4/0 str.-#2 sol.	4/0-#2	4/0 str.-#2 sol.	.563	.258	.563	.258	3/4	2 1/4	2	2	1/2
PAA400†	PAA4009†	336.4-1/0, 1/0-#6 AR	400-1/0 str., 1/0-#6 AR	336.4-1/0	400-1/0 str.	.741	.368	.741	.368	3/4	3 1/4	3 3/4	2 1/2	1/2

* RUS Listed.

† PAA400 and PAA4009 are two bolt clamps.


AR = Over armor rod.

Note: For hex-head bolt option, add "-3" suffix to the catalog number.

Our most corrosion-resistant groove clamp ever!

PAC Aluminum Parallel-Groove Clamps with Copper Liner

- Pressure-cast aluminum body effectively seals out moisture and resists corrosion
- Clamp separates conductors to reduce the possibility of galvanic corrosion

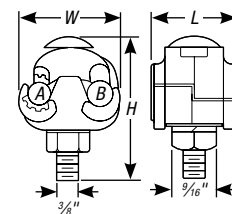

STANDARD CAT. NO.	PREFILLED CAT. NO.	CONDUCTOR RANGE			CONDUCTOR DIAMETER		DIMENSIONS (IN.)		
		MAIN		TAP	MAIN	TAP	H	W	L
		ACSR	AL	COPPER					
PAC345	PAC3459	1/0-#8	1/0 str.-#8 sol.	1/0 str.-#8 sol.	.398-.128	.373-.128	2 1/32	1 11/32	1 1/4
PAC7*	PAC79	336.4-1/0, 1/0-#6 AR	400-2/0 str., 1/0-#6 AR	1/0 str.-#8 sol.	.741-.398	.373-.128	2 13/32	1 3/8	1 3/8

* RUS Listed.

Note: For hex-head bolt option, add "-3" suffix to the catalog number.