





Actual

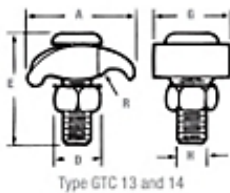

Type GTC 13 and 14

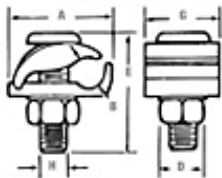

Type GTC 23 and 24

Line Art

Catalog Number: GTC14P
Product ID: 7TBA014260R0004
UPC Number: 78378630311
Status: Active

Tin Plated Copper Alloy Tower Ground Clamp for Wire Range 2/0 Stranded - 250kcmil, Width 1-15/32 Inches

North American Specifications (UNSPSC)

UNSPSC	39121613 Grounding devices or assemblies
IGCC	4909 Grounding devices or assemblies
Brand Name	Blackburn
Type	Tower Ground Clamp
Special Features	Bolt has square shank to prevent turning and allow clamp to be tightened with one wrench
Conductor Size	2/0 Str - 250 kcmil
Conductor Material	Copper Alloy
Insulation	Non-Insulated

European Specifications (ETIM)

ETIM	EC000511 Tube earthing clamp for lightning protection
Material	Copper
Surface protection	Other

Packaging

Inner Quantity	1
Outer Quantity	25
Outer Dimensions (inches)	1x1x1
Weight Uom	39.75 lbs. per 100

Documents / Support Tools

Technical Drawing / Data Sheet Canada Available on Website

For further technical assistance, please contact us...

Thomas & Betts - USA
 860 Ridge Lake Blvd.
 Memphis, TN 38120
 www.tnb.com

T&B Technical Support
 MS 3B-50
 860 Ridge Lake Blvd.
 Memphis, TN 38120

Hours: 7AM - 6PM CDT
 Monday-Friday
 Phone: (888) 862-3289
 Fax: (901) 252-1321
 Email: techsupport@tnb.com