





Actual

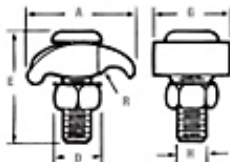

Type GTC 13 and 14

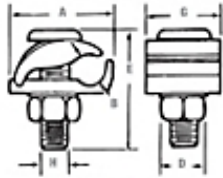

Type GTC 23 and 24

Line Art

**Catalog Number:** GTC13P  
**Product ID:** 7TBA014260R0002  
**UPC Number:** 78378647547  
**Status:** Active

Tin Plated Copper Alloy Tower Ground Clamp for Wire Range 4 Solid - 2/0 Stranded, Width 1-15/32 Inches

### North American Specifications (UNSPSC)

UNSPSC	39121613 Grounding devices or assemblies
IGCC	4909 Grounding devices or assemblies
Brand Name	Blackburn
Type	Tower Ground Clamp
Standard	CSA 12798
Conductor Size	4 Sol - 2/0 Str
Conductor Material	Copper Alloy
Insulation	N

### European Specifications (ETIM)

ETIM	EC000511 Tube earthing clamp for lightning protection
Material	Copper
Surface protection	Other

### Packaging

Inner Quantity	1
Outer Quantity	25
Outer Dimensions (inches)	1x1x1
Weight Uom	18.5 lbs. per 100

### Documents / Support Tools

Technical Drawing / Data Sheet Canada Available on Website

**For further technical assistance, please contact us...**

Thomas & Betts - USA  
 860 Ridge Lake Blvd.  
 Memphis, TN 38120  
 www.tnb.com

T&B Technical Support  
 MS 3B-50  
 860 Ridge Lake Blvd.  
 Memphis, TN 38120

Hours: 7AM - 6PM CDT  
 Monday-Friday  
 Phone: (888) 862-3289  
 Fax: (901) 252-1321  
 Email: techsupport@tnb.com