


Battery module **PVA**

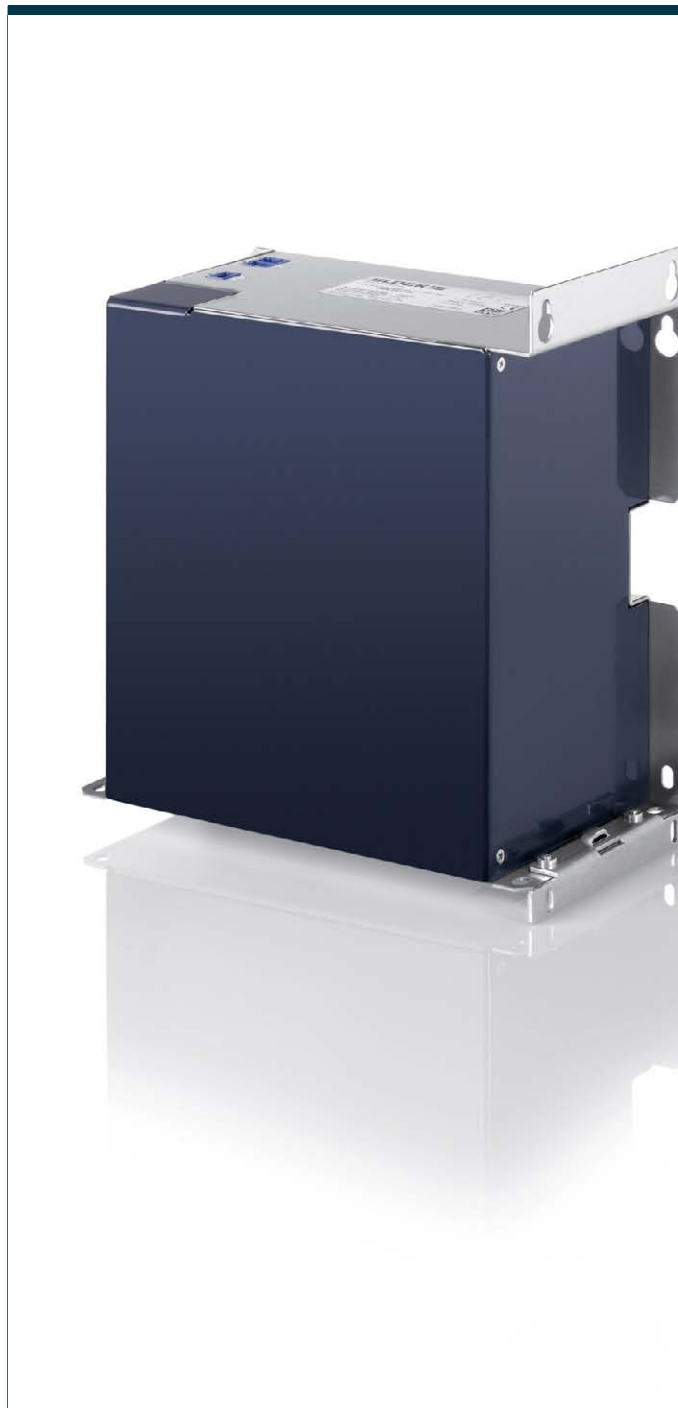

General Data

Input rated voltage 24 Vdc
Output rated voltage 24 Vdc
Capacity 3.2 - 12 Ah
Ambient temperature -10 °C to +40 °C
Protection index IP 20

Advantages

Automatic detection of connected battery module
Reliable early warning signal when battery life expectancy is declining
Extended life expectancy through temperature controlled battery management
Service-friendly spring-loaded connector system

 
Applications

Battery module for building a secure 24 Vdc power supply in case of power failure.

Approvals



UL 508 (E219022)



1.1

1.2

1.3

2.1

2.2

3.1

3.2

Dimension pictures



4.0

5.1

5.2