

# Laser Materials

## Laser Label Materials

Brady continues to stock the following laser toner printable labels.

### Laser Printer Sheets - General ID Label Sheets

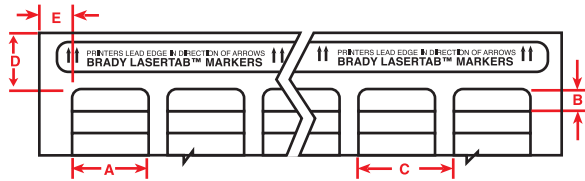


Fig. Laser-01

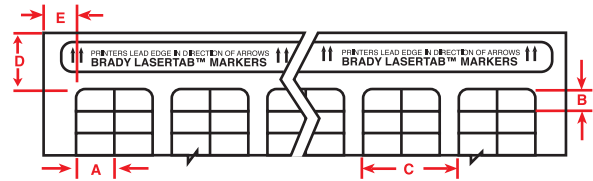


Fig. Laser-02

| Diagram  | Catalog #      | Material    | Color | Label Width A<br>Inch (mm) | Label Height B<br>Inch (mm) | Horizontal Repeat C<br>Inch (mm) | Horizontal Margin E<br>Inch (mm) | Top Margin F<br>Inch (mm) | Labels Per Row | Labels Per Sheet | Labels Per Pkg |
|----------|----------------|-------------|-------|----------------------------|-----------------------------|----------------------------------|----------------------------------|---------------------------|----------------|------------------|----------------|
| Laser-02 | LAT-26-747-10  | Polyester   | White | 0.250 (6.35)               | 0.250 (6.35)                | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 26             | 936              | 10,000         |
| Laser-02 | LAT-1-747-10   | Polyester   | White | 0.300 (7.62)               | 0.250 (6.35)                | 0.700 (17.78)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 22             | 836              | 10,000         |
| Laser-01 | LAT-2-747-10   | Polyester   | White | 0.375 (9.53)               | 0.375 (9.53)                | 0.500 (12.70)                    | 0.875 (22.23)                    | 0.313 (7.95)              | 16             | 400              | 10,000         |
| Laser-01 | LAT-45-707-10  | Polyester   | White | 0.500 (12.70)              | 0.375 (9.53)                | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 325              | 10,000         |
| Laser-01 | LAT-25-747-10  | Polyester   | White | 0.500 (12.70)              | 0.437 (11.10)               | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 286              | 10,000         |
| Laser-01 | LAT-46-707-10  | Polyester   | White | 0.500 (12.70)              | 0.500 (12.70)               | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 247              | 10,000         |
| Laser-01 | LAT-40-799-1   | Nylon Cloth | White | 0.500 (12.70)              | 0.750 (19.05)               | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 156              | 1,000          |
| Laser-01 | LAT-40-799-5   | Nylon Cloth | White | 0.500 (12.70)              | 0.750 (19.05)               | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 156              | 5,000          |
| Laser-01 | LAT-38-799-2.5 | Nylon Cloth | White | 0.500 (12.70)              | 1.437 (36.50)               | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 13             | 78               | 2,500          |
| Laser-01 | LAT-3-410-10   | Polyolefin  | White | 0.650 (16.51)              | 0.250 (6.35)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 380              | 10,000         |
| Laser-01 | LAT-3-747-10   | Polyester   | White | 0.650 (16.51)              | 0.250 (6.35)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 380              | 10,000         |
| Laser-01 | LAT-29-747-10  | Polyester   | White | 0.650 (16.51)              | 0.200 (5.08)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 480              | 10,000         |
| Laser-01 | LAT-29-799-10  | Nylon Cloth | White | 0.650 (16.51)              | 0.200 (5.08)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 480              | 10,000         |
| Laser-01 | LAT-4-410-10   | Polyolefin  | White | 0.800 (20.32)              | 0.250 (6.35)                | 1.000 (25.40)                    | 0.875 (22.23)                    | 0.350 (8.89)              | 8              | 304              | 10,000         |
| Laser-01 | LAT-4-747-10   | Polyester   | White | 0.800 (20.32)              | 0.250 (6.35)                | 1.000 (25.40)                    | 0.875 (22.23)                    | 0.350 (8.89)              | 8              | 304              | 10,000         |
| Laser-01 | LAT-5-747-10   | Polyester   | White | 0.800 (20.32)              | 0.500 (12.70)               | 1.000 (25.40)                    | 0.875 (22.23)                    | 0.350 (8.89)              | 8              | 152              | 10,000         |
| Laser-01 | LAT-5-759-10   | Paper       | White | 0.800 (20.32)              | 0.500 (12.70)               | 1.000 (25.40)                    | 0.875 (22.23)                    | 0.350 (8.89)              | 8              | 152              | 10,000         |
| Laser-01 | LAT-37-799-1   | Nylon Cloth | White | 0.800 (20.32)              | 1.437 (36.50)               | 0.900 (22.86)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 9              | 54               | 1,000          |
| Laser-01 | LAT-37-799-2.5 | Nylon Cloth | White | 0.800 (20.32)              | 1.437 (36.50)               | 0.900 (22.86)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 9              | 54               | 2,500          |
| Laser-01 | LAT-6-747-10   | Polyester   | White | 1.000 (25.40)              | 0.250 (6.35)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 266              | 10,000         |
| Laser-01 | LAT-8-707-10   | Polyester   | White | 1.000 (25.40)              | 0.375 (9.53)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 175              | 10,000         |
| Laser-01 | LAT-8-747-10   | Polyester   | White | 1.000 (25.40)              | 0.375 (9.53)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 175              | 10,000         |
| Laser-01 | LAT-8-799-10   | Nylon Cloth | White | 1.000 (25.40)              | 0.375 (9.53)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 175              | 10,000         |
| Laser-01 | LAT-7-410-10   | Polyolefin  | White | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-7-707-10   | Polyester   | White | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-7-747-10   | Polyester   | White | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-7-799-10   | Nylon Cloth | White | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-39-799-1   | Nylon Cloth | White | 1.000 (25.40)              | 1.437 (36.50)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 7              | 42               | 1,000          |
| Laser-01 | LAT-39-799-2.5 | Nylon Cloth | White | 1.000 (25.40)              | 1.437 (36.50)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 7              | 42               | 2,500          |
| Laser-01 | LAT-9-747-10   | Polyester   | White | 1.500 (38.10)              | 0.250 (6.35)                | 1.600 (40.64)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 5              | 190              | 10,000         |
| Laser-01 | LAT-9-799-10   | Nylon Cloth | White | 1.500 (38.10)              | 0.250 (6.35)                | 1.600 (40.64)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 5              | 190              | 10,000         |
| Laser-01 | LAT-41-707-10  | Polyester   | White | 1.500 (38.10)              | 0.375 (9.53)                | 1.600 (40.64)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 5              | 125              | 10,000         |
| Laser-01 | LAT-47-707-10  | Polyester   | White | 1.500 (38.10)              | 0.500 (12.70)               | 1.600 (40.64)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 5              | 100              | 10,000         |
| Laser-01 | LAT-10-747-10  | Polyester   | White | 1.875 (47.63)              | 0.250 (6.35)                | 2.000 (50.80)                    | 0.875 (22.23)                    | 0.314 (7.98)              | 4              | 156              | 10,000         |
| Laser-01 | LAT-11-747-5   | Polyester   | White | 1.875 (47.63)              | 0.375 (9.53)                | 2.000 (50.80)                    | 0.875 (22.23)                    | 0.310 (7.87)              | 4              | 100              | 5,000          |
| Laser-01 | LAT-13-410-2.5 | Polyolefin  | White | 1.875 (47.63)              | 0.833 (21.16)               | 2.000 (50.80)                    | 0.834 (21.18)                    | 0.310 (7.87)              | 4              | 44               | 2,500          |
| Laser-01 | LAT-13-747-2.5 | Polyester   | White | 1.875 (47.63)              | 0.833 (21.16)               | 2.000 (50.80)                    | 0.834 (21.18)                    | 0.310 (7.87)              | 4              | 44               | 2,500          |
| Laser-01 | LAT-13-759-2.5 | Paper       | White | 1.875 (47.63)              | 0.833 (21.16)               | 2.000 (50.80)                    | 0.834 (21.18)                    | 0.310 (7.87)              | 4              | 44               | 2,500          |
| Laser-01 | LAT-14-747-1.5 | Polyester   | White | 1.875 (47.63)              | 1.330 (33.78)               | 2.000 (50.80)                    | 0.834 (21.18)                    | 0.315 (8.00)              | 4              | 28               | 1,500          |
| Laser-01 | LAT-31-747-1   | Polyester   | White | 2.000 (50.80)              | 0.900 (22.86)               | 2.800 (71.12)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 30               | 1,000          |
| Laser-01 | LAT-33-707-1   | Polyester   | White | 2.000 (50.80)              | 1.437 (36.50)               | 2.800 (71.12)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 18               | 1,000          |
| Laser-01 | LAT-33-747-1   | Polyester   | White | 2.000 (50.80)              | 1.437 (36.50)               | 2.800 (71.12)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 18               | 1,000          |
| Laser-01 | LAT-21-707-1   | Polyester   | White | 2.500 (63.50)              | 1.000 (25.40)               | 2.600 (66.04)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 27               | 1,000          |
| Laser-01 | LAT-21-747-1   | Polyester   | White | 2.500 (63.50)              | 1.000 (25.40)               | 2.600 (66.04)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 27               | 1,000          |

## Laser Printer Sheets - General ID Label Sheets (cont.)

| Diagram  | Catalog #         | Material             | Color  | Label Width A<br>Inch (mm) | Label Height B<br>Inch (mm) | Horizontal Repeat C<br>Inch (mm) | Horizontal Margin E<br>Inch (mm) | Top Margin F<br>Inch (mm) | Labels Per Row | Labels Per Sheet | Labels Per Pkg |
|----------|-------------------|----------------------|--------|----------------------------|-----------------------------|----------------------------------|----------------------------------|---------------------------|----------------|------------------|----------------|
| Laser-01 | LAT-12-747-2.5    | Polyester            | White  | 3.000 (76.20)              | 0.375 (9.53)                | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 50               | 2,500          |
| Laser-01 | LAT-32-747-1      | Polyester            | White  | 3.000 (76.20)              | 0.900 (22.86)               | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 20               | 1,000          |
| Laser-01 | LAT-32-759-1      | Paper                | White  | 3.000 (76.20)              | 0.900 (22.86)               | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 20               | 1,000          |
| Laser-01 | LAT-34-707-1      | Polyester            | White  | 3.000 (76.20)              | 1.437 (36.50)               | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 12               | 1,000          |
| Laser-01 | LAT-34-747-1      | Polyester            | White  | 3.000 (76.20)              | 1.437 (36.50)               | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 18               | 1,000          |
| Laser-01 | LAT-34-759-1      | Paper                | White  | 3.000 (76.20)              | 1.437 (36.50)               | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 18               | 1,000          |
| Laser-01 | LAT-44-707-2.5    | Polyester            | White  | 3.600 (91.44)              | 0.375 (9.53)                | -                                | 0.650 (16.51)                    | 0.875 (22.23)             | 2              | 40               | 2,500          |
| Laser-02 | LAT-26-652-10     | Polyimide            | Amber  | 0.250 (6.35)               | 0.250 (6.35)                | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 26             | 936              | 10,000         |
| Laser-02 | LAT-1-652-10      | Polyimide            | Amber  | 0.300 (7.62)               | 0.250 (6.35)                | 0.700 (17.78)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 22             | 836              | 10,000         |
| Laser-01 | LAT-2-652-10      | Polyimide            | Amber  | 0.375 (9.53)               | 0.375 (9.53)                | 0.500 (12.70)                    | 0.875 (22.23)                    | 0.313 (7.95)              | 16             | 400              | 10,000         |
| Laser-01 | LAT-25-652-10     | Polyimide            | Amber  | 0.500 (12.70)              | 0.437 (11.10)               | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 286              | 10,000         |
| Laser-01 | LAT-3-652-10      | Polyimide            | Amber  | 0.650 (16.51)              | 0.250 (6.35)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 380              | 10,000         |
| Laser-01 | LAT-29-652-10     | Polyimide            | Amber  | 0.650 (16.51)              | 0.200 (5.08)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 480              | 10,000         |
| Laser-01 | LAT-4-652-10      | Polyimide            | Amber  | 0.800 (20.32)              | 0.250 (6.35)                | 1.000 (25.40)                    | 0.875 (22.23)                    | 0.350 (8.89)              | 8              | 304              | 10,000         |
| Laser-01 | LAT-5-652-10      | Polyimide            | Amber  | 0.800 (20.32)              | 0.500 (12.70)               | 1.000 (25.40)                    | 0.875 (22.23)                    | 0.350 (8.89)              | 8              | 152              | 10,000         |
| Laser-01 | LAT-6-652-10      | Polyimide            | Amber  | 1.000 (25.40)              | 0.250 (6.35)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 266              | 10,000         |
| Laser-01 | LAT-8-652-10      | Polyimide            | Amber  | 1.000 (25.40)              | 0.375 (9.53)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 175              | 10,000         |
| Laser-01 | LAT-7-652-10      | Polyimide            | Amber  | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-9-652-10      | Polyimide            | Amber  | 1.500 (38.10)              | 0.250 (6.35)                | 1.600 (40.64)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 5              | 190              | 10,000         |
| Laser-01 | LAT-10-652-10     | Polyimide            | Amber  | 1.875 (47.63)              | 0.250 (6.35)                | 2.000 (50.80)                    | 0.875 (22.23)                    | 0.314 (7.98)              | 4              | 156              | 10,000         |
| Laser-01 | LAT-12-652-2.5    | Polyimide            | Amber  | 3.000 (76.20)              | 0.375 (9.53)                | 3.200 (81.28)                    | 0.875 (22.23)                    | 1.150 (29.21)             | 2              | 50               | 2,500          |
| Laser-01 | LAT-7-773-10      | Metallized Polyester | Silver | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-20-773-2.5    | Metallized Polyester | Silver | 1.500 (38.10)              | 0.750 (19.05)               | 1.600 (40.64)                    | 0.875 (22.23)                    | 0.250 (6.35)              | 5              | 60               | 2,500          |
| Laser-01 | LAT-21-773-1      | Metallized Polyester | Silver | 2.500 (63.50)              | 1.000 (25.40)               | 2.600 (66.04)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 27               | 1,000          |
| Laser-01 | LAT-29-747-10-YL  | Polyester            | Yellow | 0.650 (16.51)              | 0.200 (5.08)                | 0.800 (20.32)                    | 0.875 (22.23)                    | 0.325 (8.26)              | 10             | 480              | 10,000         |
| Laser-01 | LAT-7-747-10-YL   | Polyester            | Yellow | 1.000 (25.40)              | 0.500 (12.70)               | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 133              | 10,000         |
| Laser-01 | LAT-13-747-2.5-YL | Polyester            | Yellow | 1.875 (47.63)              | 0.833 (21.16)               | 2.000 (50.80)                    | 0.834 (21.18)                    | 0.310 (7.87)              | 4              | 44               | 2,500          |
| Laser-01 | LAT-21-747-1-YL   | Polyester            | Yellow | 2.500 (63.50)              | 1.000 (25.40)               | 2.600 (66.04)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 3              | 27               | 1,000          |
| Laser-01 | LAT-175-124-YL    | Paper                | Yellow | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-BL    | Paper                | Blue   | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-PL    | Paper                | Purple | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-BR    | Paper                | Brown  | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-GR    | Paper                | Green  | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-GY    | Paper                | Gray   | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-OR    | Paper                | Orange | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |
| Laser-01 | LAT-175-124-RD    | Paper                | Red    | 3.062 (77.77)              | 0.500 (12.70)               | 0.500 (12.70)                    | 0.938 (23.83)                    | 1.118 (30.18)             | 2              | 38               | 380            |

## Laser Printer Sheets - PermaShield™ Label Sheets

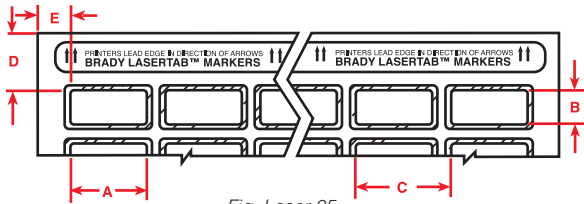


Fig. Laser-05

| Diagram  | Catalog #      | Material             | Color  | Label Width A<br>Inch (mm) | Label Height B<br>Inch (mm) | Horizontal Repeat C<br>Inch (mm) | Horizontal Margin E<br>Inch (mm) | Top Margin F<br>Inch (mm) | Labels Per Row | Labels Per Sheet | Labels Per Pkg |
|----------|----------------|----------------------|--------|----------------------------|-----------------------------|----------------------------------|----------------------------------|---------------------------|----------------|------------------|----------------|
| Laser-05 | LAT-23-747-2.5 | Polyester            | White  | 1.000 (25.40)              | 0.500 (12.70)               | 1.350 (34.29)                    | 1.000 (25.40)                    | 0.275 (6.99)              | 6              | 60               | 2,500          |
| Laser-05 | LAT-24-747-1   | Polyester            | White  | 1.750 (44.45)              | 1.000 (25.40)               | 2.200 (55.88)                    | 1.000 (25.40)                    | 1.175 (29.85)             | 3              | 21               | 1,000          |
| Laser-05 | LAT-23-773-2.5 | Metallized Polyester | Silver | 1.000 (25.40)              | 0.500 (12.70)               | 1.350 (34.29)                    | 1.000 (25.40)                    | 0.275 (6.99)              | 6              | 60               | 2,500          |
| Laser-05 | LAT-24-773-1   | Metallized Polyester | Silver | 1.750 (44.45)              | 1.000 (25.40)               | 2.200 (55.88)                    | 1.000 (25.40)                    | 1.175 (29.85)             | 3              | 21               | 1,000          |

## Laser Printer Sheets - Self-Laminating Labels

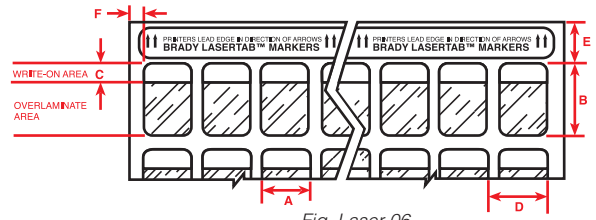


Fig. Laser-06

| Diagram  | Catalog #      | Material  | Color       | Label Width A<br>Inch (mm) | Label Height B<br>Inch (mm) | Print-On Area C<br>Inch (mm) | Horizontal Repeat D<br>Inch (mm) | Horizontal Margin E<br>Inch (mm) | Top Margin F<br>Inch (mm) | Labels Per Row | Labels Per Sheet | Labels Per Pkg |
|----------|----------------|-----------|-------------|----------------------------|-----------------------------|------------------------------|----------------------------------|----------------------------------|---------------------------|----------------|------------------|----------------|
| Laser-06 | LAT-15-361-1   | Polyester | White/Clear | 0.500 (12.70)              | 0.750 (19.05)               | 0.370 (9.40)                 | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 156              | 1,000          |
| Laser-06 | LAT-15-361-5   | Polyester | White/Clear | 0.500 (12.70)              | 0.750 (19.05)               | 0.370 (9.40)                 | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 156              | 5,000          |
| Laser-06 | LAT-48-361-1   | Polyester | White/Clear | 0.500 (12.70)              | 1.000 (25.40)               | 0.375 (9.53)                 | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 117              | 1,000          |
| Laser-06 | LAT-49-361-1   | Polyester | White/Clear | 0.500 (12.70)              | 1.250 (31.75)               | 0.500 (12.70)                | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 91               | 1,000          |
| Laser-06 | LAT-22-361-5   | Polyester | White/Clear | 0.500 (12.70)              | 1.500 (38.10)               | 0.500 (12.70)                | 0.600 (15.24)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 13             | 78               | 5,000          |
| Laser-06 | LAT-56-361-2.5 | Polyester | White/Clear | 0.600 (15.24)              | 1.625 (41.28)               | 1.000 (25.40)                | 1.725 (43.82)                    | 0.875 (22.23)                    | 0.850 (21.59)             | 4              | 64               | 2,500          |
| Laser-06 | LAT-59-361-2.5 | Polyester | White/Clear | 0.600 (15.24)              | 2.625 (66.68)               | 1.000 (25.40)                | 2.725 (69.22)                    | 0.875 (22.23)                    | 0.213 (5.41)              | 3              | 48               | 2,500          |
| Laser-06 | LAT-50-361-1   | Polyester | White/Clear | 0.750 (19.05)              | 1.000 (25.40)               | 0.375 (9.53)                 | 0.850 (21.59)                    | 0.875 (22.23)                    | 0.475 (12.07)             | 9              | 81               | 1,000          |
| Laser-06 | LAT-51-361-1   | Polyester | White/Clear | 0.750 (19.05)              | 1.500 (38.10)               | 0.500 (12.70)                | 0.850 (21.59)                    | 0.875 (22.23)                    | 0.475 (12.07)             | 9              | 54               | 1,000          |
| Laser-06 | LAT-16-361-5   | Polyester | White/Clear | 1.000 (25.40)              | 0.750 (19.05)               | 0.340 (8.64)                 | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 84               | 5,000          |
| Laser-06 | LAT-16-361-1   | Polyester | White/Clear | 1.000 (25.40)              | 0.750 (19.05)               | 0.340 (8.64)                 | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 84               | 1,000          |
| Laser-06 | LAT-17-361-2.5 | Polyester | White/Clear | 1.000 (25.40)              | 1.000 (25.40)               | 0.340 (8.64)                 | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 63               | 2,500          |
| Laser-06 | LAT-17-361-1   | Polyester | White/Clear | 1.000 (25.40)              | 1.000 (25.40)               | 0.340 (8.64)                 | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 63               | 1,000          |
| Laser-06 | LAT-18-361-1   | Polyester | White/Clear | 1.000 (25.40)              | 1.330 (33.78)               | 0.500 (12.70)                | 1.100 (27.94)                    | 0.834 (21.18)                    | 0.450 (11.43)             | 7              | 49               | 1,000          |
| Laser-06 | LAT-18-361-2.5 | Polyester | White/Clear | 1.000 (25.40)              | 1.330 (33.78)               | 0.500 (12.70)                | 1.100 (27.94)                    | 0.834 (21.18)                    | 0.450 (11.43)             | 7              | 49               | 2,500          |
| Laser-06 | LAT-39-361-1   | Polyester | White/Clear | 1.000 (25.40)              | 1.437 (36.50)               | 0.500 (12.70)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.300 (7.62)              | 7              | 42               | 1,000          |
| Laser-06 | LAT-58-361-1   | Polyester | White/Clear | 1.000 (25.40)              | 2.625 (66.68)               | 1.000 (25.40)                | 1.100 (27.94)                    | 0.875 (22.23)                    | 0.450 (11.43)             | 7              | 21               | 1,000          |
| Laser-06 | LAT-19-361-1   | Polyester | White/Clear | 1.000 (25.40)              | 3.167 (80.44)               | 0.970 (24.64)                | 1.100 (27.94)                    | 0.834 (21.18)                    | 0.450 (11.43)             | 7              | 21               | 1,000          |
| Laser-06 | LAT-35-361-2.5 | Polyester | White/Clear | 1.200 (30.48)              | 1.500 (38.10)               | 0.500 (12.70)                | 1.270 (32.23)                    | 0.875 (22.23)                    | 0.400 (10.16)             | 6              | 36               | 2,500          |
| Laser-06 | LAT-52-361-1   | Polyester | White/Clear | 1.500 (38.10)              | 1.000 (25.40)               | 0.375 (9.53)                 | 0.875 (22.23)                    | 0.300 (7.62)                     | 0.300 (7.62)              | 5              | 45               | 1,000          |
| Laser-06 | LAT-53-361-1   | Polyester | White/Clear | 1.500 (38.10)              | 1.500 (38.10)               | 0.500 (12.70)                | 1.600 (40.64)                    | 0.300 (7.62)                     | 0.300 (7.62)              | 5              | 30               | 1,000          |
| Laser-06 | LAT-54-361-1   | Polyester | White/Clear | 1.750 (44.45)              | 1.000 (25.40)               | 0.375 (9.53)                 | 0.875 (22.23)                    | 0.600 (15.24)                    | 0.600 (15.24)             | 4              | 36               | 1,000          |
| Laser-06 | LAT-55-361-1   | Polyester | White/Clear | 1.750 (44.45)              | 1.500 (38.10)               | 0.375 (9.53)                 | 0.875 (22.23)                    | 0.600 (15.24)                    | 0.600 (15.24)             | 4              | 24               | 1,000          |
| Laser-06 | LAT-27-361-1   | Polyester | White/Clear | 1.875 (47.63)              | 3.167 (80.44)               | 0.968 (24.59)                | 2.000 (50.80)                    | 0.875 (22.23)                    | 0.215 (5.46)              | 4              | 12               | 1,000          |

## Laser Printer Sheets - Non-Die-Cut Sheets

| Catalog #         | Material             | Color  | Label Width A<br>Inch (mm) | Label Height B<br>Inch (mm) | Labels Per Sheet | Labels Per Pkg |
|-------------------|----------------------|--------|----------------------------|-----------------------------|------------------|----------------|
| LAT-28-747-25-SH  | Polyester            | White  | 8.500 (215.90)             | 11.000 (279.40)             | 1                | 25 Sheets      |
| LAT-28-773-25-SH  | Metallized Polyester | Silver | 8.500 (215.90)             | 11.000 (279.40)             | 1                | 25 Sheets      |
| LAT-28-747Y-25-SH | Polyester            | Yellow | 8.500 (215.90)             | 11.000 (279.40)             | 1                | 25 Sheets      |