



Metal Ball Seals

- Supplied with embossed consecutive numbering (factory specified) and the word SEALED
- Available with or without rolled edges to help prevent accidental cuts


Catalog #	Description	Qty.
95197	Metal Ball Seals	100
95198	Rolled Edge Metal Ball Seals	100



Bradylock™ Fastener

- Self-locking heavy duty plastic fastener for Strap-On Markers
- Excellent chemical resistance

Catalog #	Description	Size
41772	Bradylock Fastener	0.5 in. x 150 ft.

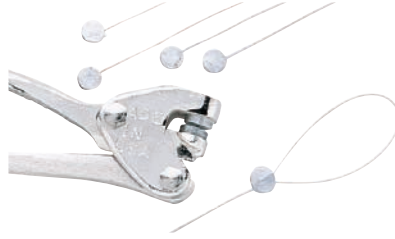

Lead Seals and Press

- 12 in. wire with pre-fitted lead seals fit easily around pipes or valves
- Quickly and permanently crimp your lead seals with Brady's own hand sealer.


Catalog #	Material	Size	Qty.
23301	Copper	12 in. length 31 gauge 7/16 in. dia.	250
23302	Monel Lead	12 in. length 31 gauge 7/16 in. dia.	250
23300	Hand Sealing Press		1



Plastic Truck Seals

- Deters entry, yet easily removed
- Tamper-resistant truck seals are embossed with the word SEAL and are consecutively numbered
- Ships in mats of ten for convenience and accountability; 100 seals total

Catalog #	Size	Color	Qty.
95193	7.5 in.	Blue	100
95195	7.5 in.	Red	100
95196	7.5 in.	Yellow	100
133487	7.5 in.	Green	100
133488	7.5 in.	Orange	100

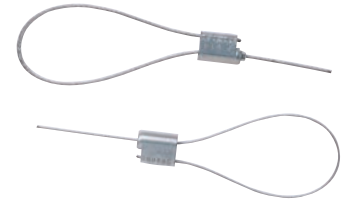

Cable Lock Seals

- Heavy steel seals have a steel head with 6 serialized numbers for inventory or tracking
- Factory chooses the starting number

Catalog #	Description	Tensile Strength	Qty.
95166	12 in. x 1/16 in.	727 lbs.	100
95167	12 in. x 3/32 in.	727 lbs.	100




Padlock Plastic Seals

- Made of durable polypropylene with galvanized wire hasps
- Seal body will blush if tampered with
- Heat stamped with SEAL and a 7-digit sequence number (factory specified)

Catalog #	Color	Qty.
95168	Black	100/pk*
95174	White	100/pk*
95173	Red	100/pk*
95172	Orange	100/pk*
95170	Gray	100/pk*
95171	Green	100/pk*
95169	Blue	100/pk*
95175	Yellow	100/pk*

* Minimum order: 5pks

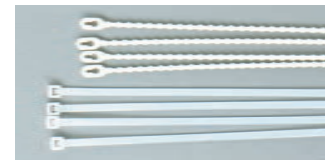

Nylon Fasteners

- Nylon fastener styles available to meet every application

Catalog #	Description	Qty.
81761	8 in. Reusable Beaded Ties	100/pk
81762	7 in. Nylon Fasteners	100/pk



Colored Nylon Ties

- Easily secure valve tags

Catalog #	Description	Length	Qty.
98848	Black	8 in.	100
98850	Green	8 in.	100
98853	Purple	8 in.	100
98851	Natural	8 in.	100
98854	Red	8 in.	100
98855	Yellow	8 in.	100
98849	Blue	8 in.	100



Quik-Applied™ Nylon Straps

- Can be used with a variety of tags including valve and lockout tags

Catalog #	Strap Length	Qty
91165	6 in.	10/pk
91166	7 in.	10/pk



Stainless Steel Wire

- 32 mil stainless steel safety wire
- Recommend to be used with wire twister pliers

Catalog #	Description	Length
15424	Stainless Steel Safety Wire	1,800 ft



Stainless Steel Strapping

- Type 316 Stainless Steel Strapping is highly corrosion and heat resistant


Catalog #	Description	Qty
42331	0.25 in. Stainless Steel Strapping	100 ft.
42332	0.25 in. Stainless Steel Strapping	250 ft.



Banding Heads

- Use with 0.25 in. continuous stainless steel strapping to create secure closures


Catalog #	Description	Qty.
90910	Stainless Steel Banding Heads	100

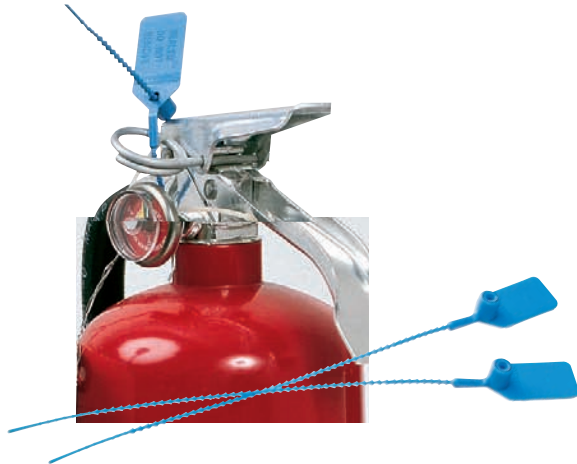

Pull-Tite Seals

- One of the few security seals approved for use by Underwriter's Laboratories (UL) for fire extinguishers and safety doors
- Ideal for use with courier pouches, canisters or cabinets that contain valuables or sensitive documents
- Pull-Tite Seals are embossed SEALED DO NOT REMOVE
- Breaking strength of 10-14 pounds

Catalog #	Size	Color	Qty.
UL approved for fire extinguishers and safety doors			
95150	9 in.	Red	100
95155	9 in.	Yellow	100
95143	9 in.	Light Blue	100
95144	9 in.	Green	100
95141	9 in.	Black	100
Non-UL approved			
133485	9 in.	Orange	100
133482	9 in.	Red	100
133483	9 in.	Yellow	100
133484	9 in.	Light Blue	100
133481	9 in.	Green	100
133486	9 in.	White	100

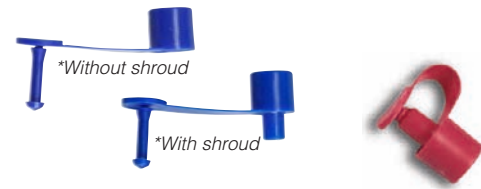

Ring-Loc Drum™ Seals

- Specifically designed to ensure fiber drum integrity
- Available in two materials:
Nylon which affords greater strength
Polypropylene will blush if tampered
- Hand applied seals can be removed with a simple cutting tool


Catalog #	Description	Color	Qty.
Nylon			
95158	Nylon w/ Shroud	Blue	100
95159	Nylon w/o Shroud	Blue	100
95161	Nylon w/ Shroud	Red	100
95160	Nylon w/o Shroud	Red	100
Polypropylene			
95162	Polypropylene w/ Shroud	Blue	100
95163	Polypropylene w/o Shroud	Blue	100
95164	Polypropylene w/ Shroud	Red	100
95165	Polypropylene w/o Shroud	Red	100



SecurAlert™ Clip-On Badges

- Low cost clip-on alternative to self-adhesive badges
- 3 in. x 3 in. slotted cards
- 500 front and back sets per pack

	Visitor	Contractor	Temporary
Badge expires after 1 day			
Red	95643	95653	95663
Blue	95644	95654	95664
Yellow	95645	95655	95665
Green	95646	95656	95666
White	95647	95657	95667
Badge expires after 1 week			
Red	95648	95658	95668
Blue	95649	95659	95669
Yellow	95650	95660	95670
Green	95651	95661	95671
White	95652	95662	95672

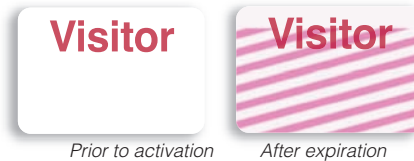


Prior to activation

After expiration

One Step SecurAlert™ Badges

- Pre-assembled for your convenience
- Activated by removing the liner between the front and back of badge
- Badges expire after 24 hours
- 500 front and back sets per pack

Catalog #	Legend	Size	Qty.
95635	Visitor	2 in. x 3 in.	500

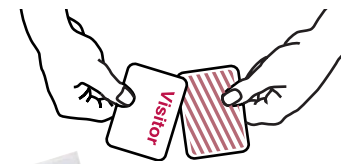

Prior to activation

After expiration

SecurAlert™ Adhesive Badges

- Activate expiration by applying the front badge to the back badge
- Badges expire after 24 hours
- 500 front and back sets per pack

Catalog #	Legend	Expires In	Qty.
95689	Contractor	24 hours	500
95674	Contractor	1 week	500
95690	Temporary	24 hours	500
95675	Temporary	1 week	500
95688	Visitor	24 hours	500
95673	Visitor	1 week	500



Retractable Badge Holder

- Clip attaches to belt or pocket while the heavy-duty nylon cable with fastener attaches to badge
- An ideal alternative to bull dog clips which may damage clothing

Catalog #	Description	Color	Qty.
95071	Retractable Holder	Blue	1
95072	Retractable Holder	Red	1
95073	Retractable Holder	White	1
95074	Retractable Holder	Gray	1
95075	Retractable Holder	Black	1



Lanyards

- Reuseable 19 in. cloth lanyard
- Includes a snap-swivel hook and adjustable bead for securing lanyard

Catalog #	Color	Size	Qty.
95090	Blue	19 in.	1
95091	Green	19 in.	1
95092	Orange	19 in.	1
95093	Red	19 in.	1
95094	White	19 in.	1




Security Tyvek® Wristbands

- An economical way to keep track of personnel, patients or visitors
- Will not tear or stretch
- Adhesive closure cannot be reused
- All wristbands are consecutively numbered (factory specified)

Tyvek® is a registered trademark of Dupont

Catalog #	Color	Size	Qty
95097	Red	1 in.	500
95101	Pink	1 in.	500
95099	Yellow	1 in.	500
95102	Orange	1 in.	500
95098	Purple	1 in.	500
95100	Blue	1 in.	500
95103	Green	1 in.	500

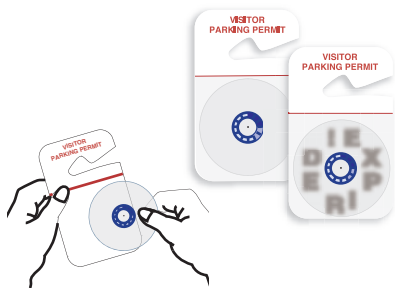


Self-Expiring Permits

- Temporary parking permits expire during the day by progressively revealing the letters E-X-P-I-R-E-D.
- Expiration process starts once the self-adhesive cover is applied

Catalog #	Legend	Color	Qty.
Red for Hot Weather Over 80°F (25°C)			
95677	Visitor	5 in. x 3 in.	500
95680	Temporary	5 in. x 3 in.	500
Blue for Moderate Weather 50–80°F (10–25°C)			
95678	Visitor	5 in. x 3 in.	500
95681	Temporary	5 in. x 3 in.	500
Purple for Cold Weather under 50°F (10°C)			
95679	Visitor	5 in. x 3 in.	500
95682	Temporary	5 in. x 3 in.	500

Contact Brady for custom permits with your own logo, color and custom text.

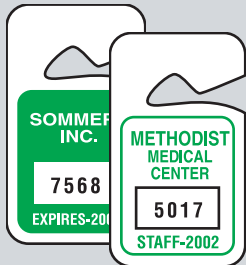

Self-Adhesive Vinyl Windshield Decals

Catalog #	Color	Sequence	Size	Qty.
95199	Blue	001-100	3 in. x 3 in.	100
96230	Blue	101-200	3 in. x 3 in.	100
96231	Blue	201-300	3 in. x 3 in.	100
96232	Blue	301-400	3 in. x 3 in.	100
96233	Blue	401-500	3 in. x 3 in.	100
95200	Red	001-100	3 in. x 3 in.	100
96234	Red	101-200	3 in. x 3 in.	100
96235	Red	201-300	3 in. x 3 in.	100
96236	Red	301-400	3 in. x 3 in.	100
96237	Red	401-500	3 in. x 3 in.	100



Self-Adhesive Vinyl Bumper Decals

Catalog #	Color	Sequence	Size	Qty.
95207	Blue	001-100	4.75 in. x 2.74 in.	100
96246	Blue	101-200	4.75 in. x 2.74 in.	100
96247	Blue	201-300	4.75 in. x 2.74 in.	100
96248	Blue	301-400	4.75 in. x 2.74 in.	100
96249	Blue	401-500	4.75 in. x 2.74 in.	100
95208	Red	001-100	4.75 in. x 2.74 in.	100
96250	Red	101-200	4.75 in. x 2.74 in.	100
96251	Red	201-300	4.75 in. x 2.74 in.	100
96252	Red	301-400	4.75 in. x 2.74 in.	100
96253	Red	401-500	4.75 in. x 2.74 in.	100



Rearview Mirror Hanging Tags

Catalog #	Color	Sequence	Size	Qty.
95201	Blue	001-100	2.75 in. x 4.75 in.	100
96262	Blue	101-200	2.75 in. x 4.75 in.	100
96263	Blue	201-300	2.75 in. x 4.75 in.	100
96264	Blue	301-400	2.75 in. x 4.75 in.	100
96265	Blue	401-500	2.75 in. x 4.75 in.	100
96266	Blue	501-600	2.75 in. x 4.75 in.	100
96267	Blue	601-700	2.75 in. x 4.75 in.	100
96268	Blue	701-800	2.75 in. x 4.75 in.	100
96269	Blue	801-900	2.75 in. x 4.75 in.	100
96270	Blue	901-1000	2.75 in. x 4.75 in.	100
95202	Red	001-100	2.75 in. x 4.75 in.	100
96271	Red	101-200	2.75 in. x 4.75 in.	100
96272	Red	201-300	2.75 in. x 4.75 in.	100
96273	Red	301-400	2.75 in. x 4.75 in.	100
96274	Red	401-500	2.75 in. x 4.75 in.	100
96275	Red	501-600	2.75 in. x 4.75 in.	100
96276	Red	601-700	2.75 in. x 4.75 in.	100
96277	Red	701-800	2.75 in. x 4.75 in.	100
96278	Red	801-900	2.75 in. x 4.75 in.	100
96279	Red	901-1000	2.75 in. x 4.75 in.	100



Rearview Mirror Hanging Tags

Catalog #	Color	Sequence	Size	Qty.
95205	Blue	001-100	4.75 in. x 2 in.	100
96280	Blue	101-200	4.75 in. x 2 in.	100
96281	Blue	201-300	4.75 in. x 2 in.	100
96282	Blue	301-400	4.75 in. x 2 in.	100
96283	Blue	401-500	4.75 in. x 2 in.	100
96284	Blue	501-600	4.75 in. x 2 in.	100
96285	Blue	601-700	4.75 in. x 2 in.	100
96286	Blue	701-800	4.75 in. x 2 in.	100
96287	Blue	801-900	4.75 in. x 2 in.	100
96288	Blue	901-1000	4.75 in. x 2 in.	100
95206	Red	001-100	4.75 in. x 2 in.	100
96289	Red	101-200	4.75 in. x 2 in.	100
96290	Red	201-300	4.75 in. x 2 in.	100
96291	Red	301-400	4.75 in. x 2 in.	100
96292	Red	401-500	4.75 in. x 2 in.	100
96293	Red	501-600	4.75 in. x 2 in.	100
96294	Red	601-700	4.75 in. x 2 in.	100
96295	Red	701-800	4.75 in. x 2 in.	100
96296	Red	801-900	4.75 in. x 2 in.	100
96297	Red	901-1000	4.75 in. x 2 in.	100