


SMTP TorqTaper Plus® Unit Sizes 407 - 800

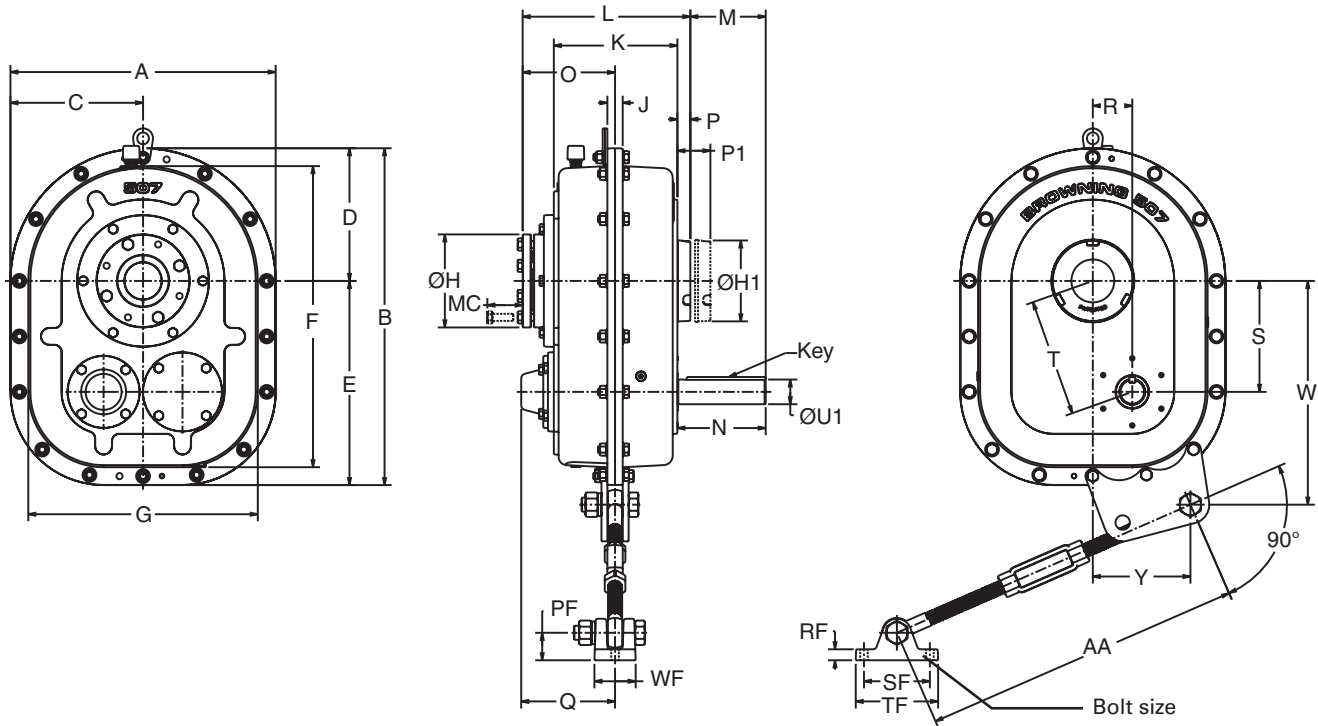

Part No.★	Dimensions in Inches																				
	A	B	C	D	E	F	G	H	H1	J	K	L	M	N	O	P	P1	PF	Q	R	RF
407SMTP-B	21.69	27.80	10.85	10.85	16.96	24.48	18.37	7.69	7.00	1.38	10.13	13.88	5.50	6.70	7.55	1.20	3.00	2.22	8.25	3.13	0.72
415SMTP-B	25.04	31.80	12.52	12.52	19.28	28.01	21.25	9.44	7.88	1.63	12.63	16.78	8.00	9.23	9.18	1.23	3.25	2.92	9.43	3.63	1.17
507SMTP-B	28.16	35.75	14.08	14.08	21.67	31.96	24.37	9.88	8.50	1.63	13.12	17.80	8.00	9.37	9.81	1.37	3.50	2.92	9.96	4.19	1.17
608SMTP-B	30.23	39.58	15.11	15.11	24.47	35.78	26.43	11.56	10.94	1.88	16.74	21.96	8.00	9.51	12.09	1.51	3.75	3.52	12.50	4.25	1.36
800SMTP	36.56	46.93	18.28	18.28	28.65	41.22	30.84	14.50	12.75	2.38	18.78	24.40	10.81	12.75	12.99	1.94	4.75	4.25	13.57	4.88	1.63

Part No.★	Dimensions in Inches								AA		Bolt Size	Key	Max.	MC	Wt. Lbs.
	S	SF	T	TF	U1	W	WF	Y	Min.	Max.			Output Bore		
407SMTP-B	9.24	4.75	9.75	6.50	2.12	19.72	3.63	3.56	29.50	35.50	5/8	1/2 Sq. x 6.00" Key	4 7/16	2.75	609
415SMTP-B	10.39	7.00	11.00	8.75	2.37	21.79	4.38	7.16	28.00	34.00	3/4	5/8 Sq. x 8.38" Key	4 15/16	3.25	957
507SMTP-B	11.78	7.00	12.50	8.75	2.62	23.75	4.38	10.36	28.00	34.00	3/4	5/8 Sq. x 8.38" Key	5 7/16	3.75	1217
608SMTP-B	13.60	7.00	14.25	9.25	2.69	26.05	4.96	11.71	28.00	34.00	3/4	5/8 Sq. x 8.75" Key	6 1/2	4.25	1913
800SMTP	15.24	9.00	16.00	11.88	2.94	31.36	5.75	10.62	31.00	37.00	7/8	3/4 Sq. x 12.00" Key	8	4.50	2894

Part Number Explanation

