

Browning®

Mounted Ball Bearings



Duty: Standard

Rolling Elements: Ball


Housing: Cast Iron Pillow Block – Low Base

Self Alignment: +/- 2 Degrees

Lock: Setscrew

Seal: Contact and Flinger

Temperature: -20° to 200°F

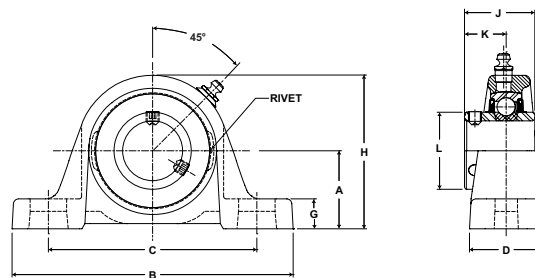

VPLS 200 Series Standard Duty Low Base Pillow Blocks - Setscrew Locking

Bore Diameter inch	Part No.	Bearing Insert No.	Basic Dynamic Rating lb/N	Dimensions inch / mm										Bolt Size	Unit Wt. lb/kg
				A	B	C		D	G	H	J	K	L		
1/2	VPLS-208	VS-208	2108	1 1/16	4 7/8	3 1/8	4 1/8	1 7/32	11/32	2 3/32	1 1/32	5/8	31/32	3/8	.7
5/8	VPLS-210	VS-210	9377	27.0	123.8	79.4	104.8	31.0	8.7	53.2	26.2	15.9	24.6	3/8	.32
3/4	VPLS-212	VS-212	2611	1 1/4	5	3 3/8	4 3/16	1 11/32	15/32	2 15/32	1 7/32	23/32	1 3/16	3/8	1.3
			11614	31.8	127.0	85.7	106.4	34.1	11.9	62.7	31.0	18.3	30.2	3/8	.59
7/8	VPLS-214	VS-214	2801	1 5/16	5 1/2	3 11/16	4 9/16	1 13/32	15/32	2 11/16	1 3/8	13/16	1 3/8	3/8	1.4
15/16	VPLS-215	VS-215	12459	33.3	139.7	93.7	115.9	35.7	11.9	68.3	34.9	20.6	34.9	3/8	.64
1	VPLS-216	VS-216													
1 1/8	VPLS-218	VS-218	4381	1 9/16	6 3/16	4 3/16	5 1/16	1 3/4	17/32	3 5/32	1 1/2	7/8	1 19/32	1/2	2.4
1 3/16	VPLS-219	VS-219	19487	39.7	157.2	106.4	128.6	44.5	13.5	80.2	38.1	22.2	40.5	1/2	1.09
1 1/4	VPLS-220S	VS-220S													
1 1/4	VPLS-220	VS-220	5782	1 13/16	6 3/4	4 5/8	5 3/8	1 3/4	21/32	3 5/8	1 11/16	1	1 55/64	1/2	3.5
1 3/8	VPLS-222	VS-222	25718	46.0	171.5	117.5	136.5	44.5	16.7	92.1	42.9	25.4	47.3	1/2	1.59
1 7/16	VPLS-223	VS-223													
1 1/2	VPLS-224	VS-224	7340	1 15/16	7 1/8	4 7/8	5 7/8	1 15/16	3/4	3 15/16	1 15/16	1 3/16	2 1/16	1/2	4.5
			32648	49.2	181.0	123.8	149.2	49.2	19.1	100.0	49.2	30.2	52.4	1/2	2.04
1 5/8	VPLS-226	VS-226	7901	2 1/16	7 3/8	5 1/4	6 1/16	2	11/16	4 3/16	1 15/16	1 3/16	2 19/64	1/2	5.5
1 11/16	VPLS-227	VS-227	35144	52.4	187.3	133.4	154.0	50.8	17.5	106.4	49.2	30.2	58.3	1/2	2.49
1 3/4	VPLS-228	VS-228													
1 15/16	VPLS-231	VS-231	7889	2 3/16	8	5 7/8	6 1/2	2 3/16	11/16	4 1/2	2 1/32	1 9/32	2 15/32	5/8	5.9
2	VPLS-232S	VS-232S	35090	55.6	203.2	149.2	165.1	55.6	17.5	114.3	51.6	32.5	62.7	5/8	2.68
2	VPLS-232	VS-232	9752	2 7/16	8 13/16	6 9/16	7 5/16	2 5/16	13/16	4 29/32	2 3/16	1 19/64	2 23/32	5/8	7.6
2 3/16	VPLS-235	VS-235	43377	61.9	223.8	166.7	185.7	58.7	20.6	124.6	55.6	32.9	69.1	5/8	3.45
2 1/4	VPLS-236	VS-236	11789	2 11/16	9 1/2	6 7/8	7 15/16	2 3/8	13/16	5 1/2	2 9/16	1 9/16	2 63/64	5/8	9.7
2 7/16	VPLS-239	VS-239	52437	68.3	241.3	174.6	201.6	60.3	20.6	139.7	65.1	39.7	75.8	5/8	4.40

Metric dimensions for reference only.