


Mounted Ball Bearings *Browning*

Mtd. Ball Bearings



Duty: Standard
Rolling Elements: Ball
Housing: Cast Iron Tapped Base Pillow Block
Self Alignment: +/- 1.5 Degrees
Lock: Setscrew
Seal: Contact and Flinger
Temperature: -20° to 200°F

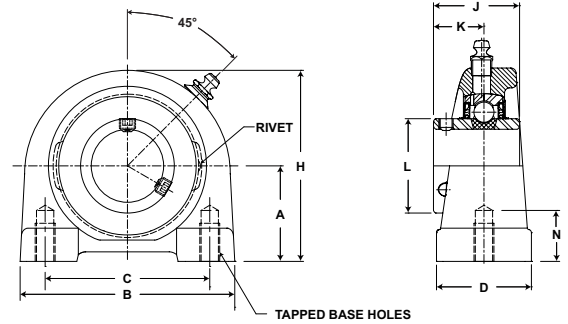

VTBS 200 Series Standard Duty Tapped Base Pillow Blocks - Setscrew Locking

Bore Diameter inch	Part No.	Bearing Insert No.	Basic Dynamic Rating lb/N	Dimensions inch / mm								Tapped Hole Thread Size	N Min Tap Depth	Unit Wt. lb/kg
				A	B	C	D	H	J	K	L			
1/2	VTBS-208	VS-208	2108	1 5/16	2 7/8	2	1 1/2	2 9/16	1 1/32	5/8	31/32	3/8-16	1/2	1.3
5/8	VTBS-210	VS-210	9377	33.3	73.0	50.8	38.1	65.1	26.2	15.9	24.6	3/8-16	1/2	.59
3/4	VTBS-212	VS-212	2611	1 5/16	2 7/8	2	1 1/2	2 9/16	1 7/32	23/32	1 3/16	3/8-16	1/2	1.5
			11614	33.3	73.0	50.8	38.1	65.1	31.0	18.3	30.2	3/8-16	1/2	.68
7/8	VTBS-214	VS-214	2801	1 7/16	3	2	1 1/2	2 13/16	1 3/8	13/16	1 3/8	3/8-16	1/2	1.6
15/16	VTBS-215	VS-215	12459	36.5	76.2	50.8	38.1	71.4	34.9	20.6	34.9	3/8-16	1/2	.73
1	VTBS-216	VS-216												
1 1/8	VTBS-218	VS-218	4381	1 11/16	4	3	1 1/2	3 3/8	1 1/2	7/8	1 19/32	7/16-14	5/8	2.5
1 3/16	VTBS-219	VS-219	19487	42.9	101.6	76.2	38.1	85.7	38.1	22.2	40.5	7/16-14	5/8	1.13
1 1/4	VTBS-220S	VS-220S												
1 1/4	VTBS-220	VS-220	5782	1 7/8	4 1/4	3 1/4	1 7/8	3 3/4	1 11/16	1	1 55/64	1/2-13	3/4	3.4
1 3/8	VTBS-222	VS-222	25718	47.6	108.0	82.6	47.6	95.3	42.9	25.4	47.2	1/2-13	3/4	1.54
1 7/16	VTBS-223	VS-223												
1 1/2	VTBS-224	VS-224	7340	1 15/16	4 5/8	3 1/2	1 7/8	3 15/16	1 15/16	1 3/16	2 1/16	1/2-13	3/4	3.8
			32648	49.2	117.5	88.9	47.6	100.0	49.2	30.2	52.4	1/2-13	3/4	
1 5/8	VTBS-226	VS-226	7901	2 1/8	5	3 3/4	2	4 1/4	1 15/16	1 3/16	2 19/64	1/2-13	3/4	4.7
1 11/16	VTBS-227	VS-227	35144	54.0	127.0	95.3	50.8	108.0	49.2	30.2	58.3	1/2-13	3/4	2.13
1 3/4	VTBS-228	VS-228												
1 15/16	VTBS-231	VS-231	7889	2 1/4	5 1/2	4	2	4 5/8	2 1/32	1 9/32	2 15/32	5/8-11	7/8	5.7
2	VTBS-232S	VS-232S	35090	57.2	139.7	101.6	50.8	117.5	51.6	32.5	62.7	5/8-11	7/8	2.59