



**TECH·SPEC®**



**CSB115BI**

### COMMERCIAL SPECIFICATION GRADE BACK AND SIDE WIRED 15 AMP TOGGLE SWITCHES

Description	Color	Catalog Number			
		Single-Pole	Double-Pole	3-Way	4-Way
Toggle switch; back and side wired; self-grounding	Almond	<b>CSB115BAL</b>	<b>CSB215BAL</b>	<b>CSB315BAL</b>	<b>CSB415BAL</b>
	Black	<b>CSB115BLK</b>	<b>CSB215BLK</b>	<b>CSB315BLK</b>	<b>CSB415BLK</b>
	Brown	<b>CSB115B</b>	<b>CSB215B</b>	<b>CSB315B</b>	<b>CSB415B</b>
	Gray	<b>CSB115BGRY</b>	<b>CSB215BGRY</b>	<b>CSB315BGRY</b>	<b>CSB415BGRY</b>
	Ivory	<b>CSB115BI</b>	<b>CSB215BI</b>	<b>CSB315BI</b>	<b>CSB415BI</b>
	Light Almond	<b>CSB115BLA</b>	<b>CSB215BLA</b>	<b>CSB315BLA</b>	<b>CSB415BLA</b>
	White	<b>CSB115BW</b>	<b>CSB215BW</b>	<b>CSB315BW</b>	<b>CSB415BW</b>



**CSB320B**

### 20 AMP TOGGLE SWITCHES

Description	Color	Catalog Number			
		Single-Pole	Double-Pole	3-Way	4-Way
Toggle switch; back and side wired; self-grounding	Almond	<b>CSB120BAL</b>	<b>CSB220BAL</b>	<b>CSB320BAL</b>	<b>CSB420BAL</b>
	Black	<b>CSB120BLK</b>	<b>CSB220BLK</b>	<b>CSB320BLK</b>	<b>CSB420BLK</b>
	Brown	<b>CSB120B</b>	<b>CSB220B</b>	<b>CSB320B</b>	<b>CSB420B</b>
	Gray	<b>CSB120BGRY</b>	<b>CSB220BGRY</b>	<b>CSB320BGRY</b>	<b>CSB420BGRY</b>
	Ivory	<b>CSB120BI</b>	<b>CSB220BI</b>	<b>CSB320BI</b>	<b>CSB420BI</b>
	Light Almond	<b>CSB120BLA</b>	<b>CSB220BLA</b>	<b>CSB320BLA</b>	<b>CSB420BLA</b>
	Red	<b>CSB120BRED</b>	<b>CSB220BRED</b>	<b>CSB320BRED</b>	<b>CSB420BRED</b>
White	<b>CSB120BW</b>	<b>CSB220BW</b>	<b>CSB320BW</b>	<b>CSB420BW</b>	



**CS115BW**

### TOGGLE SWITCHES, 15 AND 20 AMP

Description	Color	15 Amp Catalog Number		20 Amp Catalog Number	
		Single-Pole	3-Way	Single-Pole	3-Way
Toggle switch; side wired only; self-grounding	Almond	<b>CS115BAL</b>	<b>CS315BAL</b>	<b>CS120BAL</b>	<b>CS320BAL</b>
	Black	<b>CS115BLK</b>	<b>CS315BLK</b>	<b>CS120BLK</b>	<b>CS320BLK</b>
	Brown	<b>CS115B</b>	<b>CS315B</b>	<b>CS120B</b>	<b>CS320B</b>
	Gray	<b>CS115BGRY</b>	<b>CS315BGRY</b>	<b>CS120BGRY</b>	<b>CS320BGRY</b>
	Ivory	<b>CS115BI</b>	<b>CS315BI</b>	<b>CS120BI</b>	<b>CS320BI</b>
	Light Almond	<b>CS115BLA</b>	<b>CS315BLA</b>	<b>CS120BLA</b>	<b>CS320BLA</b>
	White	<b>CS115BW</b>	<b>CS315BW</b>	<b>CS120BW</b>	<b>CS320BW</b>




**CS320BI**

### HORSEPOWER RATINGS

RATING	120V	240V	277V AC	RATING	120V	240V	277V AC
<b>15 AMP</b>	½ HP	2 HP	2 HP	<b>20 AMP</b>	1 HP	2 HP	2 HP

### PRODUCT DIMENSIONS Inches (mm)

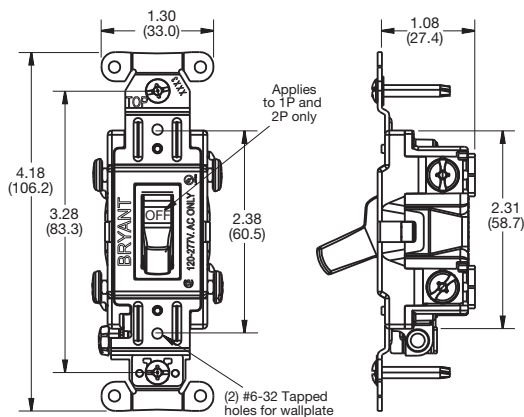

1P, 2P, 3W, 4W Switches