


# Locking Devices

## Angle Adapters for 20 and 30 Amp Locking Plugs and Connectors

- Nylon angle adapters convert 20 and 30 amp nylon locking plugs/connectors into space-saving angle devices
- Adapters permit wire to exit parallel to the receptacle, eliminating space needed for wire to bend

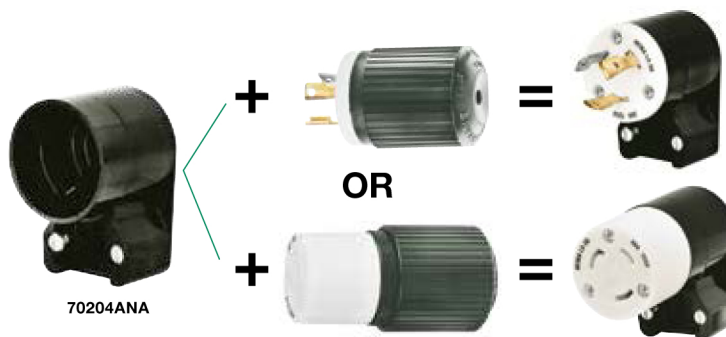

### Triple Gripper® Angle Adapters

Description	Cord Grip	Catalog Number
Angle adapter, black nylon	.500"-1.00" (12.7-25.4)	<b>70204ANA</b>

### Product Dimensions

Adapter with Plug		Inches (mm)	
A	2.88" (73.2)		
B	2.25" (57.2) Plug 3.35" (85.1) Connector		
C	1.33" (33.8)		
D	1.86" (47.2)		
E	1.80" (45.7)		

## PLUGBOX® Lockout Devices

- PLUGBOX® devices provide an assured method of complying with OSHA lockout/tagout regulation
- Protect against unexpected start-up of equipment during maintenance and repair work
- Discourages unauthorized use of tools and equipment
- UV stabilized polypropylene housing
- High visibility red for easy identification



### PLUGBOX® Lockout Devices

Description	Accommodates						
	15 Amp up to 277V Rating		20 Amp		30 Amp		50 Amp
	3-Wire	2- and 3-Wire	3-Wire	4- and 5-Wire	4- and 5-Wire		3- and 4-Wire
	Locking Molded-On Plugs	Locking Plugs	Power Interrupting Plugs	NEMA and Non-NEMA Locking Plugs	NEMA and Non-NEMA Locking Plugs	Power Interrupting Plugs	Locking Plugs
Red polypropylene	<b>BLDMP</b>	<b>BLD</b>	<b>BLD</b>	<b>BLD</b>	<b>BLD</b>	<b>BLD2</b>	<b>BLD2</b>

### Product Dimensions

	BLDMP	BLD	BLD2
A	4.22" (107.2)	7.27" (184.7)	12.51" (317.8)
B	3.14" (79.8)	4.27" (108.5)	6.31" (160.3)
C	(2) 0.32" (8.1)	(4) 0.39" (9.9)	(4) 0.39" (9.9)
D	2.57" (65.3)	3.10" (78.7)	5.00" (127.0)
E	3.70" (94.0)	4.75" (120.7)	10.15" (257.8)
F	0.79"-1.73" (20.1-43.9)	1.50"-2.75" (38.1-69.9)	1.90"-4.50" (48.3-114.3)
G	0.64" (16.3)	1.11" (28.2)	1.45" (36.8)

