

Locking Devices

15 Amp Locking Receptacles

15A 125V, 250V and 277V Locking Devices, 2-Pole 3-Wire Grounding Inches (mm)

TECH·SPEC®



Rating	Description	Back and Side Wired				
		Duplex Receptacle Reinforced Thermoplastic Polyester (RTP)	Nylon	Single Receptacle		
				Panel Mount Mounting Hole Center		Mounted on 4" (101.6) Round Metal Box
				1.94" (49.3)	1.75" (44.5)	
NEMA L5-15, 15A 125V	Black	—	4710	4712BRY	4713BRY	4711BRY
Plug	Connector	4700DR	—	—	—	—
		4700DRI	—	—	—	—
	Isolated Ground	4700DRIG	4710IG	—	—	—
	Orange					
	Corrosion-Resistant	4700DRCR	4710CR	—	—	—
	Yellow					
NEMA L6-15, 15A 250V	Black	—	70615FR	7061594	7061575	—
Plug	Connector	70615DR	—	—	—	—
		70615DRIG	70615IG	—	—	—
	Isolated Ground					
	Orange					
NEMA L7-15, 15A 277V AC	Black	—	4760	—	—	4761
Plug	Connector	4750DR	—	—	—	—

Note: See Section C for more information on isolated ground devices.
See Section I for more information on corrosion-resistant devices.

Accessories




Single Receptacle Wallplate		Duplex Receptacle Wallplate		Weatherproof Covers		
Stainless Steel	Nylon	Stainless Steel	Nylon	Zinc Die Cast	Zinc Die Cast	Thermoplastic
SS7	NP7BK	SS8	NP8BK	RW51550	RW51470	RW57300


Note: See Section P for additional information on wallplates and weatherproof covers.

Product Dimensions Inches (mm)


Receptacle		
	Duplex	Single
A	3.28" (83.3)	3.28" (83.3)
B	2.74" (69.6)	2.38" (60.5)
C	1.70" (43.2)	1.38" (35.1)
D	1.17" (29.7)	1.41" (35.8)
E	0.93" (23.6)	1.37" (37.8)
F	—	1.01" (25.7)
Panel Mounting		
A	2.38" (60.5)	
B	1.75" (44.5) or 1.94" (49.3)	
C	1.38" (35.1)	
D	1.41" (35.8)	
E	1.09" (27.7)	
F	0.33" (8.4)	

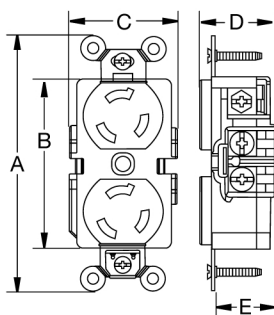

4700DR, 70615DR and 4750DR

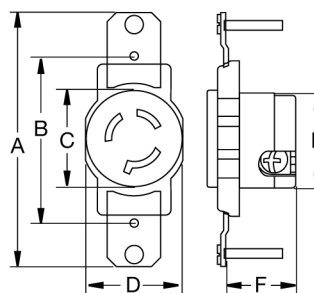

4710, 70615FR and 4760

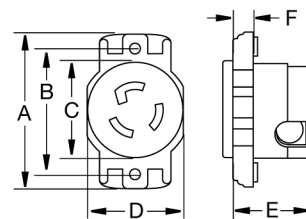

4712BRY and 4713BRY