

Straight Blade Devices



Residential Grade Quick Thread Receptacles

Quick and Easy Does It

Residential Grade exclusive "Quick Thread" makes installation of wallplates and receptacles quicker and easier. One push for a snug fit. Just push in the screw and turn, see detail below.

15A 125V Quick Thread Tamper-Resistant Receptacles



RR15QLATR




RR15EQWTR

Wiring	Push and Side Wired		Eight Push Wire Holes Only	
Grounding	Self-Grounding		#14 AWG Only	
Rating	Color	Catalog Number	Catalog Number	
NEMA 5-15, 15A 125V	Black Brown Ivory Light Almond White	RR15QBKTR RR15QTR RR15QITR RR15QLATR RR15QWTR	RR15EQBKTR RR15EQTR RR15EQITR RR15EQLATR RR15EQWTR	

Note: See page R-6 for tamper-resistant description.

Product Dimensions Inches (mm)

Quick Thread Duplex	
A	4.19" (106.4)
B	3.28" (83.3)
C	1.41" (28.5)
D	1.12" (23.6)
E	2.62" (66.6)

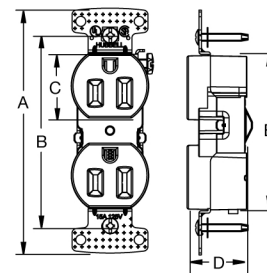

Residential Grade Duplex and Decorator Receptacles

15A 125V Duplex and Decorator Receptacles



RR15SW



RRD15SLA



RR15



RRD15GY



RR15KI



RRD15KW

Wiring	Grounding	Push and Side Wired					
		Self-Grounding		Grounding		Self-Grounding	
Rating	Color	Duplex	Decorator	Duplex	Decorator	Earless Duplex	Earless Decorator
NEMA 5-15, 15A 125V	Black Brown Gray Ivory Light Almond White	— RR15S — RR15SI RR15SLA RR15SW	RRD15SBK RRD15S RRD15SGY RRD15SI RRD15SLA RRD15SW	RR15BK RR15 — RR15I RR15LA RR15W	RRD15BK RRD15 RRD15GY RRD15I RRD15LA RRD15W	— RR15K — RR15KI RR15KLA RR15KW	RRD15KBK RRD15K RRD15KGY RRD15KI RRD15KLA RRD15KW

15A 125V Duplex and Decorator Tamper-Resistant Receptacles



RR15SALTR



RRD15SWTR



RR15KITR



RRD15KBKTR



RR15EWTR



RRD15EGYTR

Wiring	Grounding	Push and Side Wired				Eight Push Wire Holes Only, #14 AWG	
		Self-Grounding		Grounding	Self-Grounding	Grounding	Self-Grounding
Rating	Color	Duplex	Decorator	Earless Duplex	Earless Decorator	Duplex	Decorator
NEMA 5-15, 15A 125V	Almond Black Brown Gray Ivory Light Almond White	RR15SALTR RR15STR RR15SBKTR — RR15SITR RR15SLATR RR15SWTR	RRD15SALTR RRD15SBKTR RRD15STR RRD15SGYTR RRD15SITR RRD15SLATR RRD15SWTR	— — RR15KTR — RR15KITR RR15KLATR RR15KWTR	— RRD15KBKTR RRD15KTR RRD15KGYTR RRD15KITR RRD15KLATR RRD15KWTR	— RR15EBKTR RR15ETR — RR15EITR RR15ELATR RR15EWTR	— RRD15EBKTR RRD15ETR RRD15EGYTR RRD15EITR RRD15ELATR RRD15EWTR

Note: See page R-6 for tamper-resistant description.