

Straight Blade Devices

Hospital Grade • Self-Grounding Receptacles



- Heavy duty, copper-alloy self-grounding system (tin plated)
- Double-wipe, copper-alloy grounding contacts
- ID surface for marking identification of circuits
- Heavy duty, brass over nickel plated wrap-around steel yoke locked in for maximum strength and security

Why Hospital Grade?

Bryant hospital grade receptacles are specifically designed to provide maximum safety and withstand severe abuse in hospitals and heavy duty industrial applications. The green dot • signifying UL hospital grade listing is more than just a symbol of compliance. It is your assurance that each device has passed the most stringent requirements for grounding reliability, security of assembly, strength and durability.

15A and 20A 125V and 20A 250V Receptacles

TECH-SPEC®



BRY8200RED



BRY8300IWR



BRY8200WL



BRY8300GTR



8210I




8310WWR

Wiring		Back and Side Wired			Stranded Wire Leads		Back and Side Wired	
Face		Duplex			Duplex		Single	
Rating	Color	Standard	Weather Resistant	Lighted Face	Tamper-Resistant	Standard	Weather Resistant	
NEMA 5-15, 15A 125V 	Almond	—	—	—	BRY8200ALTR	—	—	
	Brown	BRY8200	BRY8200WR	—	BRY8200TR	8210	8210WR	
	Gray	BRY8200GRY	BRY8200GRYWR	BRY8200GRYL	BRY8200GTR	8210GRY	8210GRYWR	
	Ivory	BRY8200I	BRY8200IWR	BRY8200IL	BRY8200ITR	8210I	8210IWR	
	Red	BRY8200RED	BRY8200REDWR	BRY8200REDL	BRY8200RTR	8210RED	8210REDWR	
	White	BRY8200W	BRY8200WWR	BRY8200WL	BRY8200WTR	8210W	8210WWR	
Orange*	BRY8200IG	—	—	—	—	8210IG	—	
NEMA 5-20, 20A 125V 	Almond	—	—	—	BRY8300ALTR	—	—	
	Brown	BRY8300	BRY8300WR	—	BRY8300TR	8310	8310WR	
	Gray	BRY8300GRY	BRY8300GRYWR	BRY8300GRYL	BRY8300GTR	8310GRY	8310GRYWR	
	Ivory	BRY8300I	BRY8300IWR	BRY8300IL	BRY8300ITR	8310I	8310IWR	
	Red	BRY8300RED	BRY8300REDWR	BRY8300REDL	BRY8300RTR	8310RED	8310REDWR	
	White	BRY8300W	BRY8300WWR	BRY8300WL	BRY8300WTR	8310W	8310WWR	
Orange*	BRY8300IG	—	—	—	—	8310IG	—	
NEMA 6-20, 20A 250V 	Brown	—	—	—	—	8410BRN	—	
	Gray	—	—	—	—	8410GRY	—	
	Ivory	—	—	—	—	8410I	—	
	Red	—	—	—	—	8410RED	—	
	White	—	—	—	—	8410W	—	
	Orange*	—	—	—	—	8410IG	—	

Note: *Orange is Isolated Ground. See Section C for isolated ground products.
See page R-6 for tamper-resistant and weather resistant descriptions.
See page A-28 for technical specifications.

Product Dimensions Inches (mm)

	Duplex Standard, Weather Resistant and Lighted Face	Duplex, Tamper-Resistant	Single Standard and Weather Resistant
A	4.06" (103.1)	4.06" (103.1)	4.06" (103.1)
B	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)
C	1.54" (39.1)	1.65" (41.9)	2.38" (60.5)
D	1.16" (29.5)	2.75" (69.9)	1.38" (35.1)
E	2.69" (68.3)	1.30" (33.0)	0.91" (23.1)
F	—	—	1.78" (45.2)

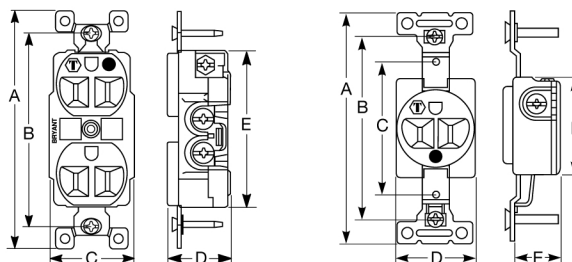

Straight Blade Devices

Hospital Grade • Self-Grounding Receptacles



- High-impact thermoplastic face and base
- Back and side wired
- Break-off tab for two-circuit wiring
- Heavy duty, wrap-around steel yoke

Fashion Series® 9000

The built-in features of the 9200 self-grounding receptacle reflect the super-safe design, solid construction, and attention to details — the Face of Quality of Bryant's full line of Fashion Series 9000 designer receptacles. This line assures you of the exact device you need for hospital, industrial or commercial applications.

15A and 20A 125V Receptacles

FASHION SERIES™ 9000



9200GRY



9200IG




9300IL

Wiring		Back and Side Wired		
Face		Decorator		
Rating	Color	Duplex	Isolated Ground	Lighted Face
NEMA 5-15, 15A 125V 	Brown	9200	—	—
	Gray	9200GRY	9200IGGRY	9200GRYL
	Ivory	9200I	9200IGI	9200IL
	Red	9200RED	9200IGRED	9200REDL
	White	9200W	9200IGW	9200WL
Orange*	—	9200IG	—	—
NEMA 5-20, 20A 125V 	Brown	9300	—	—
	Gray	9300GRY	9300IGGRY	—
	Ivory	9300I	9300IGI	9300IL
	Red	9300RED	9300IGRED	9300REDL
	White	9300W	9300IGW	9300WL
Orange*	—	9300IG	—	—

Note: *Orange is Isolated Ground. See Section C for isolated ground products.
See page A-28 for technical specifications.

Product Dimensions Inches (mm)

A	3.28" (83.3)
B	1.36" (34.5)
C	1.03" (26.2)
D	2.75" (69.9)

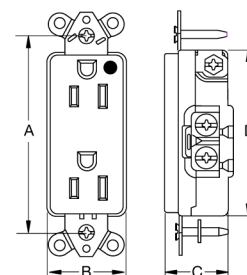

Hospital Grade • USB Charger Receptacles



- Two USB ports 3.8 Amp, 5V DC, Type A, class 2.0
- Tamper-Resistant (TR) decorator duplex
- Green LED indicator to show USB power available
- Back and side wire for solid or stranded wire



15A and 20A 125V USB Charger Receptacles



Rating	Color	Duplex	Rating	Color	Duplex
NEMA 5-15, 15A 125V 	Black	USBB8200BK	NEMA 5-20, 20A 125V 	Black	USBB8300BK
	Gray	USBB8200GY		Gray	USBB8300GY
	Ivory	USBB8200I		Ivory	USBB8300I
	Light Almond	USBB8200LA		Light Almond	USBB8300LA
	Red	USBB8200R		Red	USBB8300R
White	USBB8200W	White	USBB8300W		

Note: See page R-6 for tamper-resistant description.
See page A-29 for technical specifications.

Product Dimensions Inches (mm)

A	3.28" (83.3)
B	1.75" (44.5)
C	2.62" (66.5)
D	1.73" (43.9)
E	0.27" (6.8)

