

Straight Blade Devices

USB Charger Receptacles and Outlets



Receptacle Features

- Two USB ports 3.8 Amp, 5V DC, type A, class 2.0
- Tamper-Resistant decorator duplex receptacle
- Standard and Hospital Grade
- cULus listed to UL498 and UL1310

4 Port Features

- Four USB ports 5 Amp, 5V DC, type A, class 2.0
- cETLus listed to UL 1310

2 Port Features

- Two USB ports 3.0 Amp, 5V DC, type A, class 2.0
- Shallow design to fit in delivery systems and for OEM use
- cULus Listed to UL 1310



USB Chargers

Bryant's USB Charger Receptacle provides both USB and electrical power in a standard single gang electrical opening. Designed to provide more charging options for personal electronics. The USB ports are capable of charging two tablets simultaneously.

The 4 Port and 2 Port Charger Outlets feature a USB port door, which when open enables power. When closed, all power is switched off. This eliminates all current flow for a "zero" no-load draw.

15A and 20A 125V USB Charger Receptacles



USBB15W



USBB8300W



Wiring		Back and Side Wired	
Style		Decorator	
Rating	Color	Standard	Hospital Grade
NEMA 5-15, 15A 125V 	Black	USBB15BK	USBB8200BK
	Brown	USBB15	—
	Gray	USBB15GY	USBB8200GY
	Ivory	USBB15I	USBB8200I
	Light Almond	USBB15LA	USBB8200LA
	Red	—	USBB8200R
	White	USBB15W	USBB8200W
NEMA 5-20, 20A 125V 	Black	USBB20BK	USBB8300BK
	Brown	USBB20	—
	Gray	USBB20GY	USBB8300GY
	Ivory	USBB20I	USBB8300I
	Light Almond	USBB20LA	USBB8300LA
	Red	—	USBB8300R
	White	USBB20W	USBB8300W

Note: See page R-6 for tamper-resistant description.

4 Port and 2 Port USB Charger Outlets



USBB4W




USBB2W




Wiring		Back and Side Wired	
Style		Decorator	
Color	4 Port	2 Port	
Black	USBB4BK	USBB2BK	
Brown	USBB4	USBB2	
Gray	USBB4GY	USBB2GY	
Ivory	USBB4I	USBB2I	
Light Almond	USBB4LA	USBB2LA	
White	USBB4W	USBB2W	

Product Dimensions Inches (mm)


	Duplex	4 Port	2 Port
A	3.28" (83.3)	3.28" (83.3)	3.28" (83.3)
B	1.75" (44.5)	1.72" (43.8)	1.75" (44.5)
C	2.62" (66.5)	2.62" (66.5)	2.62" (66.5)
D	1.73" (43.9)	1.73" (43.9)	1.01" (25.8)
E	0.27" (6.8)	0.27" (6.8)	0.30" (7.6)

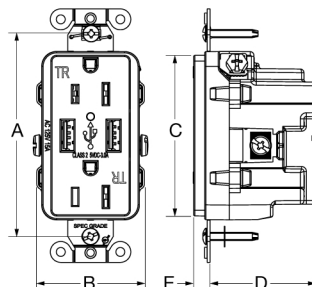

Duplex Receptacles

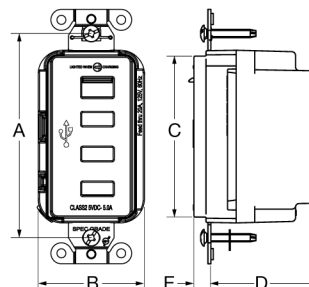

4 Port

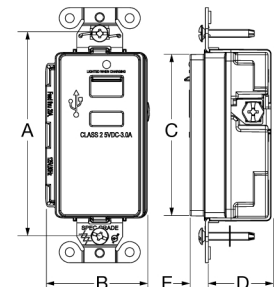

2 Port