



## QUADCAB® WALL MOUNT ENCLOSURE

Cabinet Depth	Door Style	Color*	Catalog Number
20.0"	Window	Black	<b>HSQXX</b>
26.0"	Window	Black	<b>HSQXX26</b>
36.0"	Window	Black	<b>HSQXX36</b>
20.0"	Solid	Black	<b>HSQXXS</b>
26.0"	Solid	Black	<b>HSQXXS26</b>
36.0"	Solid	Black	<b>HSQXXS36</b>

Note: **XX** = Height in inches. '24' = 24"/12 Rack Units; '36' = 36"/19 Rack Units; '48' = 48"/26 Rack Units.

\*For Office White, add "W" to the end of the catalog number.

Delivery: 1 rear section (arrives disassembled, facilitating installation); 1 front door; 2 19-inch mounting angles; 1 center section with 2 CH751 locks; 2 top/bottom cover plates; 2 hinge pins; 2 security cotter pins.



**REKZ**

## RE-BOX® AND QUADCAB® WALL MOUNT ENCLOSURE ACCESSORIES

Description	Size/Style	Catalog Number
¼" plywood backboard	20.0" x 19.0"	<b>REKBB20</b>
	30.0" x 19.0"	<b>REKBB30</b>
	40.0" x 19.0"	<b>REKBB40</b>
110/66 block mounting rails	—	<b>REK110</b>
DIN rail utility box	—	<b>DRUBTVSS15</b>
DIN rail communications kit	—	<b>HIDRUBCKIT</b>
Equipment mounting bracket	8.75" 5.25"	<b>REKZ</b> <b>REKZL</b>
Fiber optic bracket	—	<b>REKFP</b>
Filler panel	3.5"H	<b>MCCBP350</b>
Gasket kit - padded grommet	30'	<b>HWKGT</b>
Gasket kit - adhesive backed foam	10'	<b>REKG</b>
Ground kit	—	<b>REKGB</b>
Ground strap kit; economy	—	<b>REKEGS</b>
Key lock kits:	CH751	<b>CKL751</b>
	333	<b>CKL333</b>
	Bellcore 716	<b>CKL716</b>
	Cat60	<b>CKLCAT60</b>
	Cat70	<b>CKLCAT70</b>
Patch panel mounting bracket	7.0"	<b>REK19</b>
	3.5"	<b>REK19L</b>
Power kit; 20A	—	<b>REKP</b>
Thermostat	—	<b>CTK</b>



**REKFP**




**HIDRUBCKIT**



**REKP**



**REKGB**

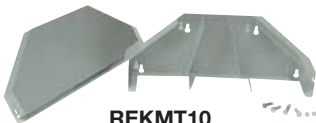

**REKMT10**



**CTK**