

**TYPE BIBS-MT, BIBD-MT**

**UNITAP™**

**Clear Insulated Multiple Tap Connectors Mounting Version**

The BIBS-MT and BIBD-MT series UNITAP™ offer the same multi-port capabilities as the standard UNITAP™ connectors except these -MT types are provided with two isolated mounting holes at both ends of the connector for direct mounting to a trough, gutter or wireway. They will accommodate up to standard 1/4" hardware.

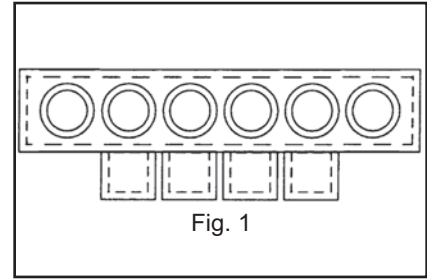


Fig. 1

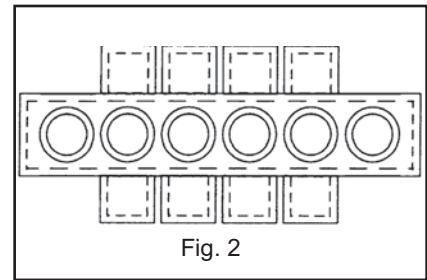


Fig. 2

**MULTI-PORT  
Single-Sided Entry**

| Catalog Number | Fig. # | # of Ports | Wire Range (AWG/kcmil) | L     | W    | H    | Hex Key |
|----------------|--------|------------|------------------------|-------|------|------|---------|
| BIBS2/04MT     | 1      | 4          | #14 -2/0 Str           | 4.20  | 1.25 | 1.50 | 3/16    |
| BIBS2/06MT     | 1      | 6          | #14 -2/0 Str           | 5.54  | 1.25 | 1.50 | 3/16    |
| BIBS2/08MT     | 1      | 8          | 14 AWG-2/0 Str         | 6.89  | 1.25 | 1.50 | 3/16    |
| BIBS2/010MT    | 1      | 10         | 14 AWG-2/0 Str         | 8.23  | 1.25 | 1.50 | 3/16    |
| BIBS2/012MT    | 1      | 12         | 14 AWG-2/0 Str         | 9.58  | 1.25 | 1.50 | 3/16    |
| BIBS2504MT     | 1      | 4          | 10 AWG-250 kcmil       | 5.78  | 1.95 | 2.63 | 5/16    |
| BIBS2506MT     | 1      | 6          | 10 AWG-250 kcmil       | 7.65  | 1.95 | 2.63 | 5/16    |
| BIBS2508MT     | 1      | 8          | 10 AWG-250 kcmil       | 9.53  | 1.95 | 2.63 | 5/16    |
| BIBS25010MT    | 1      | 10         | 10 AWG-250 kcmil       | 11.41 | 1.95 | 2.63 | 5/16    |
| BIBS25012MT    | 1      | 12         | 10 AWG-250 kcmil       | 13.28 | 1.95 | 2.63 | 5/16    |
| BIBS3504MT     | 1      | 4          | 10 AWG-350 kcmil       | 5.86  | 2.19 | 2.63 | 5/16    |
| BIBS3506MT     | 1      | 6          | 10 AWG-350 kcmil       | 7.68  | 2.19 | 2.63 | 5/16    |
| BIBS3508MT     | 1      | 8          | 10 AWG-350 kcmil       | 9.50  | 2.19 | 2.63 | 5/16    |
| BIBS35010MT    | 1      | 10         | 10 AWG-350 kcmil       | 11.32 | 2.19 | 2.63 | 5/16    |
| BIBS35012MT    | 1      | 12         | 10 AWG-350 kcmil       | 13.41 | 2.19 | 2.63 | 5/16    |
| BIBS6004MT     | 1      | 4          | 4 AWG-600 kcmil        | 7.84  | 2.25 | 2.88 | 3/8     |
| BIBS6006MT     | 1      | 6          | 4 AWG-600 kcmil        | 10.41 | 2.25 | 2.88 | 3/8     |
| BIBS6008MT     | 1      | 8          | 4 AWG-600 kcmil        | 12.97 | 2.25 | 2.88 | 3/8     |
| BIBS60010MT    | 1      | 10         | 4 AWG-600 kcmil        | 15.53 | 2.25 | 2.88 | 3/8     |
| BIBS60012MT    | 1      | 12         | 4 AWG-600 kcmil        | 18.09 | 2.25 | 2.88 | 3/8     |

UNITAP™ rated for code conductor only.

**MULTI-PORT  
Double-Sided Entry**

| Catalog Number | Fig. # | # of Ports | Wire Range (AWG/kcmil) | L     | W    | H    | Hex Key |
|----------------|--------|------------|------------------------|-------|------|------|---------|
| BIBD2/04MT     | 2      | 4          | 14 AWG-2/0 AWG         | 4.20  | 1.56 | 1.50 | 3/16    |
| BIBD2/06MT     | 2      | 6          | 14 AWG-2/0 AWG         | 5.54  | 1.56 | 1.50 | 3/16    |
| BIBD2/08MT     | 2      | 8          | 14 AWG-2/0 AWG         | 6.89  | 1.56 | 1.50 | 3/16    |
| BIBD2/010MT    | 2      | 10         | 14 AWG-2/0 AWG         | 8.23  | 1.56 | 1.50 | 3/16    |
| BIBD2/012MT    | 2      | 12         | 14 AWG-2/0 AWG         | 9.58  | 1.56 | 1.50 | 3/16    |
| BIBD2504MT     | 2      | 4          | 10 AWG-250 kcmil       | 5.78  | 2.64 | 2.26 | 5/16    |
| BIBD2506MT     | 2      | 6          | 10 AWG-250 kcmil       | 7.65  | 2.64 | 2.26 | 5/16    |
| BIBD2508MT     | 2      | 8          | 10 AWG-250 kcmil       | 9.53  | 2.64 | 2.26 | 5/16    |
| BIBD25010MT    | 2      | 10         | 10 AWG-250 kcmil       | 11.41 | 2.64 | 2.26 | 5/16    |
| BIBD25012MT    | 2      | 12         | 10 AWG-250 kcmil       | 13.28 | 2.64 | 2.26 | 5/16    |
| BIBD3504MT     | 2      | 4          | 10 AWG-350 kcmil       | 5.86  | 3.00 | 2.63 | 5/16    |
| BIBD3506MT     | 2      | 6          | 10 AWG-350 kcmil       | 7.68  | 3.00 | 2.63 | 5/16    |
| BIBD3508MT     | 2      | 8          | 10 AWG-350 kcmil       | 9.50  | 3.00 | 2.63 | 5/16    |
| BIBD35010MT    | 2      | 10         | 10 AWG-350 kcmil       | 11.32 | 3.00 | 2.63 | 5/16    |
| BIBD35012MT    | 2      | 12         | 10 AWG-350 kcmil       | 13.41 | 3.00 | 2.63 | 5/16    |
| BIBD6004MT     | 2      | 4          | 4 AWG-600 kcmil        | 7.84  | 3.00 | 2.88 | 3/8     |
| BIBD6006MT     | 2      | 6          | 4 AWG-600 kcmil        | 10.41 | 3.00 | 2.88 | 3/8     |
| BIBD6008MT     | 2      | 8          | 4 AWG-600 kcmil        | 12.97 | 3.00 | 2.88 | 3/8     |
| BIBD60010MT    | 2      | 10         | 4 AWG-600 kcmil        | 15.53 | 3.00 | 2.88 | 3/8     |
| BIBD60012MT    | 2      | 12         | 4 AWG-600 kcmil        | 18.09 | 3.00 | 2.88 | 3/8     |

UNITAP™ rated for code conductor only.

Blue highlighted items are industry standard and most frequently ordered.