
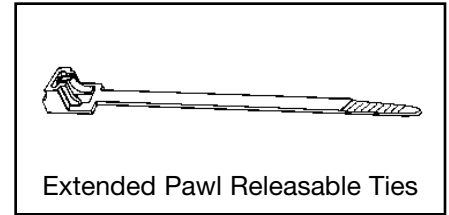


UNIRAP™

RELEASABLE CABLE TIES

Perfect for prototype construction, releasable cable ties are ideal for temporary installations. Releasable ties are also good for applications where service requires adding or subtracting wires from an existing wire bundle.

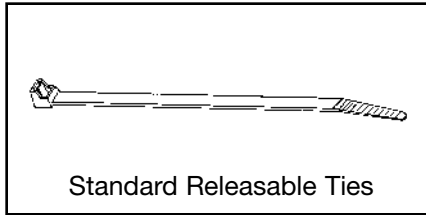

Standard Releasable Cable Ties

Standard Package Catalog Number	Material	Maximum Bundle Diameter Inches [mm]	Minimum Tensile Strength Lbs. (N)	Length Inches [mm]	Width Inches [mm]
CT40200RC	Natural Nylon 6/6	2.00 [51]	40 (178)	8.50 [216]	.16 [4]
CT40200RC0	Black Nylon 6/6 UV				
CT50137RC	Natural Nylon 6/6	1.38 [35]	50 (222)	6.50 [165]	.18 [4.6]
CT50137RC0	Black Nylon 6/6 UV				
CT50400RC	Natural Nylon 6/6	4.00 [102]		15.50 [394]	
CT50400RC0	Black Nylon 6/6 UV				

Extended Pawl Releasable Cable Ties

Standard Package Catalog Number	Material	Maximum Bundle Diameter Inches [mm]	Minimum Tensile Strength Lbs. (N)	Length Inches [mm]	Width Inches [mm]
CT50137EPRC	Natural Nylon 6/6	1.38 [35]	50 (222)	5.50 [140]	.291 [7.4]
CT50137EPRC0	Black Nylon 6/6 UV				
CT50250EPRC	Natural Nylon 6/6	2.50 [64]		9.80 [249]	
CT50250EPRC0	Black Nylon 6/6 UV				

Heavy Duty Releasable Cable Ties

Standard Package Catalog Number	Material	Maximum Bundle Diameter Inches [mm]	Minimum Tensile Strength Lbs. (N)	Length Inches [mm]	Width Inches [mm]
CT250200RQ	Natural Nylon 6/6	2.00 [51]	250 (1112)	9.00 [229]	.50 [12.7]
CT250200RQ0	Black Nylon 6/6 UV				
CT250500RQ	Natural Nylon 6/6	5.00 [127]		20.00 [508]	
CT250500RQ0	Black Nylon 6/6 UV				
CT250600RQ	Natural Nylon 6/6	6.00 [152]		23.00 [584]	
CT250600RQ0	Black Nylon 6/6 UV				
CT250800RQ	Natural Nylon 6/6	8.00 [203]		29.00 [737]	
CT250800RQ0	Black Nylon 6/6 UV				
CT2501000RQ	Natural Nylon 6/6	10.00 [254]		35.00 [889]	
CT2501000RQ0	Black Nylon 6/6 UV				
CT2501200RQ0	Black Nylon 6/6 UV	12.00 [305]		40.00 [1016]	

Blue highlighted items are industry standard and most frequently ordered.