

**TYPE UGSKIT8**

**UF DIRECT BURIAL  
SPLICE KIT**

Type UGS UF Splice Kit consists of a UF splice connector and a heavy wall heat-shrink sleeve. The UF splice connector can accommodate up to four UF conductors and is installed with common installation tools. The heavy wall heat shrink sleeve is lined with an adhesive material, providing a water-tight splice that can withstand abrasions that may occur during direct burial applications. Heat shrink sleeve installed with standard propane torch, or electric heat gun.





Catalog Number	Wire Range
	Copper
<b>UGSKIT8*</b>	14 AWG-8 AWG

\*UL486D Listed for Direct Burial

**TYPE UGS350ULDB**

**IN-LINE SPLICE/REDUCER**

For Direct Burial

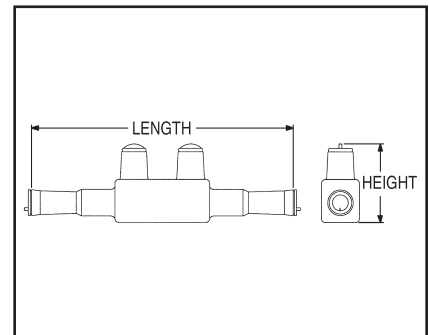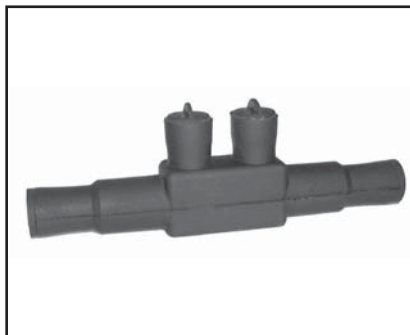

**Features & Benefits**

- EPDM rubber covered 6061-T6 aluminum connector
- Dual rated AL9CU for copper or aluminum conductor
- UL Listed and CSA Certified for Direct Burial
- Broad range taking capability
- Low installation cost

Catalog Number	Wire Range	Length	Height	Hex Size	Torque (In. Lbs.)
<b>UGS350ULDB</b>	12 AWG-350 kcmil	8.50	2.81	5/16	350

Blue highlighted items are industry standard and most frequently ordered.