


**TYPE QN-F  
FINGRIP™**

**NYLON INSULATED FEMALE  
QUICK DISCONNECTS**

Material: Tin-Plated Brass  
300 Volts Max., 105°C Max.

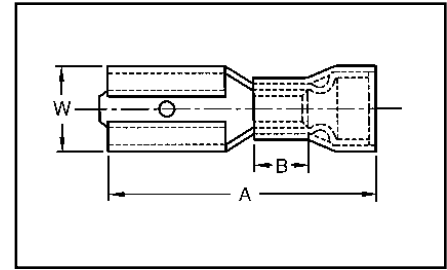

**Features and Benefits**

- Sleeved barrel.
- Insulated connectors.
  - ◇ Eliminate the need for post installation insulation.
- Funnel entry barrel opening.
  - ◇ Assures quick and easy wire insertion.
- Dimpled female socket detent.
  - ◇ Ensures firm grip.



**FEMALE NYLON DISCONNECT TERMINAL**

(Mates with Type QN-M male disconnects)


Standard Catalog Number	Std. Pkg. Qty.	Wire Range	NEMA Tab Size	Dimensions			Bulk Catalog Number	Bulk Pkg. Qty.	Installation Tool*
				A	B	W			
QN18F18X02D	100	18-22	.187 × .020	0.86	0.23	0.22	QN18F18X02B	1000	Y10D
QN18F25X03D			.250 × .032	0.91	0.23	0.29	QN18F25X03B		
QN14F18X02D	100	14-16	.187 × .020	0.87	0.23	0.23	QN14F18X02B		
QN14F25X03D			.250 × .032	0.92	0.23	0.29	QN14F25X03B		
QN10F25X03D		12-10	.250 × .032	0.97	0.23	0.25	QN10F25X03B		

\* For UL Listed applications consult BURNDY® factory.

**TYPE Q-M FINGRIP™**

**NON-INSULATED MALE  
QUICK DISCONNECTS**

Material: Tin-Plated Brass

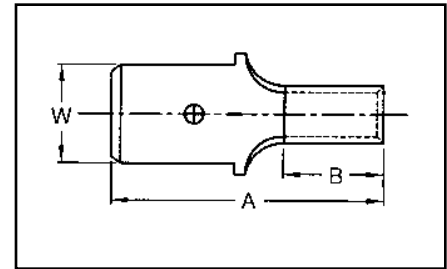

**Features and Benefits**

- Butted seam.
- Chamfered barrel opening.
  - ◇ Assures quick and easy wire insertion.
- Mates with dimpled female socket detent.
  - ◇ Ensures firm grip.



**MALE BARE DISCONNECT TERMINAL**

(Mates with Type Q-F female disconnects)

Standard Catalog Number	Std. Pkg. Qty.	Wire Range	NEMA Tab Size	Dimensions			Bulk Catalog Number	Bulk Pkg. Qty.	Installation Tool*
				A	B	W			
Q18M18X02D	100	18-22	.187 × .020	0.55	0.17	0.19	Q18M18X02B	1000	MR20, Y10D
Q18M25X03D			.250 × .032	0.67	0.17	0.25	Q18M25X03B		
Q14M18X02D	100	14-16	.187 × .020	0.55	0.17	0.19	Q14M18X02B		
Q14M25X03D			.250 × .032	0.67	0.17	0.25	Q14M25X03B		

\* For UL Listed applications consult BURNDY® factory.

Blue highlighted items are industry standard and most frequently ordered.