
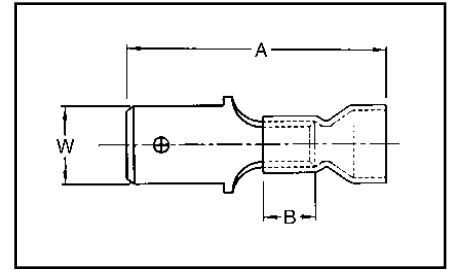


## TYPE QP-M FINGRIP™

### VINYL INSULATED MALE QUICK DISCONNECTS

Material: Tin-Plated Brass  
600 Volts Max., 105° C Max.

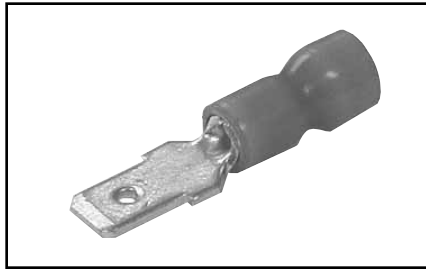

#### Features and Benefits

- Butted seam.
- Funnel entry barrel opening.
  - ◇ Assures quick and easy wire insertion.
- Mates with dimpled female socket detent.
  - ◇ Ensures firm grip.



#### MALE VINYL DISCONNECT TERMINAL

(Mates with Type QP-F female disconnects)



Standard Catalog Number	Std. Pkg. Qty.	Wire Range	NEMA Tab Size	Dimensions			Bulk Catalog Number	Bulk Pkg. Qty.	Installation Tool*
				A	B	W			
QP18M18X02D	100	18-22	.187 × .020	0.83	0.17	0.19	QP18M18X02B	1000	Y10D
QP18M25X03D			.250 × .032	0.95	0.17	0.25	QP18M25X03B		
QP14M18X02D	100	14-16	.187 × .020	0.83	0.17	0.19	QP14M18X02B	1000	
QP14M25X03D			.250 × .032	0.95	0.17	0.25	QP14M25X03B		

\* For UL Listed applications consult BURNDY® factory.

## TYPE QN-M FINGRIP™

### NYLON INSULATED MALE QUICK DISCONNECTS

Material: Tin-Plated Brass  
300 Volts Max., 105° C Max.

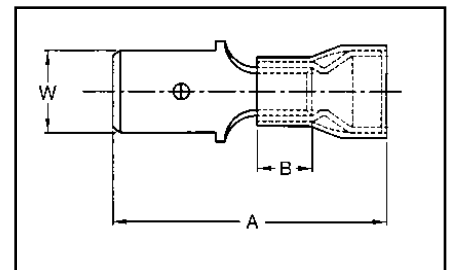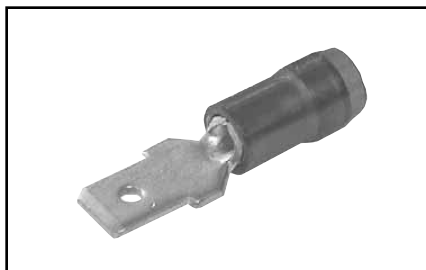

#### Features and Benefits

- Sleeved barrel.
- Funnel entry barrel opening.
  - ◇ Assures quick and easy wire insertion.
- Mates with dimpled female socket detent.
  - ◇ Ensures firm grip.



#### MALE NYLON DISCONNECT TERMINAL

(Mates with Type QN-F female disconnects)

Standard Catalog Number	Std. Pkg. Qty.	Wire Range	NEMA Tab Size	Dimensions			Bulk Catalog Number	Bulk Pkg. Qty.	Installation Tool*
				A	B	W			
QN18M18X02D	100	18-22	.187 × .020	0.82	0.17	0.19	QN18M18X02B	1000	Y10D
QN18M25X03D			.250 × .032	0.91	0.17	0.25	—		
QN14M18X02D	100	14-16	.187 × .020	0.84	0.17	0.19	QN14M18X02B	1000	
QN14M25X03D			.250 × .032	0.91	0.17	0.25	QN14M25X03B		

\* For UL Listed applications consult BURNDY® factory.

Blue highlighted items are industry standard and most frequently ordered.