


TYPES YAV-H BOX AND YAV-H

HYLUG™

Seamless Uninsulated Compression Ring Tongue Terminal With Shroud

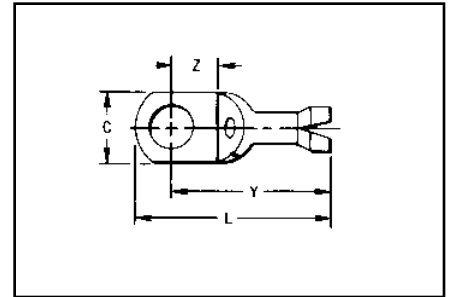

The type YAV-H HYLUG™ is a seamless heavy duty uninsulated compression ring tongue terminal with a shroud for an insulation grip and cable support. They are manufactured from pure electrolytic copper tubing for use on copper commercial (code) cable, Type AN aircraft cable and extra flexible conductors.

The seamless design produces a double thick tongue and the seamless barrel provides a strong highly reliable connection.

Meets the requirements of SAE-AS7928. The benefits of the Type YAV apply to the YAV-H HYLUG™.

Features and Benefits

- Shroud/insulation grip cable support and strain relief.
 - ◇ Protects the wire against breaking under vibration or flexing conditions.



Catalog Number	Wire Range	Stud Size	Max. Insul. Dia. Accom.	Dimensions				Bulk Catalog Number	Installation Tooling	Dies	Wire Strip Length
				C	L Max.	Y Max.	Z Min.				
YAV18-H BOX	22-18	8-10	.120"	.31	.91	.76	.24	YAV18-H	Plier: Y10D*, Y10-22*	M8ND, with N14HT, N14HT-5 Die	9/32"
YAV14-H1 BOX	20-14	6-8	.150"	.31	.95	.80	.24	YAV14-H1			Ratchet: MR8-G98, MR8-9Q, Y8MRB-1*, MR20*, M8ND
YAV14-H BOX		8-10		.31	.95	.80	.24	YAV14-H			
YAV14-H2 BOX		1/4		.42	1.14	.90	.32	YAV14-H2			
YAV10-H25 BOX	12-10	6-8	.192"	.31	1.04	.90	.24	YAV10-H25	MR8-9Q, Y8MRB-1*, MR20*, M8ND	M8ND, N10HT-24	7/16"
YAV10-H BOX		8-10		.38	1.09	.91	.24	YAV10-H			
YAV10-H3 BOX		1/4		.47	1.22	.99	.32	YAV10-H3			

* For conductor crimp only.