

UNIRAP™
Cable Tie Variety Pack
UL Listed



Catalog Number: **CTASST**



Contents			
Quantity	Length	Color	Strength
100	40	Natural	18# Strength
100	40	Black	18# Strength
100	80	Black	50# Strength
200	80	Natural	50# Strength
50	110	Natural	50# Strength
50	110	Black	50# Strength

UNIRAP™
Hand Tools



MK7, MK9

MK7, MK9
For Use On:

- MK7** Used on all UNIRAP™ ties with body width of .10" to .19".
- MK9** Used on all UNIRAP™ ties with body width of .10" to .35".


TWT1 & TWT2
Specifications

- Length:** 6.68"
- Width:** .81"
- Weight:** 1.25 oz.



TWT1, TWT2

UNIRAP™
Mounting Bases

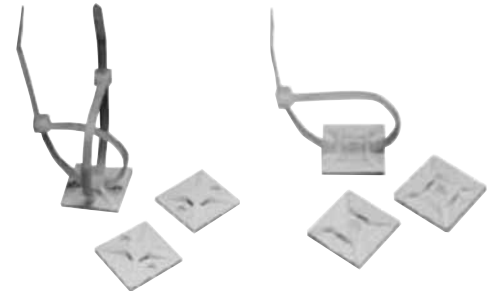

4-Way Mounting Base 2-Way Mounting Base

BURNDY® mounting bases are available in adhesive or screw mount forms. The 4-way mounting bases come in 3 sizes to accommodate UNIRAP™ ties from 18 lbs. tensile strength up to 175 lbs. All bases are made of standard nylon and are offered in weather resistant forms.

4-Way Mounting Bases

Std. Pkg. Catalog Number	Material	Max. Tie Slot Width In. (mm)	Mounting Technique	Bulk Pkg. Catalog Number
CTB075S4C	Nylon 6/6	.14 (3.5)	4 Screw	CTB075S4M
CTB075RA4C			Adhesive	CTB075RA4M
CTB125S4C		.20 (5.1)	8 Screw	CTB125S4D
CTB125RA4C			Adhesive	CTB125RA4D
CTB150S4C		.35 (8.9)	8 Screw	CTB150S4B
CTB150RA4C			Adhesive	CTB150RA4

*For weather resistant UV UNIRAP™ mounts add suffix "0" to catalog number (example: CTB075S4C0).

2-Way Mounting Bases

Std. Pkg. Catalog Number	Material	Max. Tie Slot Width In. (mm)	Mounting Technique
CTB125S2C	Nylon 6/6	.18 (4.5)	6 Screw
CTB125RA2C			Adhesive

*For weather resistant UV UNIRAP™ mounts add suffix "0" to catalog number.