
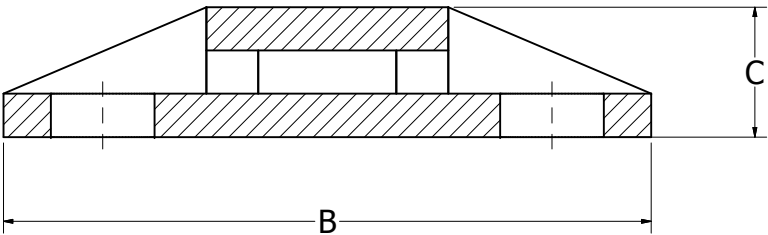


CATALOG NUMBER	TYPE	SIZE	DIMENSION A	DIMENSION B	DIMENSION C	MOUNTING METHOD	FEATURE	PACKAGE QUANTITY	COLOR
CTB125AA4C	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	ACRYLIC ADHESIVE	4 WAY	100	NATURAL
CTB125AA4C0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	ACRYLIC ADHESIVE	4 WAY	100	UV BLACK
CTB125AA4D	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	ACRYLIC ADHESIVE	4 WAY	500	NATURAL
CTB125AA4D0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	ACRYLIC ADHESIVE	4 WAY	500	UV BLACK
CTB125RA2C	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.21 [5]	RUBBER ADHESIVE	2 WAY	100	NATURAL
CTB125RA2C0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	2 WAY	100	UV BLACK
CTB125RA2D	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	2 WAY	500	NATURAL
CTB125RA4C	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	4 WAY	100	NATURAL
CTB125RA4C0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	4 WAY	100	UV BLACK
CTB125RA4D	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	4 WAY	500	NATURAL
CTB125RA4D0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	4 WAY	500	UV BLACK
CTB125RA4L	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	RUBBER ADHESIVE	4 WAY	50	NATURAL
CTB125S2C	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.21 [5]	#6 SCREW MOUNTED	2 WAY	100	NATURAL
CTB125S4C	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	#8 SCREW MOUNTED	4 WAY	100	NATURAL
CTB125S4C0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	SCREW MOUNTED	4 WAY	100	UV BLACK
CTB125S4D	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	SCREW MOUNTED	4 WAY	500	NATURAL
CTB125S4D0	CABLE TIE BASE	1.25 [32]	1.125 [29]	1.125 [29]	.19 [5]	SCREW MOUNTED	4 WAY	500	UV BLACK

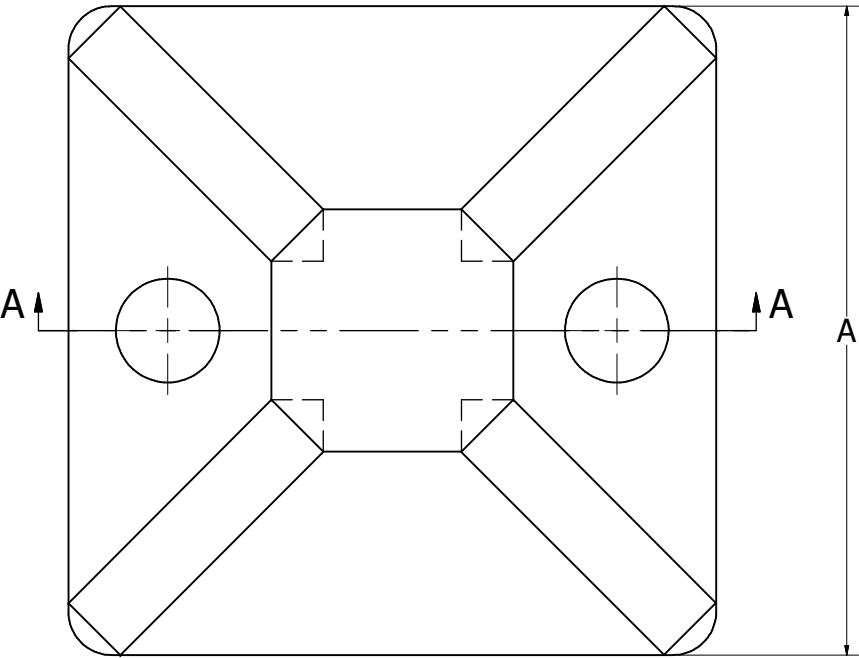

SECTION : A-A

NOTES:

1. DIMENSIONS IN BRACKETS [] ARE IN MILLIMETERS ROUNDED OFF TO THE NEAREST MILLIMETER, UNLESS OTHERWISE SPECIFIED AND ARE FOR REFERENCE ONLY.