



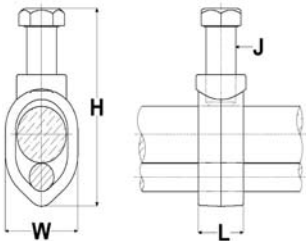

On Line Catalog

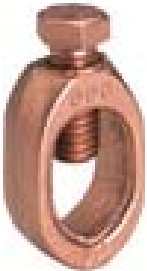

BURNDY Catalog Number
UPC Number
Description
Status

GRC58
7818102309611
5/8 IN GRD ROD CLAMP
Active

Web Use
BURNDY Product Line

Width (in)
Height (in)
Size (Hex) or Size (Bolt)
Size (Hex) or Size (Bolt) - in
B Length (in)

Dimensional
0.95
2.19
3/8
0.38
0.63

Product Description

General
Mechanical Ground Rod Clamp,
For Cable to Rod, High Strength,
10 AWG (Sol)- 1 AWG (Str), 5/8"
Drive Rod, 3/8" Stud

Rod Size (Range)
Copper Solid Size (Range)
Copper Stranded (Range)

Conductor(s)
5/8 in
10 AWG
12 AWG-1 AWG

Product Material

Physical
Copper

Approvals / Certifications
Rated for Direct Burial
UL Listed
CSA Certified
ROHS Compatible
UL Recognized
CULUS
Industry Standards

Y
Y
Y
Compliant
N
N
RUS

Documentation