


WCB12

by Burndy
Catalog ID: WCB12

Prop 65 Notice

Wejtap connector installed with blue booster, .364-.568 (Run), .162-.204 (Tap).

Features: With Blue Power Booster, ANSI Class AA, Booster: WPBB Box 25, Installation Tool: WTRB Tool, Conductor Size (tap - Mm): 4 - 5 SQ-MM, Color Code: Blue, Booster Color: Blue, Cable Diameter Range (run): 0.364 - 0.568 IN, Conductor Type: Run: ACSR, AAC, Tap: ACSR, AAC, Copper, Cable Diameter Range (tap): 0.162 - 0.204 IN, Conductor Size (run - Mm): 9 - 14 SQ-MM

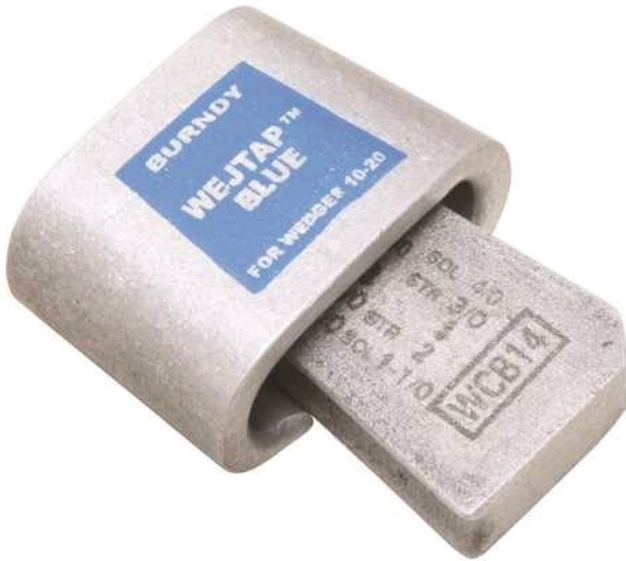

Product Details

General

Application	For use in tap applications using large run and tap conductor sizes
Sub Brand	WEJTAP
Type	Wejtap Connector
UPC	781810872550

Certifications and Compliance

Certification - CSA Approved	No
Certification - ETL	No
Standards - RoHS Compliance Status	CM
UL Listed	No

Logistics

Minimum Pack Quantity	25
-----------------------	----

For further technical assistance, please contact us

BURNDY Headquarters
47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:
8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)