


WSL4

by Burndy
Catalog ID: WSL4

Prop 65 Notice

Stirrup Assembly, Large stirrups,Run:.862-.722,Tap:.324-.324.

Features: Run Conductor Position Is Identified On All Wedges Via A Distinct Chamfer, Booster: WPBY Box 25, Installation Tool: WTRBYK Tool, Color Code: Yellow, Cable Diameter Range (run): 0.722 - 0.862 IN, Conductor Type: ACAR, ALUMOWELD, Copper (Compact Or Compressed), Galvanized Steel, ACSR (Compact Or Compressed), AAAC, Copperweld, ASC, SOLID (Copper Or Aluminum), AWAC, AAC (Standard), ACSR (Standard), Bail Size: 1/0 AWG, Cable Diameter Range (tap): 0.324 - 0.324 IN

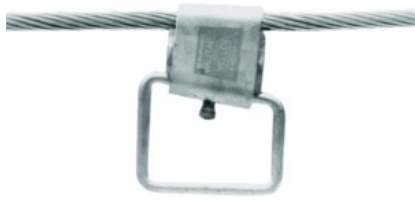

Product Details

General

Application	For Common ACSR, Aluminum And Copper Conductors
Color	Yellow
Material	Aluminum
Physical Attribute - Number of Holes	1
Sub Brand	WEJTAP, STIRRUP
Trade Name	WEJTAP™
Type	Wejtap with Stirrup
UPC	781810877258
UPC 12 Digit	7818108772588

Dimensions

Dimension - Bail Size	1/0
Dimension - F Width Center to Center inch	3 in
Dimension - G inch	1.53 in
Dimension - Hole Size fraction	17/50
Dimension - Hole Size inch	0.34 in

Conductor Related

Conductor - ACSR Str Size	397.5 (18/1) Chickadee;397.5 (24/7) Brant;397.5 (26/7) Ibis;397.5 (30/7) Larkspur;477.0 (18/1) Pelican;477.0 (24/7) Flicker;477.0 (26/7) Hawk;477.0 (30/7) Hen
Conductor - ACSR Str Size Range	397.5 (18/1) Chickadee-477.0 (30/7) Hen
Conductor - AL Str Size	397.5;400;450;477
Conductor - AL Str Size Range	397.5-477
Conductor - Copper Str Size	400;450
Conductor Type	<ul style="list-style-type: none"> • ACSR C Str-Size • AL C Str-Size • CU C Str-Size

Certifications and Compliance

Certification - CSA Approved	No
Standards - RoHS Compliance Status	CM

Logistics

Minimum Pack Quantity	5
-----------------------	---

For further technical assistance, please contact us

BURNDY Headquarters

47 East Industrial Park Drive
Manchester, New Hampshire 03109

Customer Service Hours:

8 AM - 8 PM Eastern Monday-Friday
Emergency Service 24-hours/365 Days
Phone: 1-800-346-4175
1-603-647-5299 (International)