



## Specifications (cont.)

<b>Ambient temperature</b> Operating temperature	-20° to +70°C (-4° to +158°F)	<b>Housing material</b> Body	PBT Valox 855, red
Storage temperature	-40° to +85°C (-40° to +185°F)	Backpart	Arnitel EL630
<b>Vibration</b>	10 to 150 Hz, 1.0 mm/15 G (IEC 60068-2-6)	Trimmer	LCP Vectra A 130
<b>Shock</b>	30 g / 11ms, 3 pos, 3 neg per axis (IEC 60068-2-6, 60068-2-32)	<b>Connection</b> Cable	PVC, gray, 2 m 5 x 0.75 mm <sup>2</sup> , Ø = 7.6 mm
<b>Rated insulation voltage</b>	≥ 250 VAC (rms)	<b>Weight</b>	≤ 320 g
		<b>Approvals</b>	cULus (UL508+CSA)
		<b>CE-marking</b>	Yes

## Dimensions

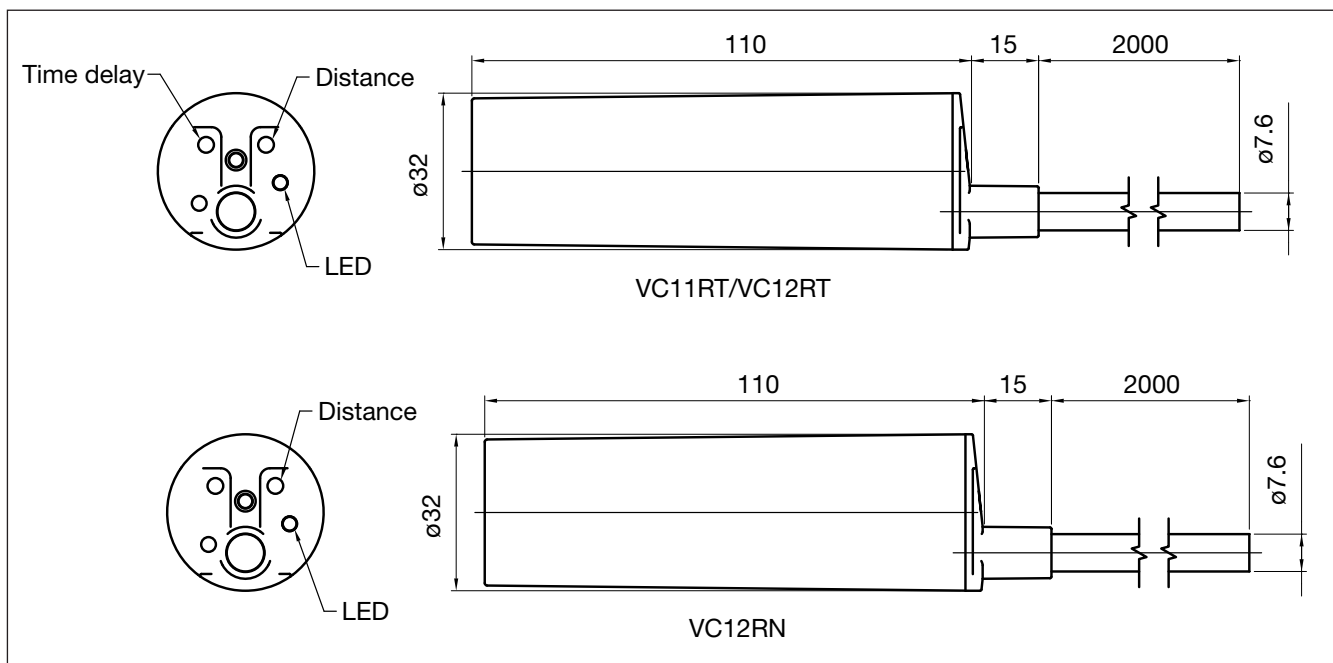

### Trimmer VS Delaytime

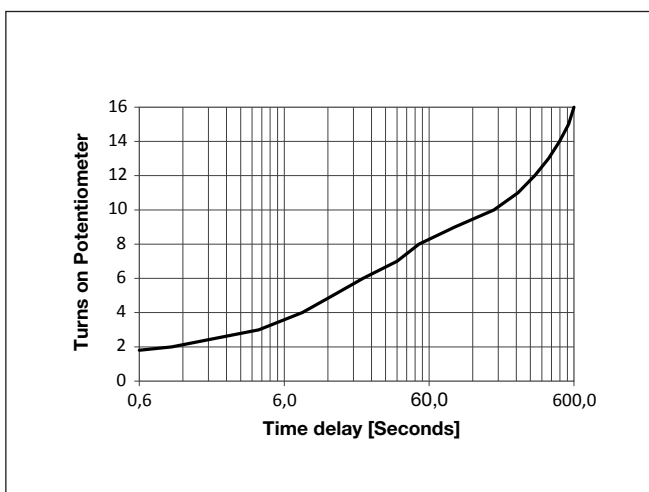

### Trimmer VS Distance

