
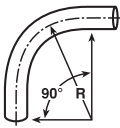
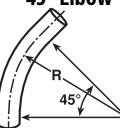
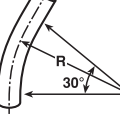
 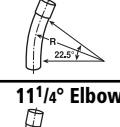


## Schedule 80 Elbows Standard Radius

Available in plain end only for use with nonmetallic solvent weld fittings.

Item	Plain End Part No.	Belled End Part No.	Size	Plain End Std. Ctn. Qty.	Belled End Std. Ctn. Qty.	
<b>90° Elbow</b> 	UB9AD	-	1/2"	50	-	
	UB9AD-CAR	-	1/2"	25	-	
	UB9AE	-	3/4"	25	-	
	UB9AE-CAR	-	3/4"	15	-	
	UB9AF	-	1"	25	-	
	UB9AF-CAR	-	1"	10	-	
	UB9AG	-	1 1/4"	20	-	
	UB9AG-CAR	-	1 1/4"	5	-	
	UB9AH	-	1 1/2"	25	-	
	UB9AH-CAR	-	1 1/2"	5	-	
	UB9AJ	-	2"	20	-	
	UB9AJ-CAR	-	2"	5	-	
	UB9AK-CAR	-	2 1/2"	10	-	
	UB9AL-CAR	-	3"	5	-	
	UB9AN	-	4"	1	-	
	UB9AP	UB9APB	5"	1	1	
	UB9AR	-	6"	1	-	
	<b>45° Elbow</b> 	UB7AD	-	1/2"	50	-
		UB7AE-UPC	-	3/4"	25	-
		UB7AF-UPC	-	1"	20	-
UB7AG		-	1 1/4"	20	-	
UB7AH		-	1 1/2"	20	-	
UB7AH-CAR		-	1 1/2"	5	-	
UB7AJ-UPC		-	2"	20	-	
UB7AK		-	2 1/2"	20	-	
UB7AL		-	3"	1	-	
UB7AN		-	4"	1	-	
UB7AP		UB7APB	5"	1	1	
UB7AR		-	6"	1	-	
<b>30° Elbow</b> 		UB6AD	-	1/2"	50	-
		UB6AE	-	3/4"	25	-
	UB6AF	-	1"	25	-	
	UB6AG	-	1 1/4"	5	-	
	UB6AH	-	1 1/2"	25	-	
	UB6AJ	-	2"	20	-	
	UB6AK	-	2 1/2"	1	-	
	UB6AL	-	3"	1	-	
	UB6AN	-	4"	1	-	
	UB6AP	-	5"	1	-	
<b>22 1/2° Elbow</b> 	UB5AL	-	3"	5	-	
	UB5AN	-	4"	1	-	
<b>11 1/4° Elbow</b> 	UB3AL	-	3"	1	-	
	UB3AR	-	6"	1	-	

## Flexible PVC Elbows



- UL listed for exposed and direct burial applications in accordance with Article 356 of 2002 NEC
- 0° - 90° bending and offset applications
- O-ring seal for moisture tight connections
- Maintains round shape throughout bend
- Sunlight resistant
- Non-corrosive – all PVC and Neoprene material
- Fully assembled and ready to use




Part No.	Size	Std. Ctn. Qty.	Std. Ctn. Wt. (lbs.)	Length Fully Assembled
UAFAD	1/2"	8	1.6	8.5"
UFAAE	3/4"	6	1.9	9.6"
UFAAF	1"	6	2.4	11.9"

## Special Radius



ETL Listed to UL 651 in compliance to the NEC

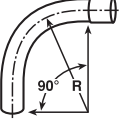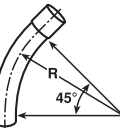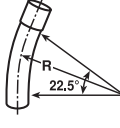

Segment	Plain End Part No.	Belled End Part No.	Nom. Diam.	Radius (in.)	Plain End Std. Ctn. Qty.	Belled End Std. Ctn. Qty.		
<b>90° Elbow</b> 	UB9CF	-	1"	18"	1	-		
	UB9DF	-	1"	24"	1	-		
	UB9FF	-	1"	36"	1	-		
	UB9HF	-	1"	48"	1	-		
	UB9CG	-	1 1/4"	18"	1	-		
	UB9DG	-	1 1/4"	24"	1	-		
	UB9FG	-	1 1/4"	36"	1	-		
	UB9HG	-	1 1/4"	48"	1	-		
	UB9CH	-	1 1/2"	18"	1	-		
	UB9DH-UPC	UB9DHB	1 1/2"	24"	1	1		
	UB9FH	-	1 1/2"	36"	1	-		
	UB9HH	-	1 1/2"	48"	1	-		
	UB9CJ	-	2"	18"	1	-		
	UB9DJ-UPC	UB9DJB	2"	24"	1	1		
	UB9FJ	UB9FJB	2"	36"	1	1		
	UB9HJ	-	2"	48"	1	-		
	UB9CK	-	2 1/2"	18"	1	-		
	UB9DK-UPC	UB9DKB	2 1/2"	24"	1	1		
	UB9FK	UB9FKB	2 1/2"	36"	1	1		
	UB9HK	-	2 1/2"	48"	1	-		
	UB9CL	-	3"	18"	1	-		
	UB9DL	UB9DLB	3"	24"	1	1		
	UB9FL	UB9FLB	3"	36"	1	1		
	UB9HL	-	3"	48"	1	-		
	UB9DN	UB9DNB	4"	24"	1	1		
	UB9FN	UB9FNB	4"	36"	1	1		
	UB9HN	UB9HNB	4"	48"	1	1		
	UB9NN	-	4"	120"	1	-		
	UB9FP	-	5"	36"	1	-		
	UB9HP	-	5"	48"	1	-		
	UB9IP	-	5"	60"	1	-		
	UB9FR	-	6"	36"	1	-		
	UB9HR	-	6"	48"	1	-		
	UB9IR	-	6"	60"	1	-		
	<b>45° Elbow</b> 	UB7CF	-	1"	18"	1	-	
		UB7DF	-	1"	24"	1	-	
		UB7FF	-	1"	36"	1	-	
		UB7HF	-	1"	48"	1	-	
		UB7DG	-	1 1/4"	24"	1	-	
		UB7FG	-	1 1/4"	36"	1	-	
		UB7HG	-	1 1/4"	48"	1	-	
		UB7CH	-	1 1/2"	18"	1	-	
		UB7DH	UB7DHB	1 1/2"	24"	1	1	
		UB7FH	-	1 1/2"	36"	1	-	
		UB7HH	-	1 1/2"	48"	1	-	
		UB7CJ	-	2"	18"	1	-	
		UB7DJ	UB7DJB	2"	24"	1	1	
		UB7FJ	UB7FJB	2"	36"	1	1	
UB7HJ		-	2"	48"	1	-		
UB7DK		UB7DKB	2 1/2"	24"	1	1		
UB7FK		-	2 1/2"	36"	1	-		
UB7HK		-	2 1/2"	48"	1	-		
UB7CL		-	3"	18"	1	-		
UB7DL		UB7DLB	3"	24"	1	1		
UB7FL		UB7FLB	3"	36"	1	1		
UB7HL		-	3"	48"	1	-		
UB7DN		UB7DNB	4"	24"	1	1		
UB7FN		UB7FNB	4"	36"	1	1		
UB7HN		-	4"	48"	1	-		
UB7FP		-	5"	36"	1	-		
UB7HP		-	5"	48"	1	-		
UB7FR		-	6"	36"	1	-		
UB7HR		-	6"	48"	1	-		
UB7IR		-	6"	60"	1	-		
<b>30° Elbow</b>		UB6FN	-	4"	36"	1	-	
		UB6FR	-	6"	36"	1	-	
		<b>22 1/2° Elbow</b> 	-	UB5DHB	1 1/2"	24"	-	20
			-	UB5DJB	2"	24"	-	20
			-	UB5FJB	2"	36"	-	25
			-	UB5DKB	2 1/2"	24"	-	15
			UB5DL	UB5DLB	3"	24"	1	10
			-	UB5FLB	3"	36"	-	1
		UB5DN	UB5DNB	4"	24"	1	5	
		-	UB5FNB	4"	36"	-	1	
		UB5FP	-	5"	36"	1	-	
		<b>11 1/4° Elbow</b>	UB3FP	-	5"	36"	1	-