

## Cable Ties

### Catalogue Number Construction

**L**      **4**      **18**      **HS**      -      **9**      **M**

**Product Prefix**  
P - Plain Bagged Cable Ties  
L - Cable Ties

**Length**  
18 lb.  
30 lb.  
40 lb.  
50 lb.  
120 lb.  
175 lb.  
250 lb.

**Tensile Strength**

**Type of Product**  
Nylon 66 - Leave Blank  
Heat Stabilized - HS  
(Black and Natural Colour Only)  
Fluorescent - FL  
Mounting Head - MH  
Pushmount - PM  
Pushmount Releasable - PMR  
Releasable - R  
Restricted Bundle - TB  
Identification - ID

**Colour**  
See Colour Table

**Quantity**  
Q - 25 pack  
L - 50 pack  
C - 100 pack  
D - 500 pack  
M - 1,000 pack

**MP**      **NY**      -      **750**      -      **9**      **C**

**Material**  
Nylon  
TZ - Fluoropolymer  
PV - PVC  
PE - Polyethylene  
FR - Flame Retardant  
TL - Teflon

**Size / #**  
.75"

**Colour**  
See Colour Table

**Quantity**  
Q - 25 pack  
L - 50 pack  
C - 100 pack  
D - 500 pack  
M - 1,000 pack

- Product Prefix**
- MP - Mounting Pad
  - ID - Identification
  - S# - Strapping Thickness
  - MC - Mounting Cradle
  - PM - Push Mounts
  - SM - Screw Mounts
  - N# - Plain-Edged Cable Clamps / Width
  - W# - Self-Aligning Cable Clamps / Dia.
  - UL - Adjustable Cable Clamps
  - GG - Gator Grip
  - FA - Flat Adhesive Clip
  - FS - Flat Screw Clip
  - FR - Flat Rubber Adhesive Clip
  - MS - Snap Mount
  - RA - Round Adhesive Clip
  - SR - Spiral Wrap
  - GS - Grommeting
  - GR - Extruded Grommeting
  - GRU - Extruded Grommeting Uncut

 
Colour Table	
0 - Black (Weather-Resistant)	7 - Purple
1 - Brown	8 - Grey
2 - Red	9 - Natural
3 - Orange	11 - Fluorescent Pink
4 - Yellow	16 - Fluorescent Orange
5 - Green	17 - Fluorescent Yellow
6 - Blue	18 - Fluorescent Green
	20 - Fluorescent Blue

## Cable Ties




Cat. No.	Length (in.)	Max. Bundle Dia. (in.)	Colour	Std. Pkg.
<b>Identification Ties</b>				
<b>L-7-50ID-9-C</b>	7.875	1-3/4	Natural	100
<b>L-4-18ID-9-C</b>	4.0	3/4	Natural	

Bulk packages available. Contact your Regional Sales Office.  
Use QC-100, L-200, L-400-C or ERG-50 Installation Tools.



Cat. No.	Width (in.)	Height (in.)	Slot Height (in.)	Slot Width (in.)	Colour	Std. Pkg.
<b>Identification Tags</b>						
<b>IDNY-1500-9-M</b>	1.5	0.745	0.090	0.200	Natural	100
<b>IDNY-2000-9-M</b>	2.0		0.113	0.336	Natural	

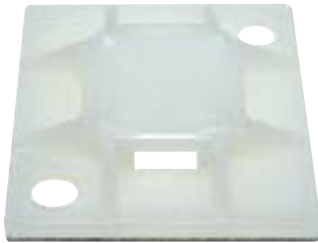

- 3/4 in. and 1-1/8 in. mounts for use with 18# through 50# tensile cable ties
- Supplied on rubber-based or acrylic closed cell foam adhesive or with no adhesive for #6 screw mount applications
- Available in 6.6 Natural Nylon and 6.6 Black Nylon
- UL Flammability 94 V-2 (clip)

Cat. No.	Mount Method	Colour
<b>Cable Tie Mounting Bases</b>		
3/4 in. Class		
<b>MPNY-750-9-C</b>	Synthetic Rubber Adhesive	Natural
<b>MPNY-750-0-C</b>	Synthetic Rubber Adhesive	Black
<b>MPNY-750A-9-C</b>	Acrylic Adhesive	Natural
<b>MPNY-750A-0-C</b>	Acrylic Adhesive	Black
<b>MPNY-750S-9-C</b>	#6 Screw	Natural
<b>MPNY-750S-0-C</b>	#6 Screw	Black
1 in. Class		
<b>MPNY-1000-9-C</b>	Synthetic Rubber Adhesive	Natural Nylon
<b>MPNY-1000-0-C</b>	Synthetic Rubber Adhesive	Black Nylon
<b>MPNY-1000A-9-C</b>	Acrylic Adhesive	Natural Nylon
<b>MPNY-1000A-0-C</b>	Acrylic Adhesive	Black Nylon
<b>MPNY-1000S-9-C</b>	#6 Screw	Natural Nylon
<b>MPNY-1000S-0-C</b>	#6 Screw	Black Nylon

For use with 18–50 lb. Cable Ties.

- Mounting Surface should be cleaned with alcohol based (IPA) cleaner before application
- Acrylic Based may be repositioned initially. Allow 24–72 hours setup for maximum performance with Acrylic Based adhesives
- For Rubber Based, allow 15 minutes setup for maximum performance