


# Thomas & Betts

## Cable Clamps and Clips



### Gator Grip Hose Clamp

- 16 sizes for bundle diameters to 2 1/2".
- Removable and reusable. Twist by hand or with pliers to remove.
- Stocked in black Nylon. 100 pieces per package.
- UL Flammability 94 V-2.
- Request samples for testing to your application. Tested to 250 PSI.

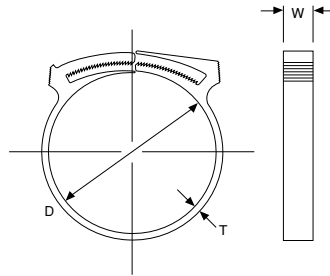

Cat. No.	D Nominal Diameter		D1 Closed Diameter		T Thickness		W Width		Bulk Pkg. Qty.
	Inch	(mm)	Inch	(mm)	Inch	(mm)	inch	(mm)	
GGNY-344-0-C	1 1/32	(10.32)	1 1/32	(8.73)	.070	(1.8)	.220	(5.6)	100
GGNY-406-0-C	1 5/32	(11.92)	1 3/32	(10.32)	.070	(1.8)	.220	(5.6)	100
GGNY-468-0-C	1 7/32	(13.49)	1 5/32	(11.91)	.070	(1.8)	.220	(5.6)	100
GGNY-531-0-C	1 9/32	(15.08)	1 7/32	(13.49)	.070	(1.8)	.220	(5.6)	100
GGNY-593-0-C	2 1/32	(16.67)	1 9/32	(15.08)	.070	(1.8)	.220	(5.6)	100
GGNY-672-0-C	1 3/16	(20.64)	4 3/64	(17.07)	.070	(1.8)	.220	(5.6)	100
GGNY-750-0-C	7/8	(22.23)	3/4	(19.05)	.070	(1.8)	.220	(5.6)	100
GGNY-875-0-C	1	(25.40)	7/8	(22.23)	.070	(1.8)	.220	(5.6)	100
GGNY-953-0-C	1 1/32	(27.78)	6 1/64	(24.21)	.070	(1.8)	.310	(7.9)	100
GGNY-1031-0-C	1 1/16	(30.16)	1 1/32	(26.19)	.070	(1.8)	.310	(7.9)	100
GGNY-1250-0-C	1 7/16	(36.51)	1 1/4	(31.75)	.070	(1.8)	.360	(9.1)	100
GGNY-1406-0-C	1 5/8	(41.28)	1 13/32	(35.72)	.070	(1.8)	.360	(9.1)	100
GGNY-1593-0-C	1 13/16	(46.04)	1 19/32	(40.48)	.070	(1.8)	.360	(9.1)	100
GGNY-1687-0-C	1 29/32	(48.42)	1 11/16	(42.86)	.070	(1.8)	.360	(9.1)	100
GGNY-1875-0-C	2 1/8	(53.98)	1 7/8	(47.63)	.070	(1.8)	.400	(10.2)	100
GGNY-2125-0-C	2 1/2	(60.33)	2 3/8	(53.98)	.070	(1.8)	.400	(10.2)	100
Tolerance ±					.010 (.254)				

Ty-Rap® / Ty-Fast®