



Thomas & Betts

Cable Clamps and Clips

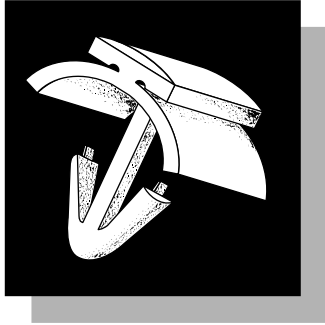

Snap Mounts


- For panel thicknesses from .060" to .150" to hold separate pieces of material together.
- Used with W4 or N4 Series Cable Clamps; allowable panel thickness is .030" to .050".
- Stocked in Natural 6/6 Nylon.
- UL Flammability 94 V-2.

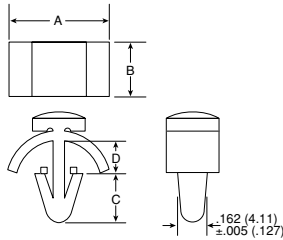

Cat. No.	Material	A		B		C		D		Bulk Pkg. Qty.
		Inch	(mm)	Inch	(mm)	Inch	(mm)	inch	(mm)	
MSNY-166-0-M	UV Black Nylon	.485	(12.32)	.312	(7.93)	.281	(7.14)	.180	(4.57)	1000
Tolerance ±					.010		(.254)			




Ty-Rap®/Ty-Fast®

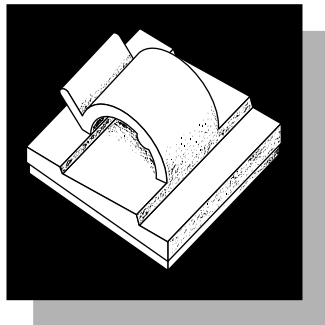

Round Adhesive Clips

- Diverse cable clamps for bundle diameters from .160 to .620.
- Mounted on a rubber based closed cell foam adhesive.
- Natural nylon.
- UL Flammability 94 V-2 (clip).
- Flexible center tang for removal or addition of cables.

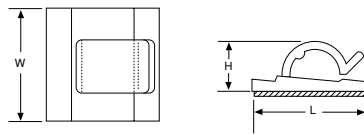

Cat. No.	Material	H Height		L Length		W Width		Maximum Bundle	Mounting Method	Bulk Pkg. Qty.
		Inch	(mm)	Inch	(mm)	Inch	(mm)			
RANY-160-9-D	Natural Nylon	.250	(6.35)	.630	(16.00)	.580	(14.73)	.160	Rubber Based Adhesive	500
RANY-280-9-D	Natural Nylon	.410	(10.41)	1.000	(25.40)	1.000	(25.40)	.280	Rubber Based Adhesive	500
RANY-530-9-D	Natural Nylon	.620	(15.75)	1.000	(25.40)	1.000	(25.40)	.530	Rubber Based Adhesive	500
RANY-620-9-D	Natural Nylon	.560	(14.22)	1.250	(31.75)	1.120	(28.45)	.620	Rubber Based Adhesive	500
Tolerance ±			.015		(.381)					

- Available July 1996.