


# Ty-Fast®

## Cable Ties

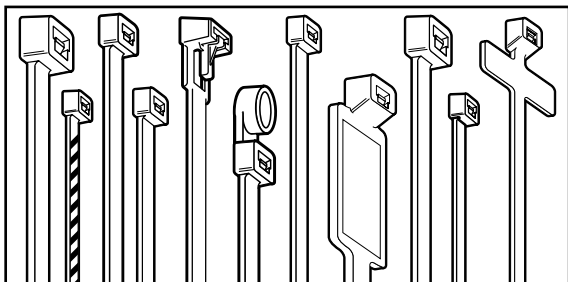

- **MINIATURE**
- **HEAVY DUTY**
- **INTERMEDIATE**
- **EXTRA HEAVY DUTY**
- **STANDARD**
- **RELEASABLE TIES**

- **MOUNTING HEAD**
- **STRIPED TIES**
- **RESTRICTED BUNDLE**
- **IDENTIFICATION TIES**
- **MIL-SPEC TIES**

Ty-Fast® Cable Ties are available in lengths from 4" to our exclusive 48" strap. Cable Ties will satisfy bundling requirements from 1/16" to 15" and loop tensile strengths from 18 to 175 pounds.

Cable Ties are stocked in materials and colors as listed. Contact your Ty-Fast® Distributor or Customer Service Representative for availability in special materials and colors.

Where applicable, Ty-Fast® Cable Ties are UL Recognized, Mil-Spec Approved and/or QPL Listed.

State-of-the-art robotic and raw material handling equipment assures product and material integrity throughout the manufacturing process. Overall quality is achieved through statistical analysis and quality driven operator objectives. Ty-Fast® has attained Mil-Spec I-45208 quality ratings from a number of equipment manufacturers.

Ty-Fast® products are sold through stocking T&B Distributors.

*Strict Tolerances  
Assure Locking  
Strength*

*Reinforced Head and  
Strap Transition for  
Added Strength*

*Highly Engineered Tooth  
and Pawl Design for  
Maximum Engagement*

*Bent Tip Design for  
Easier Assembly*

 
*Recessed  
Entry to  
Guide  
Insertion*

*Generous Radii on  
All Angles to  
Reduce Friction*


*Gradual Strap to Tail  
Transition for Lower  
Insertion Force*

*Raised Grips on  
Tail to Assist  
Operators*


*Ty-Rap®/Ty-Fast®*




**MINIATURE (PAGE J37)**

 


**INTERMEDIATE (PAGE J37)**

 


**STANDARD (PAGE J37)**

 


**HEAVY-DUTY (PAGE J38)**

 


**EXTRA HEAVY-DUTY (PAGE J38)**

 


**MOUNTING HEAD (PAGE J39)**

 


**RESTRICTED BUNDLE (PAGE J39)**

 

**RELEASABLE (PAGE J39)**

 


**MIL-SPEC (PAGE J40)**

 

**PUSH MOUNT (PAGE J41)**



**STRIPED (PAGE J43)**

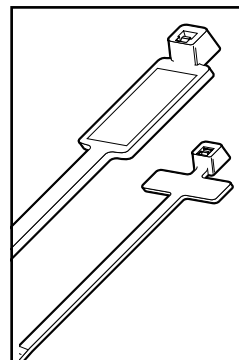



**I.D. TIES (page J42)**

**Thomas & Betts**

# Ty-Fast®

## Cable Ties

### Part Number Construction

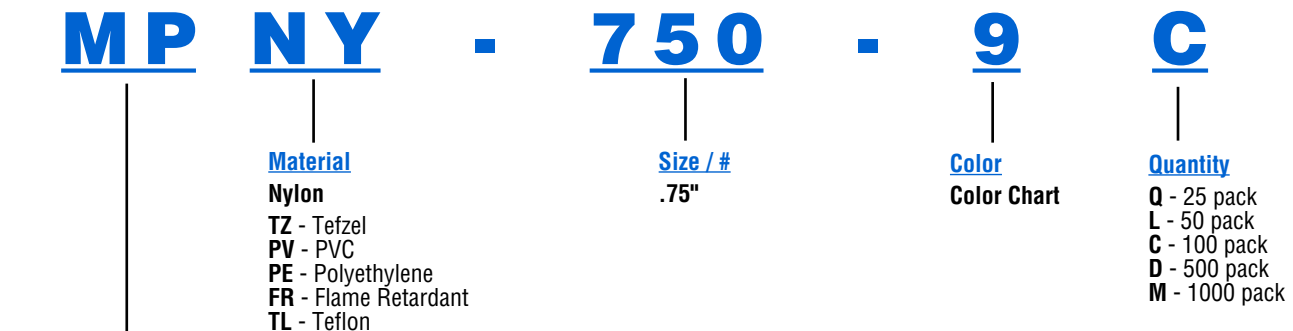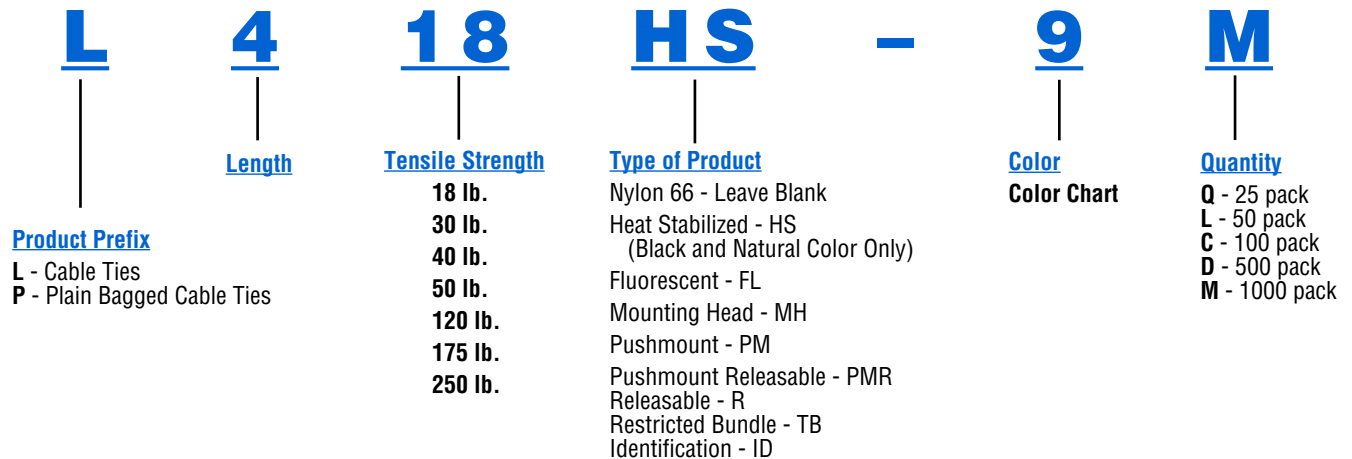

#### Product Prefix

MP - Mounting Pad  
ID - Identification  
S# - Strapping Thickness  
MC - Mounting Cradle  
PM - Push Mounts  
SM - Screw Mounts  
N# - Plain-Edged Cable Clamps / Width  
W# - Self-Aligning Cable Clamps / Dia.  
UL -  
GG - Gator Grip  
FA - Flat Adhesive Clip  
FS - Flat Screw Clip  
FR - Flat Rubber Adhesive Clip  
MS - Snap Mount  
RA - Round Adhesive Clip  
SR - Spiral Wrap  
GS - Grommeting  
GR - Extruded Grommeting  
GRU - Extruded Grommeting Uncut

#### Color Table

|                                  |                         |
|----------------------------------|-------------------------|
| 0 - Black<br>(Weather Resistant) | 7 - Purple              |
| 1 - Brown                        | 8 - Gray                |
| 2 - Red                          | 9 - Natural             |
| 3 - Orange                       | 11 - Fluorescent Pink   |
| 4 - Yellow                       | 16 - Fluorescent Orange |
| 5 - Green                        | 17 - Fluorescent Yellow |
| 6 - Blue                         | 18 - Fluorescent Green  |
|                                  | 20 - Fluorescent Blue   |

Ty-Rap®/Ty-Fast®

**Thomas & Betts**