





3/8" Dia. Heart Cross-Section (cont'd.)

- INCOLOY® Sheath
- 4,520 - 7,830 Watts
- 208, 240, 275 and 480 Volt
- 40 W/In²
- 1600°F Max. Sheath Temp.
- Component of Radiant Heater (type DU-RAD)

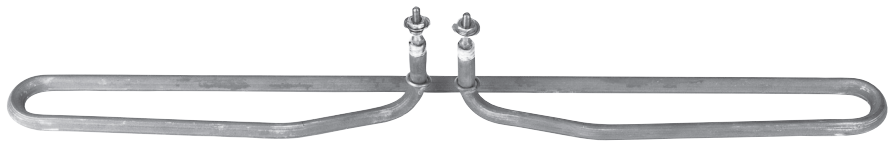

Dimensions

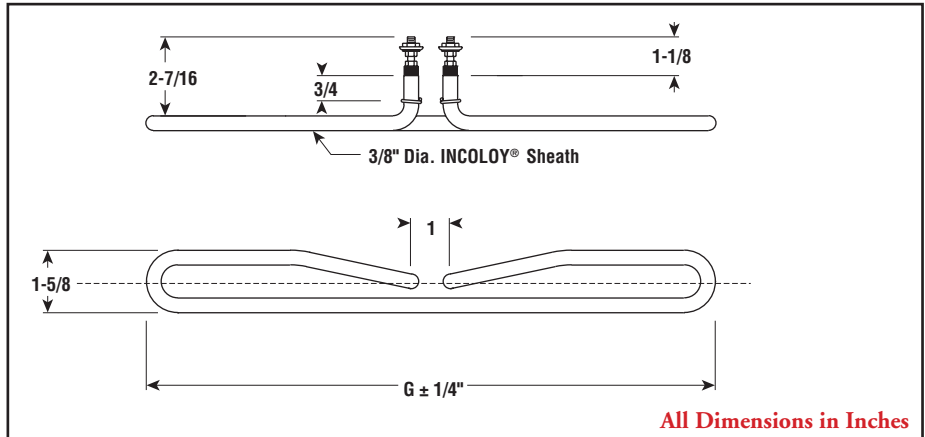

Applications

- Radiant Heating in Room Ambient
- Heating High Velocity Air
- Low Temperature Clamp-ons

Advantages

Specially constructed to provide excellent service life in radiant heating applications.

Features

Type 3 Terminals — Heliarc-welded to the cold pin. See terminal detail drawing in the Tubular Heater Overview section.

Retaining Rings locate elements in radiant heater assemblies.

Bending — Lengthwise only. See bending requirements in the Tubular Heater Overview section.

Specifications and Ordering Information

Watts	Volts	W/In ²	G - DIM (In.)	INCOLOY® Sheath			Wt. (Lbs.)
				Model	Stock	PCN	
4,520	208	40	49-7/8	UTU-102V	NS	147328	2
4,520	240	40	49-7/8	UTU-102	NS	147344	2
4,520	275	40	49-7/8	UTU-102V	NS	147336	2
4,520	480	40	49-7/8	UTU-102	NS	147352	2
4,990	208	40	54-7/8	UTU-112V	NS	147360	3
4,990	240	40	54-7/8	UTU-112	NS	147387	3
4,990	275	40	54-7/8	UTU-112V	NS	147379	3
4,990	480	40	54-7/8	UTU-112	NS	147395	3
5,560	208	40	60-15/16	UTU-124V	NS	147408	3
5,560	240	40	60-15/16	UTU-124	NS	147424	3
5,560	275	40	60-15/16	UTU-124V	NS	147416	3
5,560	480	40	60-15/16	UTU-124	NS	147432	3
6,130	208	40	66-15/16	UTU-136V	NS	147440	3
6,130	240	40	66-15/16	UTU-136	NS	147467	3
6,130	275	40	66-15/16	UTU-136V	NS	147459	3
6,130	480	40	66-15/16	UTU-136	NS	147475	3
6,700	208	40	72-15/16	UTU-148V	NS	147483	4
6,700	240	40	72-15/16	UTU-148	NS	147504	4
6,700	275	40	72-15/16	UTU-148V	NS	147491	4
6,700	480	40	72-15/16	UTU-148	NS	147512	4
7,100	208	40	77	UTU-156V	NS	147520	4
7,100	240	40	77	UTU-156	NS	147547	4
7,100	275	40	77	UTU-156V	NS	147539	4
7,100	480	40	77	UTU-156	NS	147555	4
7,450	240	40	81	UTU-164	NS	147580	4
7,450	275	40	81	UTU-164V	NS	147571	4
7,450	480	40	81	UTU-164	NS	147598	4
7,830	208	40	85-1/16	UTU-172V	NS	147600	5
7,830	240	40	85-1/16	UTU-172	NS	147627	5
7,830	275	40	85-1/16	UTU-172V	NS	147619	5
7,830	480	40	85-1/16	UTU-172	NS	147635	5

Stock Status: S = stock NS = non-stock
To Order—Specify model, PCN, watts, volts and quantity.