


## HSN, HSW & RHSW Half & Full Sheath Ring Heaters

- Narrow Ring (type HSN)
- Wide Ring (type HSW)
- Split Rivet/Wide Ring (type RHSW)
- 500 - 1,000 Watts
- 120 and 240 Volt
- Use Ring Clamp 6018 to Mount Element to Heated Surface



### Dimensions

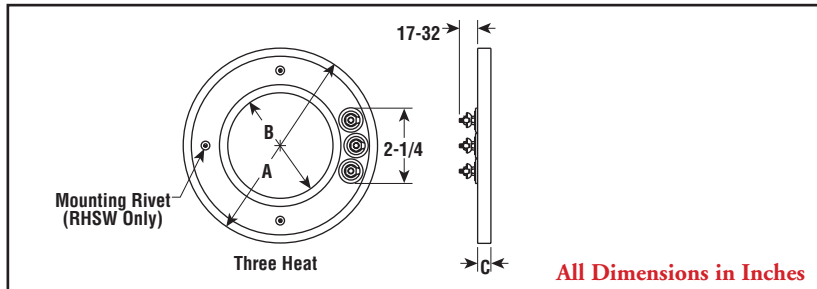

### Features

**Single-Heat Rings** — Have two terminals for single wattage on-off switch or thermostat.

**Three-Heat Rings** — Have three terminals that split the heater into 2 equal circuits. Center terminal is common.

**Easy Installation** — Circular shape and use of Chromalox utility clamps simplifies use of ring heaters.

**Nesting Rings** to pack heat in a small area.

**Half Sheath Units Have Reduced Thermal Gradient to Heated Surface** — Provides faster heat up.



HSW & RHSW Full & Half Sheath



Full Sheath Only



Full Sheath Only

STRIP AND RING

### Specifications and Ordering Information

Dimensions (In.)			Rust-Resisting Iron Sheath						Chrome Steel Sheath						Wt. (Lbs.)		
A	B	C	Watts	W/In <sup>2</sup>	Model	120V		240V		Watts	W/In <sup>2</sup>	Model	120V			240V	
						Stock	PCN	Stock	PCN				Stock	PCN		Stock	PCN
<b>HSN — Half Sheath</b>																	
6	4-5/16	1/4	500	14	HSN-6	S	185818										0.5
6	4-5/16	1/4	800	12	HSN-6			NS	185826								0.5
6	4-5/16	1/4								500	14	HSN-60	NS	185834			0.5
6	4-5/16	1/4								500	14	HSN-60			S	185842	0.5
<b>HSW — Full Sheath</b>																	
6	3-3/4	1/4	1,000	24	HSW-61	S	185877										0.5
<b>HSW — Half Sheath</b>																	
5-7/8	3-9/16	7/32	500	16	HSW-5	S	185746										0.5
5-7/8	3-9/16	7/32	750	23	HSW-5	NS		S	185738								0.5
6	3-3/4	1/4	500	12	HSW-6	S	185754										0.5
6	3-3/4	1/4	500	12	HSW-6	S		S	185762								0.5
6	3-3/4	1/4	700	17	HSW-6		185770										0.5
6	3-3/4	1/4	700	17	HSW-6			NS	185789								0.5
6	3-3/4	1/4	700	17	HSW-6-3		185797										0.5
6	3-3/4	1/4	700	17	HSW-6-3			S	185800								0.5
6	3-3/4	1/4								500	12	HSW-60	NS	185850			0.5
6	3-3/4	1/4								800	20	HSW-60			NS	185869	0.5
6	3-3/4	1/4								1,000	24	HSW-60-3	S	255767			0.5
6	3-3/4	1/4								750	18	HSW-60-3			S	255759	0.5
<b>RHSW — Half Sheath</b>																	
6	3-3/4	1/4	350	8	RHSW-6-3	S	185893										0.6
6	3-3/4	1/4	500	12	RHSW-6	NS	185922										0.6
<b>RHSW — Full Sheath</b>																	
6	3-3/4	1/4	800	19	RHSW-61	S	185906										0.6
6	3-3/4	1/4	800	19	RHSW-61-3			NS	185914								0.6

**Stock Status:** S = stock NS = non-stock  
**To Order**—Specify model, PCN, watts, volts and quantity.

1. "-3" in model number indicates 3 heat.

**Other Note** — Type HSN is not CSA Certified.