



## CTRH

### Heavy Duty Cartridge Heater

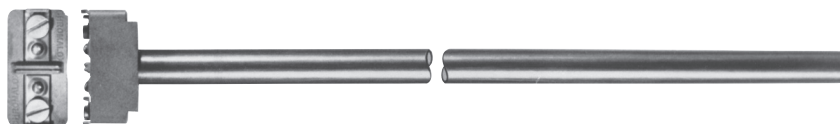

- 0.553 and 0.66" Dia.
- 1,670 - 5,130 Watts
- 120, 208, 240 and 480 Volt
- 50 and 55 W/In<sup>2</sup>
- 304 Stainless Steel Sheath

#### Dimensions

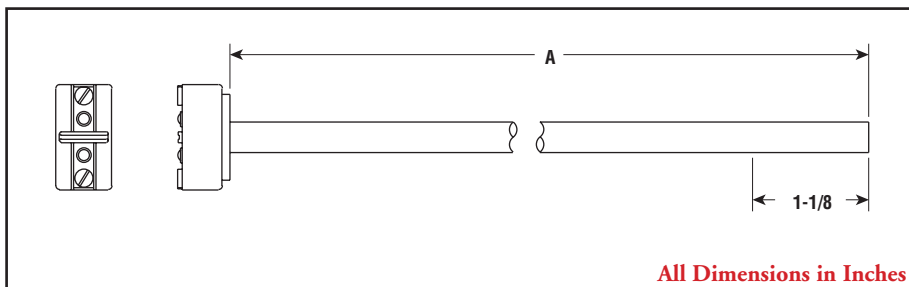

#### Applications

- Forming
- Stress Relieving Metal Parts
- Dies
- Platens

#### Construction

**Type CTRH** is an extra high-quality cartridge heater.

**Available in** 0.553 and 0.663" diameter, sheath lengths up to 4-1/2 feet.

**50 - 55 W/In<sup>2</sup>** to heat materials up to 800°F.

#### Specifications and Ordering Information

Dimensions (In.)		Watts	W/In <sup>2</sup>	Model	120V		208V		240V		480V		Wt. (Lbs.)
Diameter	Sheath Length				Stock	PCN	Stock	PCN	Stock	PCN	Stock	PCN	
0.553	20	1,670	55	CTRH-520	NS	276517	—	—	—	—	—	—	1.3
0.553	24	2,475	55	CTRH-524	NS	276525	NS	276533	NS	276541	—	—	1.5
0.553	28	2,440	55	CTRH-528	NS	276550	NS	276568	NS	276576	—	—	1.8
0.553	32	2,820	55	CTRH-532	NS	276584	NS	276592	NS	276605	—	—	2
0.553	36	3,200	55	CTRH-536	—	—	NS	276613	NS	276621	—	—	2.3
0.553	40	3,580	55	CTRH-540	—	—	NS	276630	NS	276648	—	—	2.5
0.553	44	3,970	55	CTRH-544	—	—	NS	276656	NS	276664	—	—	2.8
0.553	48	4,350	55	CTRH-548	—	—	NS	276672	NS	276680	NS	276699	3
0.553	52	4,730	55	CTRH-552	—	—	NS	276701	NS	276710	NS	276728	3.3
0.66	20	1,810	50	CTRH-620	NS	276736	—	—	—	—	—	—	1.6
0.66	24	2,475	50	CTRH-624	NS	276744	NS	276752	NS	276760	—	—	1.8
0.66	28	2,640	50	CTRH-628	NS	276779	NS	276787	NS	276795	—	—	2.1
0.66	32	3,060	50	CTRH-632	NS	276808	NS	276816	NS	276824	—	—	2.4
0.66	36	3,470	50	CTRH-636	—	—	NS	276832	NS	276840	—	—	2.7
0.66	40	3,880	50	CTRH-640	—	—	NS	276859	NS	276867	—	—	3
0.66	44	4,300	50	CTRH-644	—	—	NS	276875	NS	276883	NS	276891	3.3
0.66	48	4,610	50	CTRH-648	—	—	NS	276904	NS	276912	NS	276920	3.6
0.66	52	5,130	50	CTRH-652	—	—	NS	276939	NS	276947	NS	276955	3.9

**Stock Status:** S = stock NS = non-stock  
**To Order**—Specify model, PCN, watts, volts and quantity.