


## S-RAD

### Single Element Radiant Heater (cont'd.)



#### Dimensions (Inches)

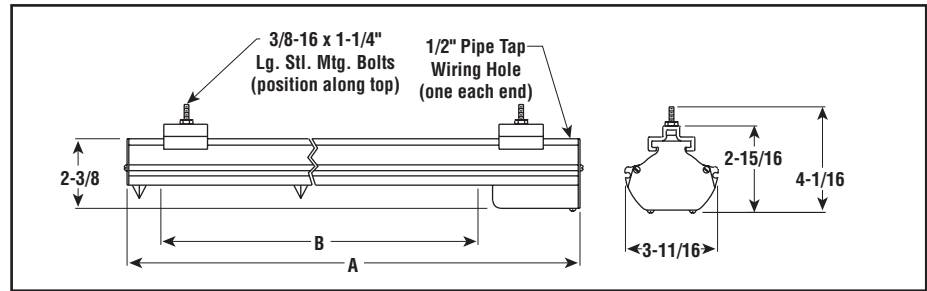

#### Specifications and Ordering Information

kW	Volts	Length (In.)		Model	Stock	PCN	Optional Grille <sup>1</sup>	Replacement Elements	Wt. (Lbs.)
		Overall A	Heated B						
0.95	120	24-3/8	16-1/2	S-RAD-2	NS	115334	(1) GR-2	SRTU-209	5
0.95	208	24-3/8	16-1/2	S-RAD-2V	NS	115342	(1) GR-2	SRTU-209V	5
0.95	240	24-3/8	16-1/2	S-RAD-2	NS	115350	(1) GR-2	SRTU-209	5
0.95	275	24-3/8	16-1/2	S-RAD-2V	NS	115369	(1) GR-2	SRTU-209V	5
1.3	120	30-5/8	22-3/4	S-RAD-3	NS	115377	(1) GR-3	SRTU-313	6
1.3	208	30-5/8	22-3/4	S-RAD-3V	NS	115385	(1) GR-3	SRTU-313V	6
1.3	240	30-5/8	22-3/4	S-RAD-3	NS	115393	(1) GR-3	SRTU-313	6
1.3	275	30-5/8	22-3/4	S-RAD-3V	NS	115406	(1) GR-3	SRTU-313V	6
2.2	208	46-5/8	38-5/8	S-RAD-4V	NS	115414	(1) GR-4	SRTU-422V	9
2.2	240	46-5/8	38-5/8	S-RAD-4	NS	115422	(1) GR-4	SRTU-422	9
2.2	275	46-5/8	38-5/8	S-RAD-4V	NS	115430	(1) GR-4	SRTU-422V	9
3	208	61-3/8	53-1/4	S-RAD-5V	NS	115457	(1) GR-5	SRTU-530V	11
3	240	61-3/8	53-1/4	S-RAD-5	NS	115465	(1) GR-5	SRTU-530	11
3	275	61-3/8	53-1/4	S-RAD-5V	NS	115473	(1) GR-5	SRTU-530V	11
3.75	208	73-3/4	65-1/2	S-RAD-6V	NS	115490	(1) GR-2, (1) GR-5	SRTU-638V	13
3.75	240	73-3/4	65-1/2	S-RAD-6	NS	115502	(1) GR-2, (1) GR-5	SRTU-638	13
3.75	275	73-3/4	65-1/2	S-RAD-6V	NS	115510	(1) GR-2, (1) GR-5	SRTU-638V	13
4.4	208	85-3/4	77-1/2	S-RAD-7V	NS	115537	(1) GR-2, (1) GR-6	SRTU-744V	15
4.4	240	85-3/4	77-1/2	S-RAD-7	NS	115545	(1) GR-2, (1) GR-6	SRTU-744	15
4.4	275	85-3/4	77-1/2	S-RAD-7V	NS	115553	(1) GR-2, (1) GR-6	SRTU-744V	15

**Stock Status:** S = stock NS = non-stock

**To Order**—Specify model, PCN, kW, volts, quantity, optional grille and replacement elements (if needed).

**Notes —**

1. See Accessories in this section for ordering information.

2. 480V ratings are available on some models. Contact your Local Chromalox Sales office for price and availability.