

NWHO & NWHOB

Light & Medium

Weight Oil Applications (*cont'd.*)

Specifications and Ordering Information


kW	Volts	Ckt & Phase	Dimensions (In.)			Model	Stock	PCN	Wt. (Lbs.)
			A	B	C				
Series 06 — 5 inch, 150 lb carbon steel vessel — 6 steel elements (23 W/in²) with side mounted thermostat — 2" NPT pipe inlet and outlet									
12	240	1-3	41-3/4	30	11-3/8	NWHO-06-012P-E1	NS	101637	140
12	480	1-3	41-3/4	30	11-3/8	NWHO-06-012P-E1	NS	011560	140
15	240	1-3	48-3/4	37	14-1/8	NWHO-06-015P-E1	S	101750	155
15	480	1-3	48-3/4	37	14-1/8	NWHO-06-015P-E1	S	101776	155
20	240	2-3	60-1/4	48-1/2	20-5/8	NWHO-06-020P-E1	S	101872	176
20	480	1-3	60-1/4	48-1/2	20-5/8	NWHO-06-020P-E1	S	101899	176
25	240	2-3	73-5/8	61-7/8	27-5/16	NWHO-06-025P-E1	NS	011316	212
25	480	1-3	73-5/8	61-7/8	27-5/16	NWHO-06-025P-E1	NS	011367	212
30	240	2-3	86-5/8	74-7/8	33-7/8	NWHO-06-030P-E1	NS	011324	240
30	480	1-3	86-5/8	74-7/8	33-7/8	NWHO-06-030P-E1	S	107537	240
Series 18 — 8 inch, 150 lb carbon steel vessel — 18 steel elements (20 W/in²) — 2-1/2" NPT - pipe inlet and outlet									
30	240	3-3	53-1/4	32-11/16	29-3/16	NWHO-18-030P-E1	NS	080194	360
30	480	3-3	53-1/4	32-11/16	29-3/16	NWHO-18-030P-E1	NS	080207	360
40	240	3-3	60-1/4	39-11/16	36-3/16	NWHO-18-040P-E1	NS	080231	436
40	480	3-3	60-1/4	39-11/16	36-3/16	NWHO-18-040P-E1	NS	084005	436
50	240	3-3	67-7/8	47-5/16	43-13/16	NWHO-18-050P-E1	NS	080274	500
50	480	3-3	67-7/8	47-5/16	43-13/16	NWHO-18-050P-E1	NS	080282	500
60	240	3-3	77-3/8	56-13/16	53-5/16	NWHO-18-060P-E1	NS	080311	600
60	480	3-3	77-3/8	56-13/16	53-5/16	NWHO-18-060P-E1	NS	080320	600
70	240	3-3	86-3/8	65-13/16	62-5/16	NWHO-18-070P-E1	NS	080354	660
70	480	3-3	86-3/8	65-13/16	62-5/16	NWHO-18-070P-E1	NS	080362	660
80	240	3-3	96-3/8	75-13/16	72-5/16	NWHO-18-080P-E1	NS	080397	750
80	480	3-3	96-3/8	75-13/16	72-5/16	NWHO-18-080P-E1	NS	080400	750
Series 27 — 10 inch, 150 lb carbon steel vessel — 27 steel elements (20 W/in²) — 3" NPT pipe inlet and outlet									
80	240	3-3	77-9/16	52	48-1/2	NWHO-27-080P-E1	NS	095871	720
80	480	3-3	77-9/16	52	48-1/2	NWHO-27-080P-E1	NS	095898	720
90	240	3-3	81-9/16	56	52-1/2	NWHO-27-090P-E1	NS	095919	735
90	480	3-3	81-9/16	56	52-1/2	NWHO-27-090P-E1	NS	095935	735
100	480	3-3	87-9/16	62	58-1/2	NWHO-27-100P-E1	NS	095951	750
120	480	3-3	97-9/16	72	68-1/2	NWHO-27-120P-E1	NS	095994	765

Stock Status: S = stock NS = non-stock
To Order—Specify model, volts, phase, kW, PCN and quantity.


Note — Refer to the Controls section for control panels.

Dimensions (Inches)

NWHO-06

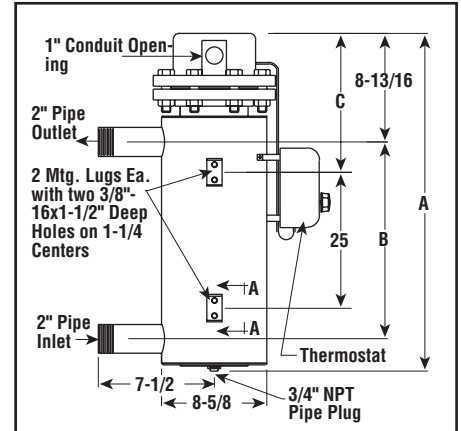

NWHO-18

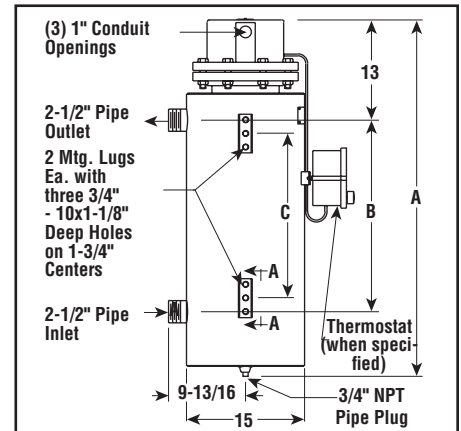

NWHO-27

