


GS3 & GT3 Side Mount Metal Tube Heaters

- 316 Stainless Steel and Titanium Sheath Tubes
- 20 and 40 W/In²
- 3 - 36 kW
- 120, 240 and 480 Volt, 1 or 3 Phase
- Moisture Resistant Terminal Enclosure



Dimensions (Inches)

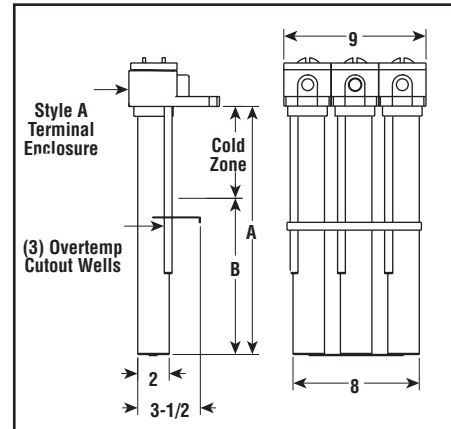

OVER-THE-SIDE

Features

- Moisture Resistant Terminal Enclosure
- Side Mounted Construction with Mounting Flange
- Single Use Overtemperature Protection Thermal Fuse Supplied as Standard, for Process Temperatures up to 180°F (82°C)/ Fuse Temperature 219°F (104°C) Limit. For Higher

Process/Fuse Temperature Limits, Consult Factory. Field Replaceable

- Resettable Overtemperature Protection Thermal Fuses also Available
- Available in Single Phase
- Steel, 304SS and Other Sheath Materials and Configurations available

Specifications and Ordering Information

kW	Volts	W/In ²	Phase ¹	Dimensions (In.)		316SS			Titanium			Wt. (Lbs.)
				A	B	Model	PCN	Stock	Model	PCN	Stock	
GS3 and GT3 — 40 W/In²												
3	240	40	3	11	6	GS3-32	050665	NS	GT3-32	050980	NS	18
6	240	40	3	17	10	GS3-62	050673	NS	GT3-62	050999	NS	27
6	480	40	3	17	10	GS3-64	050681	NS	GT3-64	051000	NS	27
9	240	40	3	23	16	GS3-92	050690	NS	GT3-92	051019	NS	33
9	480	40	3	23	16	GS3-94	050702	NS	GT3-94	051027	NS	33
12	240	40	3	29	20	GS3-122	050710	NS	GT3-122	051035	NS	39
12	480	40	3	29	20	GS3-124	050729	NS	GT3-124	051043	NS	39
15	240	40	3	35	25	GS3-152	050737	NS	GT3-152	051051	NS	46
15	480	40	3	35	25	GS3-154	050745	NS	GT3-154	051060	NS	46
18	240	40	3	40	30	GS3-182	050753	NS	GT3-182	051078	NS	50
18	480	40	3	40	30	GS3-184	050761	NS	GT3-184	051086	NS	50
24	240	40	3	47	37	GS3-242	050770	NS	GT3-242	051094	NS	63
24	480	40	3	47	37	GS3-244	050788	NS	GT3-244	051107	NS	63
27	480	40	3	54	44	GS3-274	050809	NS	GT3-274	051123	NS	69
30	480	40	3	59	49	GS3-304	050825	NS	GT3-304	051140	NS	75
36	480	40	3	68	58	GS3-364	050841	NS	GT3-364	051166	NS	84
GDS3 and GDT3 — 20 W/In²												
3	240	20	3	17	10	GDS3-32	050850	NS	GDT3-32	051174	NS	27
3	480	20	3	17	10	GDS3-34	050868	NS	GDT3-34	051182	NS	27
6	240	20	3	29	20	GDS3-62	050876	NS	GDT3-62	051190	NS	39
6	480	20	3	29	20	GDS3-64	050884	NS	GDT3-64	051203	NS	39
9	240	20	3	40	30	GDS3-92	050892	NS	GDT3-92	051211	NS	54
9	480	20	3	40	30	GDS3-94	050905	NS	GDT3-94	051220	NS	54
12	240	20	3	47	37	GDS3-122	050913	NS	GDT3-122	051238	NS	63
12	480	20	3	47	37	GDS3-124	050921	NS	GDT3-124	051246	NS	63
15	240	20	3	59	49	GDS3-152	050930	NS	GDT3-152	051254	NS	75
15	480	20	3	59	49	GDS3-154	050948	NS	GDT3-154	051262	NS	75
18	240	20	3	68	58	GDS3-182	050956	NS	GDT3-182	051270	NS	87
18	480	20	3	68	58	GDS3-184	050964	NS	GDT3-184	051289	NS	87

Stock Status: S = stock NS = non-stock
To Order—Specify model, PCN, kW, volts, phase and quantity.