


## CH-OTS

### Portable Tank Heater

- Copper Sheath Nickel Plated Elements
- High Watt Density (49 - 58W/in<sup>2</sup>)
- 4 and 6 kW
- 208 and 240 Volt, Single Phase



#### Dimensions (Inches)

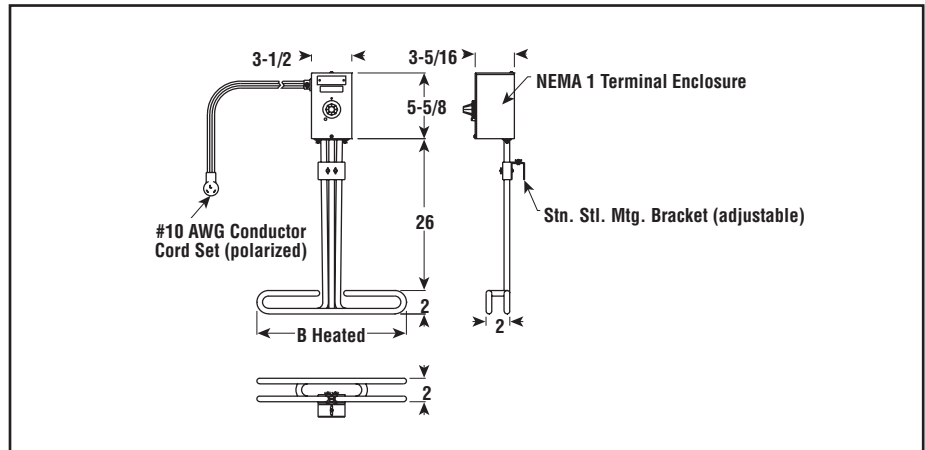

#### Features

- 26" Riser (unheated section)
- Integral Control (60 - 250°F)
- Manual Reset Cutout (set @ 50°F above temperature setpoint)
- Built-in Pilot Light
- 36" Long Cord with 10 - 30P Plug

#### Specifications and Ordering Information

kW	Volts	W/in <sup>2</sup>	Phase	DIM B (in.)	Copper			Wt. (Lbs.)
					Model	Stock	PCN	
4	240	49	1	14	CH-OTS-404	S	093833	10
6	208	58	1	17	CH-OTS-608	S	093817	10
6	240	58	1	17	CH-OTS-604	S	093825	10

**Stock Status:** S = stock    NS = non-stock  
**To Order**—Specify model, PCN, kW, volts, phase and quantity.