


Immersion

ARMT-3 Clean Water Applications (cont'd.)



- 2-1/2" NPT Brass Screw Plug
- Copper Sheath Elements
- High Watt Density (46 - 53 W/In²)
- 3 - 18 kW
- Integral Thermostat (DPST)
- 120, 208, 240 and 480 Volt, 1 and 3 Phase
- Moisture Resistant/Explosion Resistant Terminal Enclosure

E2 — Dimensions (Inches)

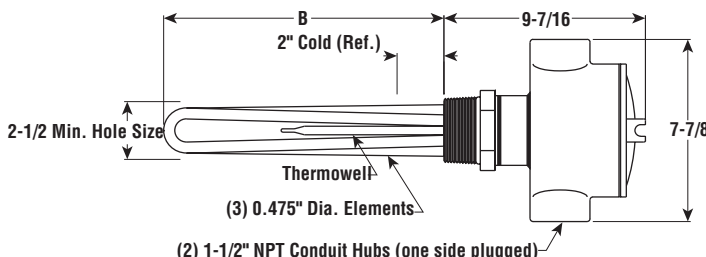

SCREW PLUG



Same-day shipping on stock item orders received before 4 pm CST. 3-day shipping on assembly-stock items.

Specifications and Ordering Information

							T2 — Temperature (60 - 250°F)			T1 — Temperature (0 - 100°F)		
kW	Volts	Phase	W/In ²	No. Elem.	DIMB (In.)	Wt. (Lbs.)	Model	Stock	PCN	Model	Stock	PCN
E2 Moisture Resistant/Explosion Resistant												
3	120	1	51	3	7-3/8	11	ARMT-3305E2T2	NS	310965	ARMT-3305E2T1	NS	310973
3	208	1	51	3	7-3/8	11	ARMT-3305E2T2	NS	320750	ARMT-3305E2T1	NS	320768
3	208	3	51	3	7-3/8	11	ARMT-3305E2T2	NS	320792	ARMT-3305E2T1	NS	320805
3	240	1	51	3	7-3/8	11	ARMT-3305E2T2	NS	285835	ARMT-3305E2T1	NS	285827
3	240	3	51	3	7-3/8	11	ARMT-3305E2T2	NS	285860	ARMT-3305E2T1	NS	285851
3	480	1	51	3	7-3/8	11	ARMT-3305E2T2	NS	311001	ARMT-3305E2T1	NS	311028
3	480	3	51	3	7-3/8	11	ARMT-3305E2T2	NS	311010	ARMT-3305E2T1	NS	311036
3.75	120	1	52	3	8-7/8	11	ARMT-3375E2T2	NS	311079	ARMT-3375E2T1	NS	311108
3.75	208	1	52	3	8-7/8	11	ARMT-3375E2T2	NS	320830	ARMT-3375E2T1	NS	320848
3.75	208	3	52	3	8-7/8	11	ARMT-3375E2T2	NS	320872	ARMT-3375E2T1	NS	320880
3.75	240	1	52	3	8-7/8	11	ARMT-3375E2T2	NS	285907	ARMT-3375E2T1	NS	285894
3.75	240	3	52	3	8-7/8	11	ARMT-3375E2T2	NS	285940	ARMT-3375E2T1	NS	285931
3.75	480	1	52	3	8-7/8	11	ARMT-3375E2T2	NS	311087	ARMT-3375E2T1	NS	311116
3.75	480	3	52	3	8-7/8	11	ARMT-3375E2T2	NS	311095	ARMT-3375E2T1	NS	311124
4.5	120	1	48	3	11-3/8	12	ARMT-3455E2T2	NS	311140	ARMT-3455E2T1	NS	311159
4.5	208	1	48	3	11-3/8	12	ARMT-3455E2T2	NS	320910	ARMT-3455E2T1	NS	320928
4.5	208	3	48	3	11-3/8	12	ARMT-3455E2T2	NS	320952	ARMT-3455E2T1	NS	320960
4.5	240	1	48	3	11-3/8	12	ARMT-3455E2T2	NS	285982	ARMT-3455E2T1	NS	285974
4.5	240	3	48	3	11-3/8	12	ARMT-3455E2T2	NS	286010	ARMT-3455E2T1	NS	286002
4.5	480	1	48	3	11-3/8	12	ARMT-3455E2T2	NS	286053	ARMT-3455E2T1	NS	286045
4.5	480	3	48	3	11-3/8	12	ARMT-3455E2T2	NS	286088	ARMT-3455E2T1	NS	286070
6	120	1	48	3	17-3/8	13	ARMT-3605E2T2	NS	311175	ARMT-3605E2T1	NS	311183
6	208	1	48	3	17-3/8	13	ARMT-3605E2T2	NS	320995	ARMT-3605E2T1	NS	321007
6	208	3	48	3	17-3/8	13	ARMT-3605E2T2	NS	321031	ARMT-3605E2T1	NS	321040
6	240	1	48	3	17-3/8	13	ARMT-3605E2T2	NS	286125	ARMT-3605E2T1	NS	286117
6	240	3	48	3	17-3/8	13	ARMT-3605E2T2	NS	286150	ARMT-3605E2T1	NS	286141
6	480	1	48	3	17-3/8	13	ARMT-3605E2T2	NS	286192	ARMT-3605E2T1	NS	286184
6	480	3	48	3	17-3/8	13	ARMT-3605E2T2	NS	286221	ARMT-3605E2T1	NS	274896
7.5	208	1	53	3	19-1/8	13	ARMT-3755E2T2	NS	321074	ARMT-3755E2T1	NS	321082
7.5	208	3	53	3	19-1/8	13	ARMT-3755E2T2	NS	321111	ARMT-3755E2T1	NS	321120
7.5	240	1	53	3	19-1/8	13	ARMT-3755E2T2	NS	286256	ARMT-3755E2T1	NS	286248
7.5	240	3	53	3	19-1/8	13	ARMT-3755E2T2	NS	286299	ARMT-3755E2T1	NS	286280
7.5	480	1	53	3	19-1/8	13	ARMT-3755E2T2	NS	286336	ARMT-3755E2T1	NS	286328
7.5	480	3	53	3	19-1/8	13	ARMT-3755E2T2	NS	286379	ARMT-3755E2T1	NS	286360
9	208	1	47	3	24-1/2	14	ARMT-3905E2T2	NS	321154	ARMT-3905E2T1	NS	321162
9	208	3	47	3	24-1/2	14	ARMT-3905E2T2	NS	321197	ARMT-3905E2T1	NS	321200
9	240	1	47	3	24-1/2	14	ARMT-3905E2T2	NS	286416	ARMT-3905E2T1	NS	286408
9	240	3	47	3	24-1/2	14	ARMT-3905E2T2	NS	286440	ARMT-3905E2T1	NS	286432
9	480	1	47	3	24-1/2	14	ARMT-3905E2T2	NS	286483	ARMT-3905E2T1	NS	286475
9	480	3	47	3	24-1/2	14	ARMT-3905E2T2	NS	286512	ARMT-3905E2T1	NS	286504